

100% Indirect

22L & SAE103



22L Pendant | 22L-P-I

New 100% Indirect Only Distribution


Variable Intensity technology provides specifiable lumen output/wattage on the new 100% Indirect 22L and SAE103, pendant and wall.




Pendant | SAE103-P-I



Pendant | 22L-P-I

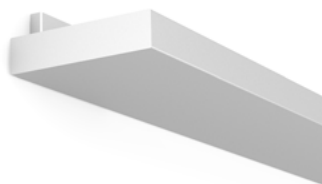

Wall | SAE103-W-I

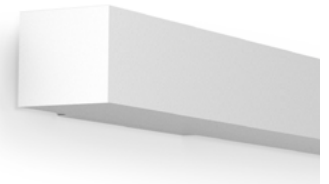

Wall | 22L-W-I

CLICK ON PRODUCT NAME TO VISIT THE PRODUCT WEB PAGE

100% Indirect

22L & SAE103

ORDERING INFORMATION

SAE103

| Feature | Options | Description |
|-----------------------------|----------------------------------------|-------------------------------------------------------|
| Program | SAE | SAE Program |
| Series | 103 | 103 LED Indirect |
| Mounting | P | Pendant |
| | W | Wall |
| Fixture Distribution | I | Indirect |
| Row Length (in feet) | ___' | Enter in foot increments. Note fixture lengths below. |
| Max Length in Row | 03 | 3', 914mm |
| | 04 | 4', 1219mm |
| | 06 | 6', 1829mm |
| | 08 | 8', 2438mm |
| Finish/Color | C1 | Matte White (Default) |
| | CC | Custom Color |
| Color Temperature | 27K | 2700K |
| | 30K | 3000K |
| | 35K | 3500K |
| | 40K | 4000K |
| | 50K | 5000K |
| | 27K9 | 2700K, 90 CRI |
| | 30K9 | 3000K, 90 CRI |
| | 35K9 | 3500K, 90 CRI |
| | 40K9 | 4000K, 90 CRI |
| | 50K9 | 5000K, 90 CRI |
| | 2230TD | 2200K-3000K SpectraSync™ Dim-to-Warm |
| 2750T | 2700K-5000K SpectraSync™ Tunable White | |
| 2765T | 2700K-6500K SpectraSync™ Tunable White | |
| Output/ft | I055 | 550 (min) |
| | I1450 | 1400 (max) |
| Driver | NDM | Non Dimming |
| | D05 | 5% Dimming, 0-10V |
| | D55 | Soft-Start 5% Dimming, 0-10V |
| | D01 | 1% Dimming, 0-10V |
| | D51 | Soft-Start 1% Dimming, 0-10V |
| | D00 | Dim-to-off (1%), 0-10V |
| | D50 | Soft-Start Dim-to-off (1%), 0-10V |
| | LEC | Hi-lume 1% EcoSystem LED driver |
| | DALI | DALI |
| DALIP | Powered DALI (2.0) | |
| Circuiting | 1C | 1 Circuit |
| Voltage | UNV | Universal Voltage |
| | 120 | 120 Volt |
| | 277 | 277 Volt |
| | 347 | 347 Volt |

22L

| Feature | Options | Description |
|-----------------------------|----------------------------------------|-------------------------------------------------------|
| Series | 22L | 100% Indirect Linear |
| Mounting | P | Pendant |
| | W | Wall |
| Fixture Distribution | I | Indirect |
| Row Length (in feet) | ___' | Enter in foot increments. Note fixture lengths below. |
| Max Length in Row | 03 | 3', 914mm |
| | 04 | 4', 1219mm |
| | 06 | 6', 1829mm |
| | 08 | 8', 2438mm |
| Finish/Color | C1 | Matte White (Default) |
| | C2 | Textured Matte White |
| | C3 | Light Silver |
| | C4 | Machined Aluminum |
| | C5 | Carbon Black |
| | C6 | Textured Camera Black |
| CC | Custom Color | |
| Color Temperature | 27K | 2700K |
| | 30K | 3000K |
| | 35K | 3500K |
| | 40K | 4000K |
| | 50K | 5000K |
| | 27K9 | 2700K, 90 CRI |
| | 30K9 | 3000K, 90 CRI |
| | 35K9 | 3500K, 90 CRI |
| | 40K9 | 4000K, 90 CRI |
| | 50K9 | 5000K, 90 CRI |
| | 2230TD | 2200K-3000K SpectraSync™ Dim-to-Warm |
| 2750T | 2700K-5000K SpectraSync™ Tunable White | |
| 2765T | 2700K-6500K SpectraSync™ Tunable White | |
| Output/ft | I030 | 300 (min) |
| | I115 | 1150 (max) |
| Driver | NDM | Non Dimming |
| | D05 | 5% Dimming, 0-10V |
| | D55 | Soft-Start 5% Dimming, 0-10V |
| | D01 | 1% Dimming, 0-10V |
| | D51 | Soft-Start 1% Dimming, 0-10V |
| | D00 | Dim-to-off (1%), 0-10V |
| | D50 | Soft-Start Dim-to-off (1%), 0-10V |
| | LEC | Hi-lume 1% EcoSystem LED driver |
| | DALI | DALI |
| DALIP | Powered DALI (2.0) | |
| Circuiting | 1C | 1 Circuit |
| Voltage | UNV | Universal Voltage |
| | 120 | 120 Volt |
| | 277 | 277 Volt |
| | 347 | 347 Volt |