

BURNDY® PATRIOT® PAT444S SERIES

FEATURES & BENEFITS

Also available with T3 Technology! See T3 Tech Series Brochure for details.




MODELS, SPECIFICATIONS & CAPACITIES

MODELS	
PAT444SLI	Tool, 3Ah, 120V AC
PAT444SL5	Tool, 5Ah, 120V AC
PAT444SLCB	Tool, No Charger/Batteries

SPECIFICATIONS	
Output Force	11 Tons
Tool Weight	14.80 lbs (without battery)
Size	16.9" x 13.7" x 3.2"
Die Style	Dieless
Operating Voltage	18 V-DC Lithium-ion
Recharge Time	30 minutes (3.0Ah)
	45 minutes (5.0Ah)
Warranty	5 year limited warranty
	Lifetime warranty on INFINITY DRIVE®
	3 years on batteries and charger



Range Taking Capability: #4 AWG to 1000 kcmil

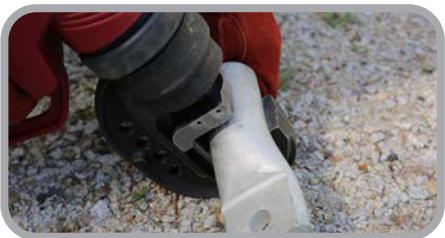

- Connections are UL Listed to 486A-486B on Copper & Aluminum terminals and splices
- Comply with ANSI C119.4 on YDS-RL and YDS-RLNI Splices (ACSR, AAC, AAAC, ACAR)
- Qualified for use on YCP-L Compression Pulling Heads

CRIMPING CAPACITIES	TERMINALS & SPLICES	HYPLUG™	FULL TENSION SPLICES
Copper	#4 AWG - 1000 kcmil	#4 AWG - 1000 kcmil	
Copper Flex	#4 AWG - 1000 kcmil	#2 AWG - 777 kcmil	
Aluminum	#4 AWG - 1000 kcmil	#4 AWG - 1000 kcmil	
ACSR, AAC, AAAC, ACAR			#4 AWG - 556.5 kcmil



TRUST THE BURNDY® ENGINEERED SYSTEM



Hubbell USA
47 East Industrial Park Drive
Manchester, NH 03109
www.hubbell.com/burndy
1-800-346-4175 | 1-603-647-5000

Hubbell Canada
870 Brock Road South
Pickering, Ontario, Canada
L1W 1Z8
www.hubbell.ca
serviceexcellence@hubbell.ca
1-800-465-7051

Hubbell Mexico
011-52-722-265-4400

Tool Repair Center
1-800-426-8720

Technical Service
603-647-5019 | 1-800-451-4956

BURNDY® TOOLS

PATRIOT® PAT444S
DIELESS C-HEAD
SERIES



©2024 Burndy, LLC. All rights reserved.

Hubbell and the Hubbell logo are registered trademarks or trademarks of Hubbell Incorporated. All other trademarks are the property of their respective owners.

