

BURNDY® PATRIOT® PAT81K2 SERIES

FEATURES & BENEFITS



Unique Crimp Guides



8IKSMLGUIDEKIT:  
Copper #8-4 AWG  
Aluminum #8-6 AWG



8IKLRGGUIDEKIT:  
Copper #3 AWG-#250 kcmil  
Aluminum #5-3/0 AWG

MODELS, SPECIFICATIONS & CAPACITIES

| MODELS       |                                       |
|--------------|---------------------------------------|
| PAT81K2U03A2 | Tool, Guides, 3Ah, 120V AC, Hard Case |
| PAT81K2U05A2 | Tool, Guides, 5Ah, 120V AC, Hard Case |
| PAT81K2U03A3 | Tool, Guides, 3Ah, 120V AC, Pro Bag   |
| PAT81K2U05A3 | Tool, Guides, 5Ah, 120V AC, Pro Bag   |



TRUST THE BURNDY® ENGINEERED SYSTEM

| SPECIFICATIONS    |                                      |
|-------------------|--------------------------------------|
| Output Force      | 6 Tons                               |
| Tool Weight       | 11.05 lbs (without battery)          |
| Size              | 15.20" x 14.93" x 3.25"              |
| Die Style         | Dieless                              |
| Operating Voltage | 18 V-DC Lithium-ion                  |
| Recharge Time     | 30 minutes (3.0Ah)                   |
|                   | 45 minutes (5.0Ah)                   |
| Warranty          | 5 year limited warranty              |
|                   | Lifetime warranty on INFINITY DRIVE® |
|                   | 3 years on batteries and charger     |



Range Taking Capability: #8 AWG to 1000 kcmil



Connections are UL Listed to 486A-486B on Copper & Aluminum terminals and splices

| CRIMPING CAPACITIES | TERMINALS & SPLICES  | HYPLUG™            |
|---------------------|----------------------|--------------------|
| Copper              | #8 AWG - 1000 kcmil  |                    |
| Copper Flex         | #8 AWG - 777.7 kcmil |                    |
| Aluminum            | #8 AWG - 750 kcmil   | #8 AWG - 750 kcmil |





**Hubbell USA**  
47 East Industrial Park Drive  
Manchester, NH 03109  
[www.hubbell.com/burndy](http://www.hubbell.com/burndy)  
1-800-346-4175 | 1-603-647-5000

**Hubbell Canada**  
870 Brock Road South  
Pickering, Ontario, Canada  
L1W 1Z8  
[www.hubbell.ca](http://www.hubbell.ca)  
[serviceexcellence@hubbell.ca](mailto:serviceexcellence@hubbell.ca)  
1-800-465-7051


**Hubbell Mexico**  
011-52-722-265-4400

**Tool Repair Center**  
1-800-426-8720

**Technical Service**  
603-647-5019 | 1-800-451-4956

# BURNDY® TOOLS

PATRIOT® PAT81K2  
4-POINT® DIELESS  
SERIES

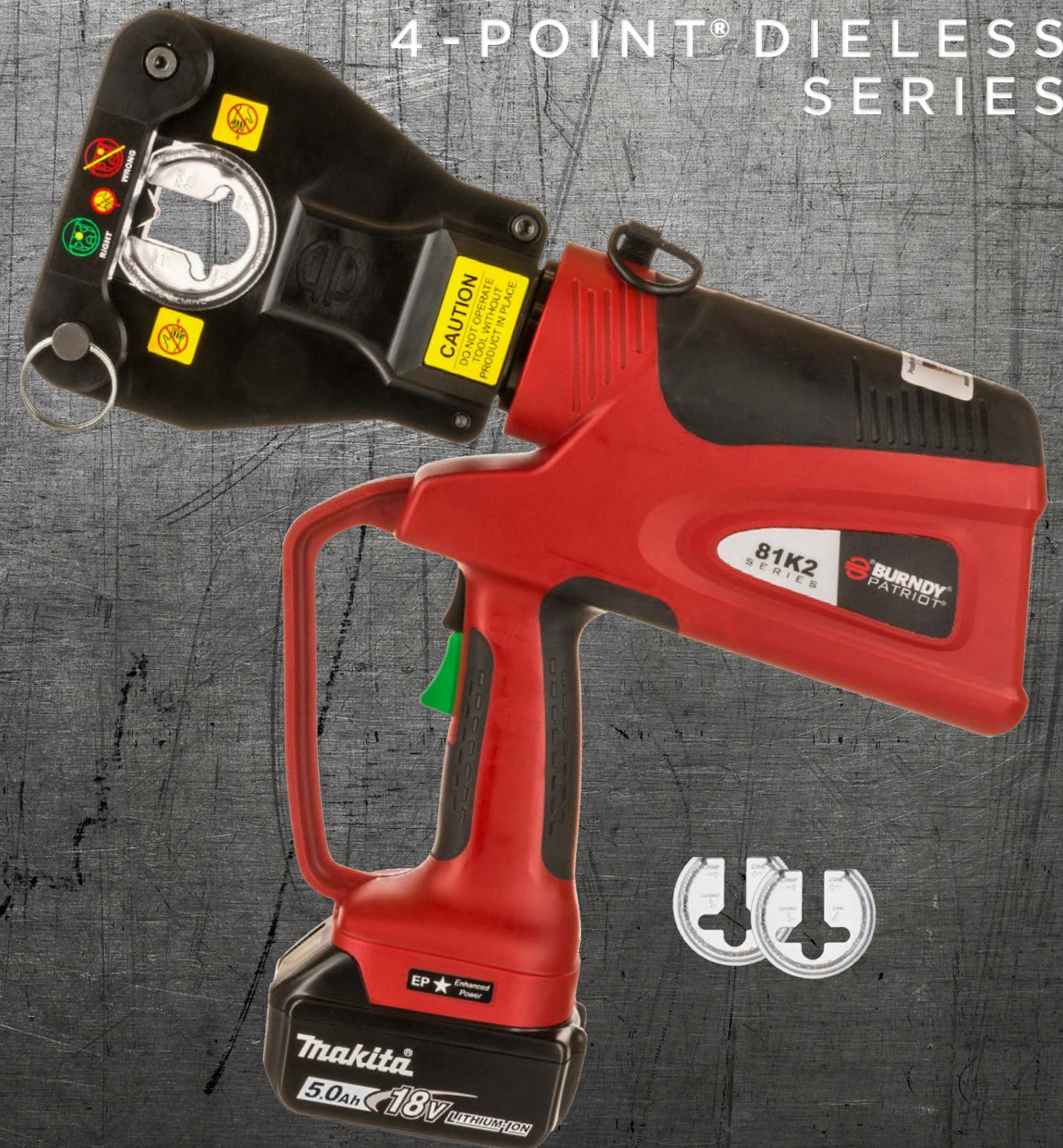

©2024 Burndy, LLC. All rights reserved.

Hubbell and the Hubbell logo are registered trademarks or trademarks of Hubbell Incorporated. All other trademarks are the property of their respective owners.

