

COMMERCIAL CORD REELS

40' Power Supply Cord Reel

- 40' 12/3 SJTW retracting cord with Triple Outlet
- 15-amp circuit breaker with reset button is located in the triple outlet
- 24" 12/3 power inlet cord with molded NEMA 5-15P grounded plug
- Adjustable ball stop allows user to set hang down height
- Wall/Ceiling Mounting Bracket is provided
- UL Listed




Removable bracket allows reel to be disengaged from mount for maximum flexibility

Durable light weight non-metallic housing

40 ft. of 12/3 cord for greater current carrying capacity

Triple tap outlet with supplemental over current protection

Description	Cable Feet (m)	Cable Type	Watts (Max)	Amps	Volts AC	Weight Lbs. (kg)	Catalog Number
Reel with triple tap outlet, black	40 (12)	12/3 SJTW	1,875	15	125	9 (4)	GR12340-TR

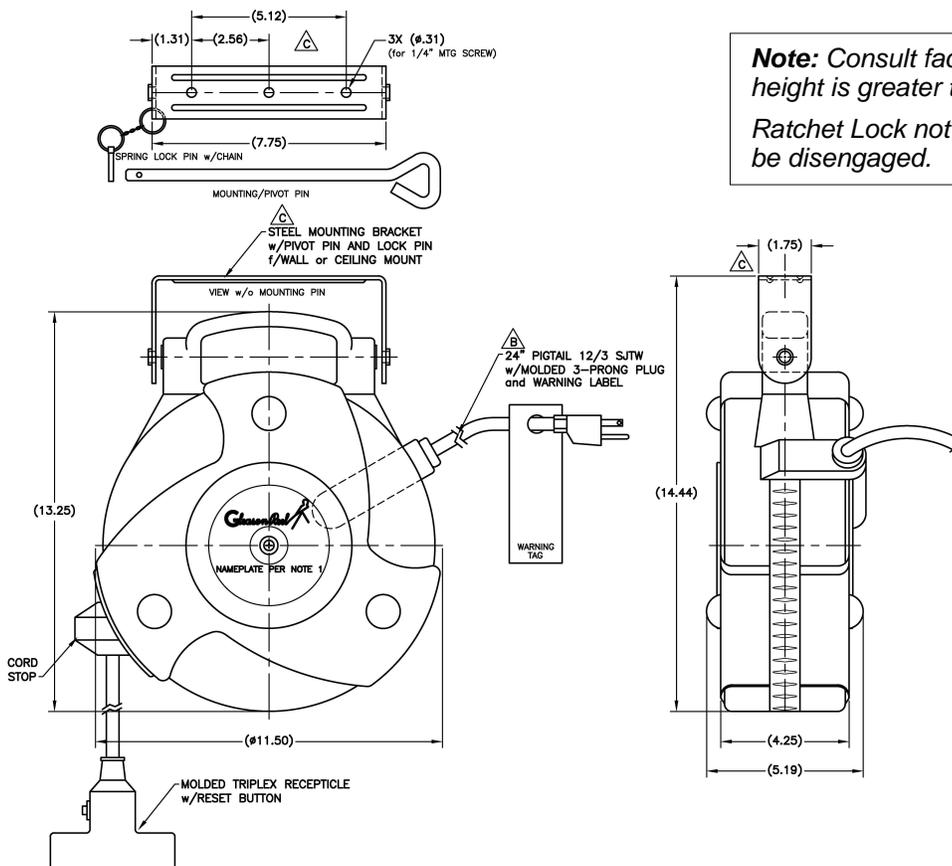

Note: Consult factory if mounting height is greater than '20.
Ratchet Lock not recommended to be disengaged.