



United States
Hubbell Lighting, Inc.
701 Millennium Boulevard
Greenville, SC 29607
www.hubbellighting.com

Canada
Hubbell Canada
870 Brock Road
Pickering, Ontario L1W 1Z8
www.hubbell-canada.com

Mexico
Hubbell De Mexico, S.A. DE CV
Av. Insurgentes Sur # 1228, 8th Floor
Col. Tlacoquemecatl del Valle • 03200 Mexico, D.F.
www.hubbell.com.mx

ALERA LIGHTING

ARCHITECTURAL AREA LIGHTING

BEACON PRODUCTS

COLUMBIA LIGHTING

COMPASS PRODUCTS

DUAL-LITE

HUBBELL CONTROL SOLUTIONS

HUBBELL INDUSTRIAL LIGHTING

HUBBELL OUTDOOR LIGHTING

KIM LIGHTING

KURT VERSEN

LITECONTROL

PRESCOLITE

SPAULDING LIGHTING

WHITEWAY



Due to our continued efforts to improve our products, product specifications are subject to change without notice.

HOL0277 REV A 12.16



GEOPAK SERIES



GEOPAK™

HUBBELL
Outdoor Lighting





The GeoPak™ Series is an LED outdoor architectural wallpack with superior performance. Designed for mounting over entrance/exit ways and along perimeter walkways. It is available in three geometric shapes: Radius, Trapezoid and Quartersphere.



Trapezoid



Radius



Quartersphere

Three Versatile Styles

Applications

EDUCATION/HOSPITALITY

Proper lighting design and effective management of the external campus environment can minimize violence and property crimes, promote efficient resource management, and provide a welcoming environment.



RETAIL

Retailers, banks, restaurants, commercial enterprises, and multi-use buildings benefit from the advantages of LED lighting. More uniform lighting levels provide overall customer and employee safety as well as making the parking area more inviting. Lighting provides peace of mind for both patrons and owner/operators of these areas.



SECURITY

Proper lighting improves safety and security and reduces crime in less frequently occupied areas including: storage facilities, delivery areas, and recycling centers.



Design



Features and Benefits:

- Capable of replacing up to 175w HID luminaires
- Easy to install and retrofit existing HID luminaires with similar footprint
- Control capabilities offer additional energy savings options
- Zero uplight distributions
- Integral battery backup options
- DesignLights Consortium® (DLC) qualified. Please refer to the DLC website for specific product qualifications at www.designlights.org.


More Info: www.hubbelloutdoor.com/products/wall-mount/

PERFORMANCE



Quick Mounting

Easy mounting without opening fixture. Attach adapter plate to wall, connect wires, hang fixture and tighten set screws.

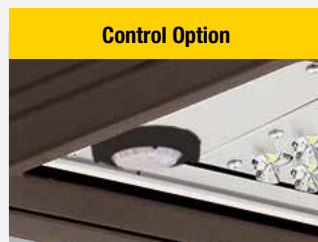

Control Option

Sensor offers greater control and energy savings with SCP programmable sensor with adjustable delay and dimming levels (Factory default is 10%)





Egress Optics

Specialized egress optics for ideal light distribution along the path of egress. 12 High Power LED's generate over 2800 lumens in normal mode, and use 4 LED's for 671 lumens in emergency mode.

8-15 ft.
TYPICAL
MOUNTING
HEIGHT

Features

POWERED BY **DUALITE**

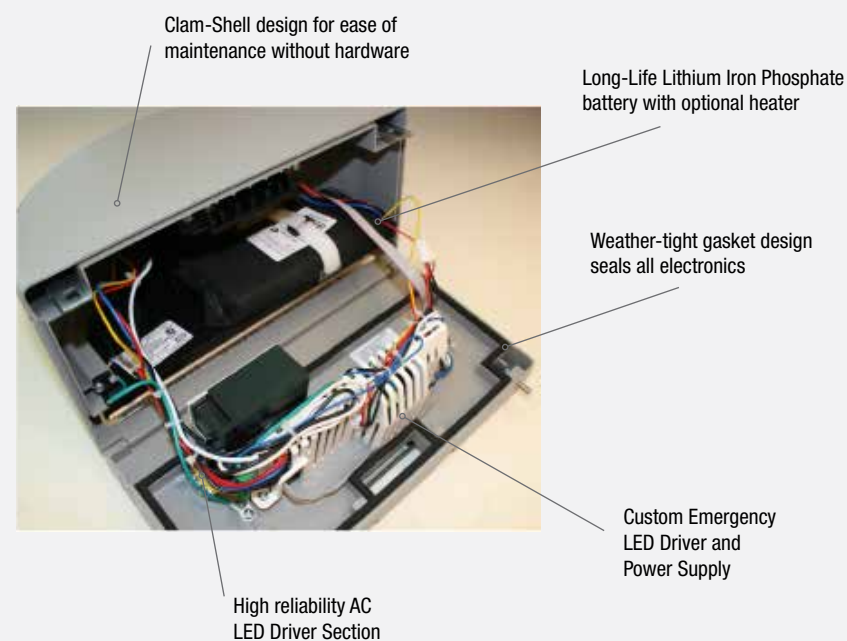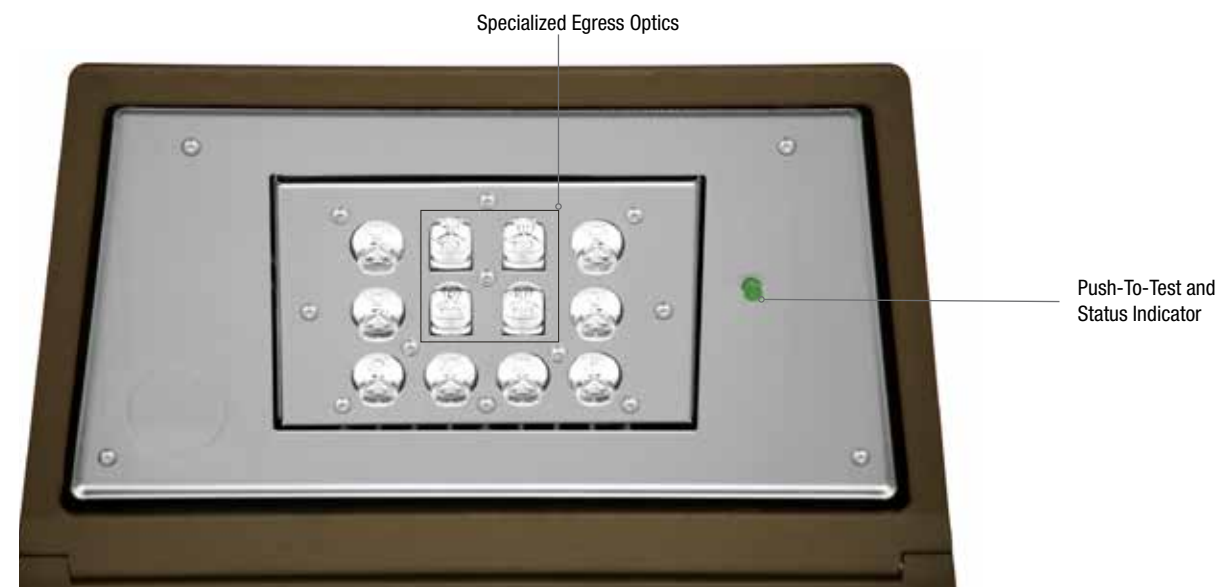

SPECTRON SELF-TEST/SELF DIAGNOSTICS

MANUAL TESTS

Initiating Act	Test Cycle
Press Test Switch Once	1 Minute
Press Test Switch Twice	2 Minute

AUTOMATIC TESTS

Testing Period	Duration of Test
Once a Month	1 Minute
Once every 6 months	Alternating 30 minutes or 60 minutes

OPERATING STATUS INDICATOR

OFF	AC OFF	
GREEN ON	AC ON	●
BLINKING GREEN	TEST IN PROGRESS	● ●

SERVICE ALERT CODES

1 RED BLINK	BATTERY DISCONNECTED	●
2 RED BLINKS	BATTERY FAULT	● ●
3 RED BLINKS	CHARGER FAULT	● ● ●
4 RED BLINKS	LED DRIVER FAULT	● ● ● ●
5 RED BLINKS	LAMP FAULT	● ● ● ● ●

BATTERY

Lithium Iron Phosphate Battery:

- Offers battery life of 5-7 years
- Outlasts Sealed Lead Acid and NiCad by 30%




Optional Battery Heater:

- Utilizes heater wrap and thermostat during charge and dis-charge
- Allows applications to -30°C

Performance


PHOTOMETRICS

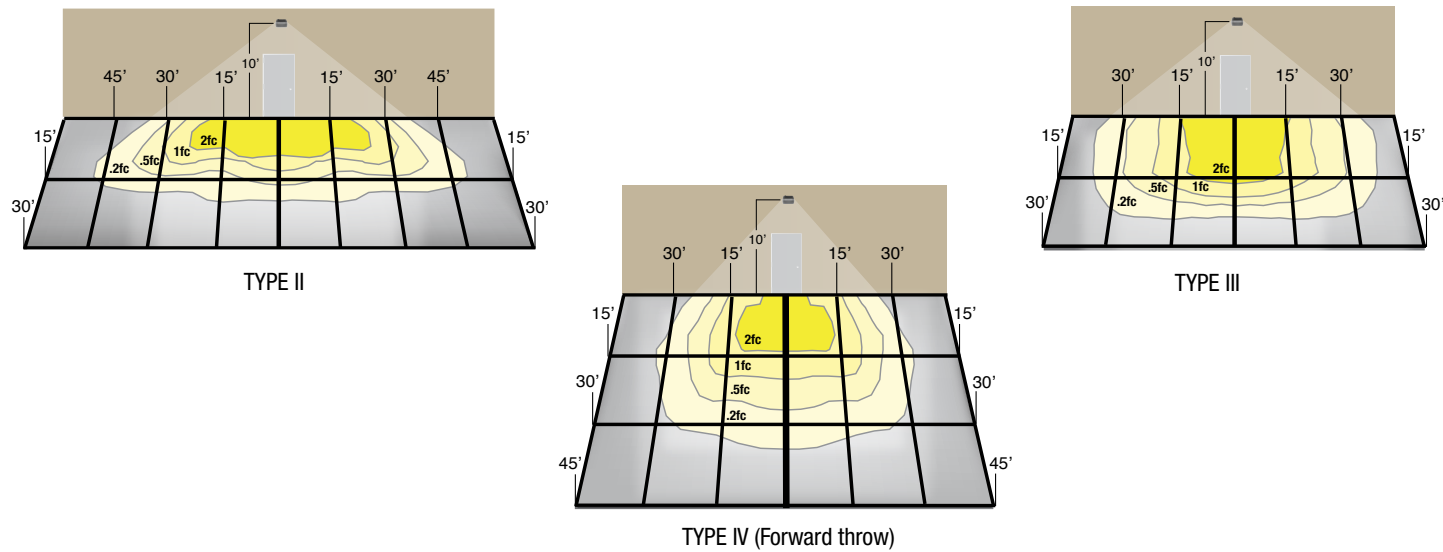

PERFORMANCE DATA

Series Number	HID Equivalency		Lumens Delivered	Number of LEDs	System Watts	Lumens Per Watt 4K, Type 4	CCT/CRI	Voltage	Drivers / Current
	MH	HPS							
12L - 15	70w	70w	1,600	12	14	114	4000K/70	120-277V	1@350mA
12L - 20	100w	100w	2,200	12	21	110	4000K/70	120-277V	1@530mA
12L - 30	150w	150w	2,900	12	28	107	4000K/70	120-277V	1@700mA

EGRESS PERFORMANCE

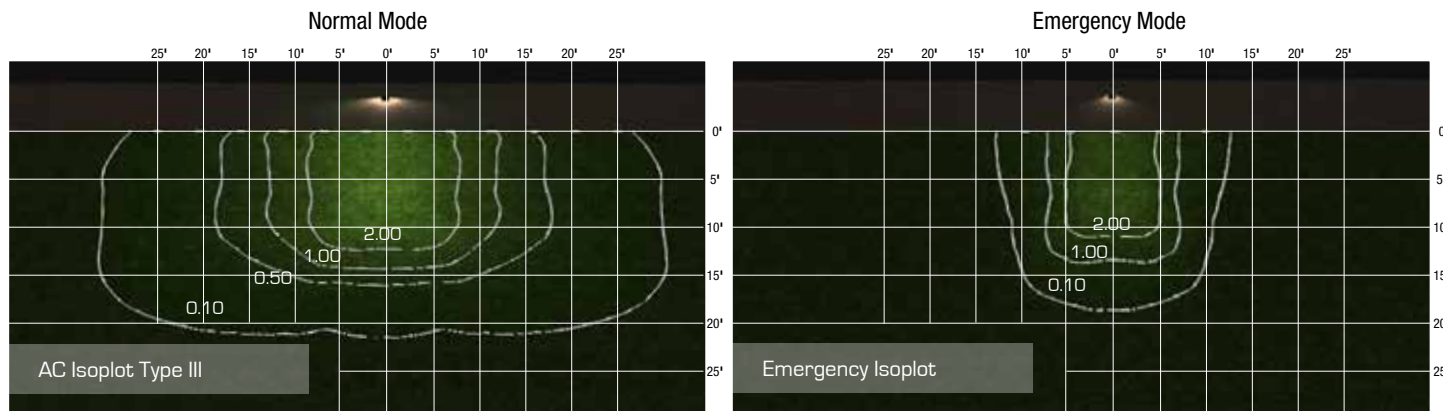

Provides Life Safety Code average illuminance of 1.0 fc. Assumes open space with no obstructions.
Diagrams for illustration purposes only, please consult factory for application layout.



DIMENSIONS

