


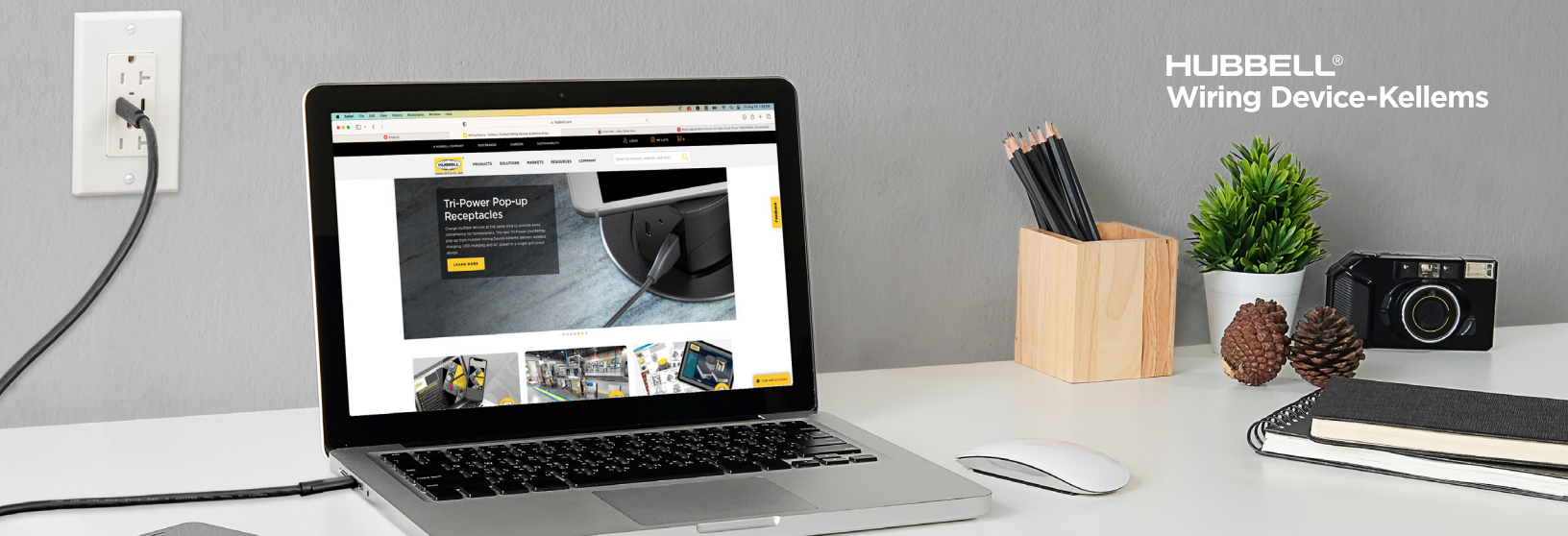

USB-C POWER DELIVERY RECEPTACLES

Now charge laptops and devices faster with high power USB!

Receptacles with fast charging USB-C® Power Delivery (PD) technology provide more power. Users can quickly charge laptops and other larger devices. Phones and tablets can charge up to three to four times faster.

These durable USB chargers/power receptacles deliver convenience, eliminating the need for power adapters while maintaining electrical outlets for higher current requirements.

The USB-C port marked PD (Power Delivery) provides up to 55W of output. The additional Type C or Type A port supports USB BC 1.2. Commercial and Hospital Grade versions are available in various colours.

Features

- Power Delivery USB-C port provides up to 20V, 55W output
- Additional C or A port delivers up to 1.5A/5V, up to 7.5W
- Heavy-duty stainless-steel USB ports rated for 10,000 cycles
- Duplex 125 VAC power receptacles available in 15A or 20A models
- Receptacles feature patented Hubbell tamper-resistant technology

Applications

- | | |
|----------------|---------------|
| • Hospitals | • Hotels |
| • Universities | • Commercial |
| • Institutions | • Home Office |



MORE POWER, LESS HEAT

Gallium Nitride (GaN) technology with optimized electronic efficiency reduces size and heat, allowing more power

USB-C Power Delivery Receptacles

USB Charger Type C

Description	Colour	Commercial Grade		Hospital Grade	
		15A 125V	20A 125V	15A 125V	20A 125V
Two Type C port configurations, (1) USB-C® Power Delivery port with up to 55W output and (1) USB-C Convenience port 1.5A, 5V output, Tamper-Resistant duplex receptacle, USB ports rated 10,000 cycles.	Black	USB15CPDBK	USB20CPDBK	USB8200CPDBK	USB8300CPDBK
	Brown	USB15CPD	USB20CPD	USB8200CPD	USB8300CPD
	Gray	USB15CPDGY	USB20CPDGY	USB8200CPDGY	USB8300CPDGY
	Ivory	USB15CPDI	USB20CPDI	USB8200CPDI	USB8300CPDI
	Light Almond	USB15CPDLA	USB20CPDLA	USB8200CPDLA	USB8300CPDLA
	White	USB15CPDW	USB20CPDW	USB8200CPDW	USB8300CPDW
	Red	-	-	USB8200CPDR	USB8300CPDR



USB15CPDBK



USB15CPD



USB15CPDGY

USB Charger Combination Type A & C

Description	Colour	Commercial Grade		Hospital Grade	
		15A 125V	20A 125V	15A 125V	20A 125V
(1) USB-C Power Delivery port with up to 55W output and (1) USB Type-A Convenience port 1.5A, 5V output, Tamper-Resistant duplex receptacle, USB ports rated 10,000 cycles.	Black	USB15ACPDBK	USB20ACPDBK	USB8200ACPDBK	USB8300ACPDBK
	Brown	USB15ACPD	USB20ACPD	USB8200ACPD	USB8300ACPD
	Gray	USB15ACPDGY	USB20ACPDGY	USB8200ACPDGY	USB8300ACPDGY
	Ivory	USB15ACPD	USB20ACPD	USB8200ACPD	USB8300ACPD
	Light Almond	USB15ACPDLA	USB20ACPDLA	USB8200ACPDLA	USB8300ACPDLA
	White	USB15ACPDW	USB20ACPDW	USB8200ACPDW	USB8300ACPDW
	Red	-	-	USB8200ACPDR	USB8300ACPDR



USB15ACPD



USB15ACPDLA



USB15ACPDW



USB8200ACPDR



©2024 Hubbell Incorporated. All rights reserved. Hubbell and the Hubbell logo are registered trademarks or trademarks of Hubbell Inc.
All other trademarks are the property of their respective owners.

Hubbell Canada | 870 Brock Rd S, Pickering, ON L1W 1Z8
hubbell.ca | 800-465-7051

