


**Low Profile Surface Mount Downlighting**

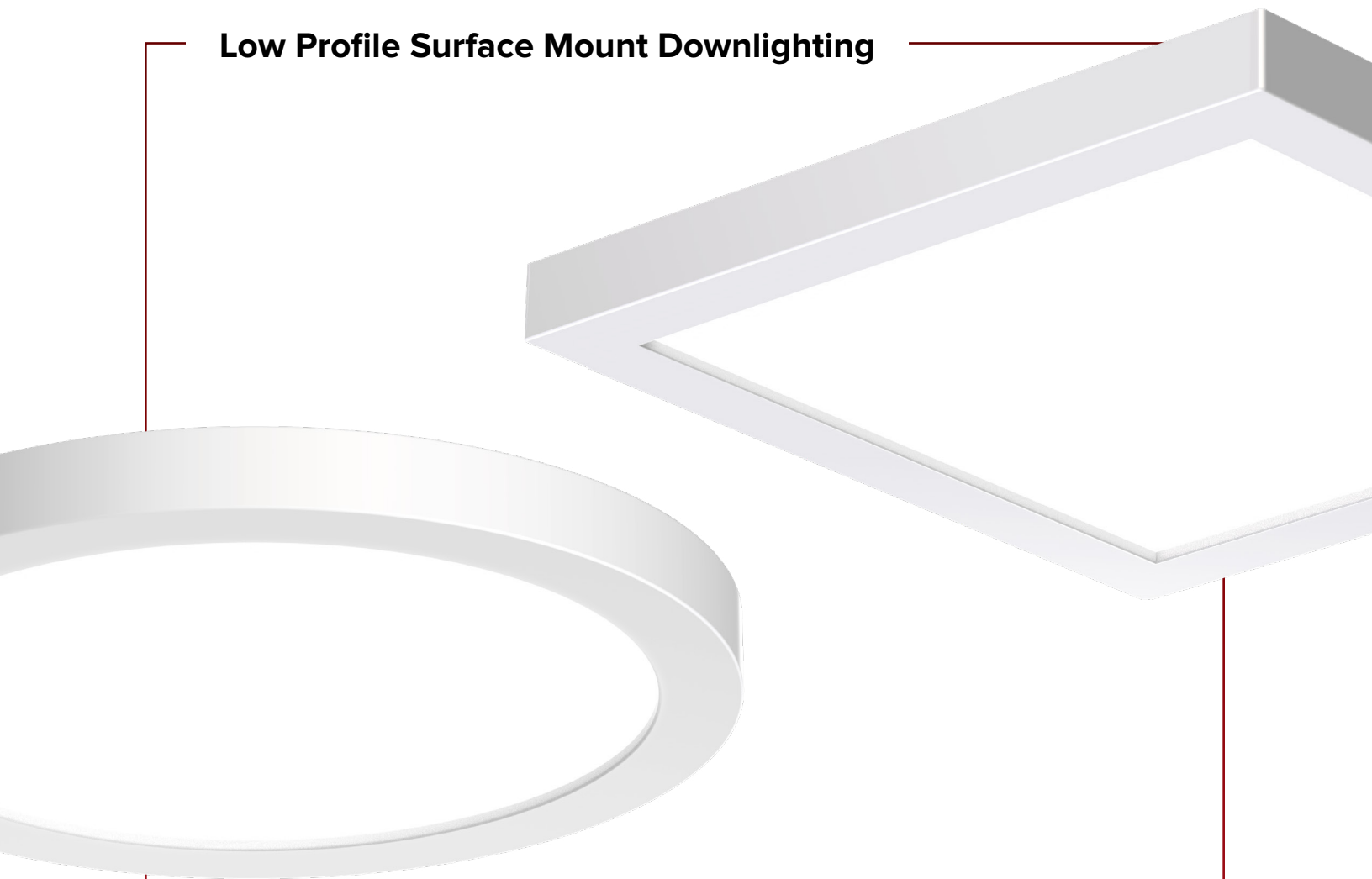

**LITEBOX<sup>®</sup>**  
**edge-lit**

# LITEBOX<sup>®</sup>

## edge-lit

### Low Profile Surface Mount Downlighting

LiteBox<sup>®</sup> Edge-Lit is a low-profile surface mount downlight family that affordably combines LED edge-lit technology and contemporary appearance with ease of installation and functional versatility. The family is available in 4", 6" or 8" round or square apertures with 750-1750 delivered lumen range.



#### Applications

- Hospitality - Restaurants, Hotels, Gyms
- Multi-Family - Condos, Townhouses, Apartments
- Healthcare - Rehab, Retirement Home



#### Appearance

- ½" profile with no exposed fasteners
- Available in 4", 6", or 8" round or square apertures



#### Simple Install

- Direct Mount integral driver uses a quick snap mounting plate that can be installed on common J-Boxes
- Remote Mount uses a convenient 3 ½" sleeve that can be installed into any space using a standard 3 ½" hole saw
- No housing required



#### Versatility

- Universal 120-277V with 0-10V/Triac/ELV Dimming
- Triac/ELV dimming to 5%; Dim to Off when using 0-10V
- Fixed CCT models in 3000K and 3500K, 80 CRI
- Switchable CCT models allow 4 CCTs (27/30/35/40K), 90 CRI







LiteBox® Edge-Lit is ideal for a wide range of spaces, including multi-family residential, offices, healthcare facilities, hospitality and other commercial spaces including wet location applications.



Hospitality



Multi-family




Office



Wet Location



Commercial

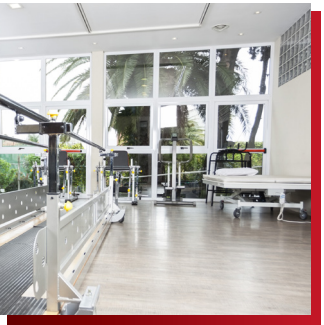


Healthcare






## Appearance

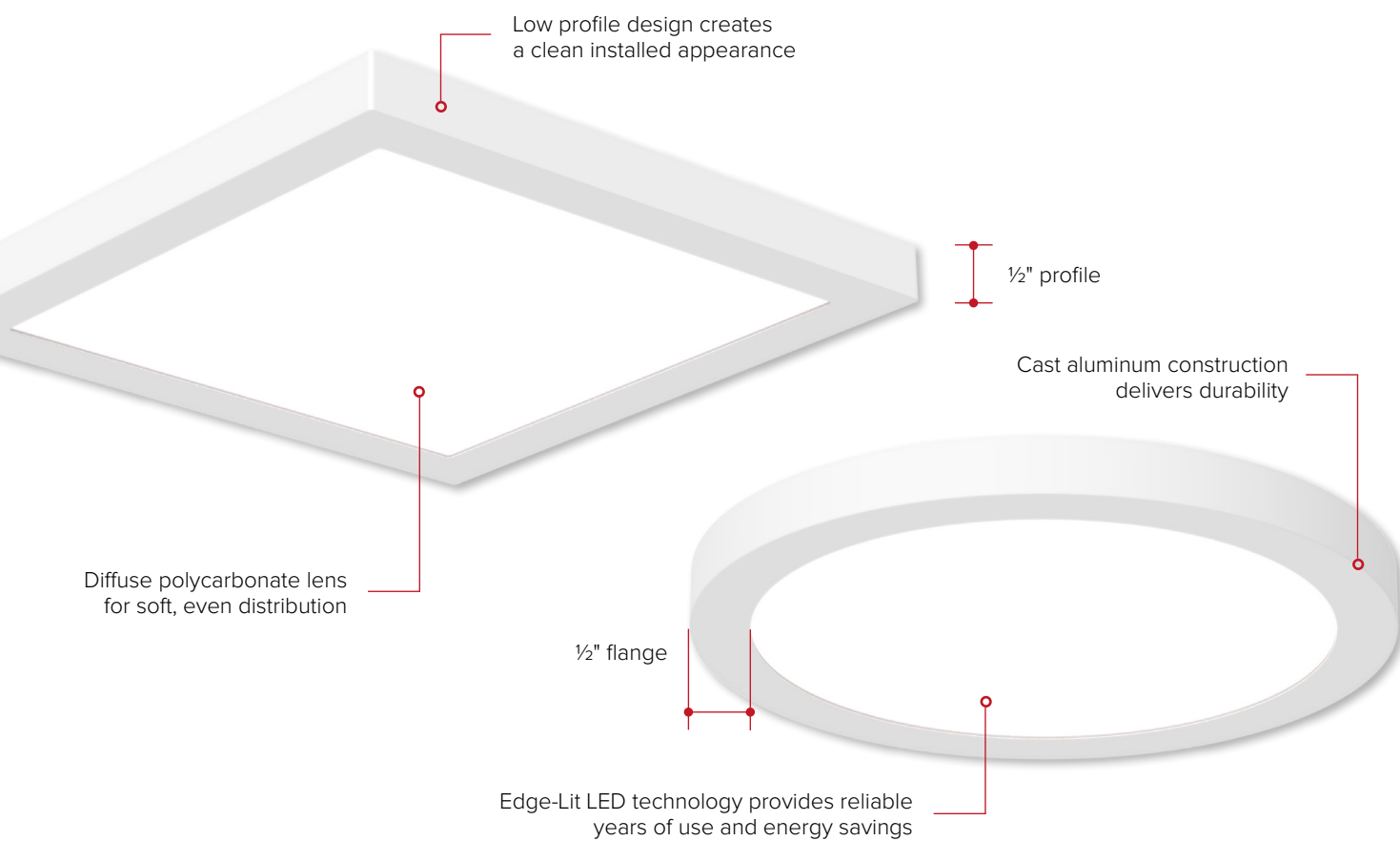

## Simple Install




### Direct J-Box Mount

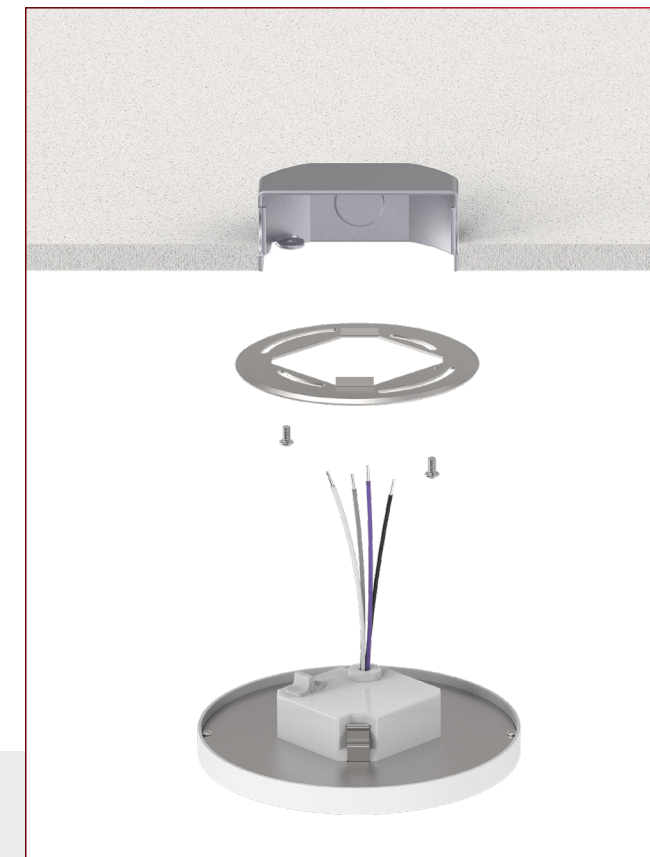

- Fits most standard 3 1/2" or 4" octagonal and round J-Boxes
- Can be used with Fire Rated J-Boxes
- IC rated for direct contact with insulation

### Remote J-Box Mount

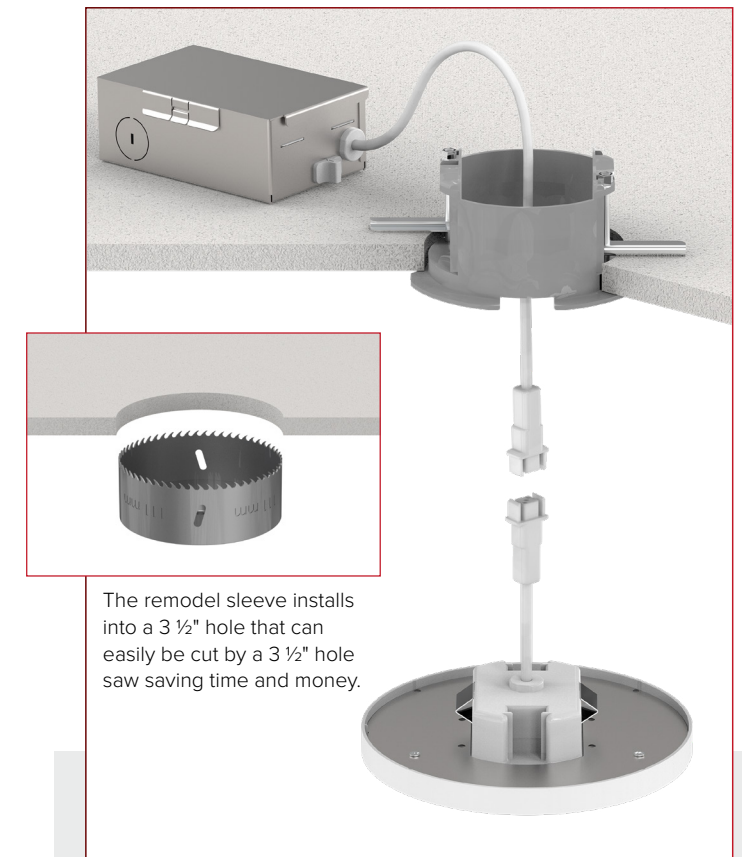

- Remote driver J-Box included
- Ideal for remodel IC rated applications
- Can be used with EM Accessory


### LiteBox Edge-Lit Decorative Color Trims (Non-Conductive)

LiteBox Edge-Lit decorative color trims are available in White, Black, Silver and Brushed Oil Rubbed Bronze. They provide a unique look to the LiteBox Edge-Lit fixture. The trims are made of high quality polymer making them easy to install onto the fixture and provides a non-conductive dead front for the applications requiring it.




### Snap Install

- Easy snap install regardless of mounting
- All Remote J-Box mount use the same 3 1/2" round ceiling cutout size and remodel sleeve

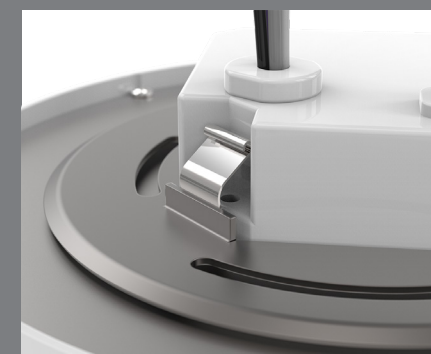

### Square Alignment

- J-Box mounting plate and remodel sleeve can be adjusted
- No need to cut precise holes to ensure square fixture alignment

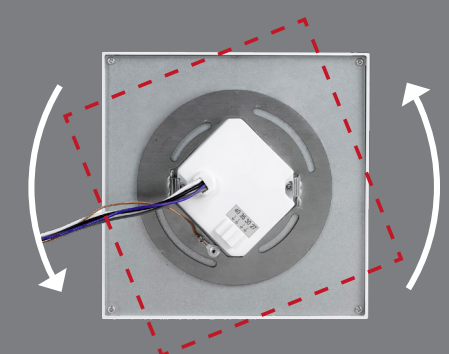

# Fixed CCT LBSE

The Fixed CCT (LBSE) is available in 30K or 35K with 80 CRI. It provides a cost effective, easy to install solution with a higher efficacy.

### Features

- 30K or 35K
- 80 CRI
- ENERGY STAR®

### Certifications

3000K

3500K

# Switchable CCT LBSES

The LiteBox Edge-Lit Switchable CCT (LBSES) can be field configured to 27K, 30K, 35K, or 40K with a simple switch. This allows flexibility during and after initial installation. The LBSES has enhanced color rendering with 90 CRI and is Title 24 JA8 compliant.

### Features

- 27K / 30K / 35K / 40K
- 90 CRI
- ENERGY STAR® / Title 24 JA8

### Certifications

2700K

3000K

3500K

4000K

## Versatility



## Voltage & Dimming

Each LiteBox Edge-Lit product comes standard with universal 120-277V and a combination of 3 dimming protocols eliminating the need for multiple SKUs.



Hubbell offers a variety of compatible wall dimmers including wireless solutions. For more information, visit [www.hubbell.com](http://www.hubbell.com).

Dimming Compatibility**		
0-10V	Hubbell Control Solutions	RSD710-UNV-WV PSD710-UNV-WV
Triac	Hubbell Control Solutions	RSDL06-120-WVLT
ELV	Hubbell Control Solutions	RSDE06-120-WVL

\*\* For a full list of recommended compatible dimmers by Hubbell and other manufacturers, refer to product specification sheets at [www.prescolite.com](http://www.prescolite.com).

## EM Accessory

UL 924 Compliant providing 90 minutes of emergency lighting

Accessory Kit includes EM remote J-Box and ring assembly with integral test switch/indicator


Requires remote J-Box mount (RM)




## Extension Cable Accessories

Universal extension cables are available in 12" and 24" lengths for use with Remote Mount (RM) models to allow varied installation distances.

Dimension Overview

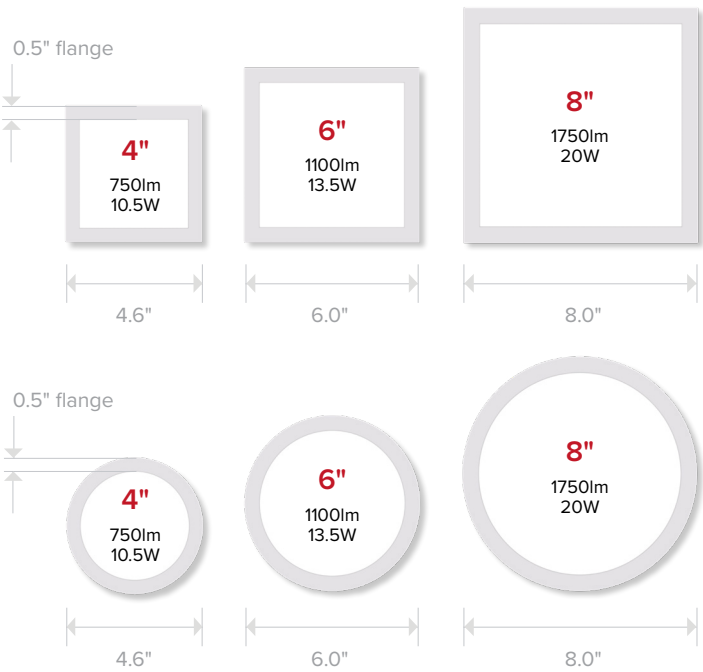

Dimension Details

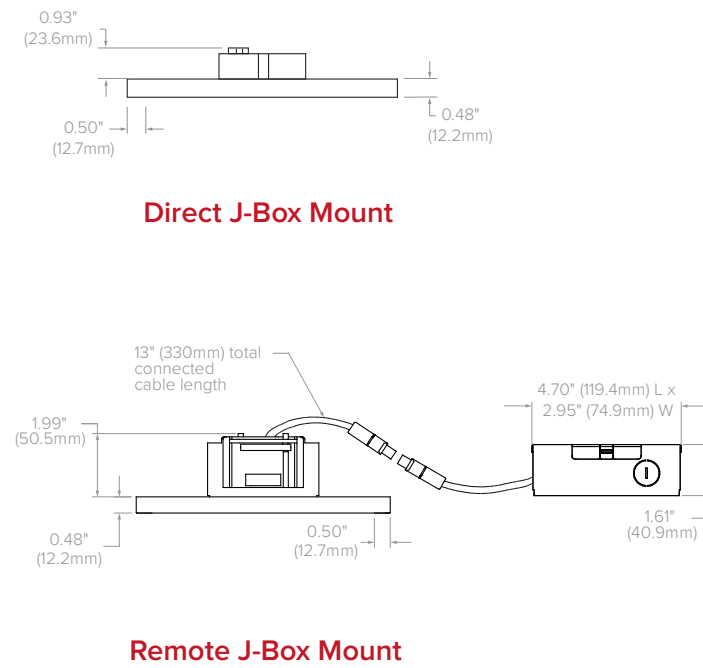


J-Box Compatibility





LBSE/LBSES Direct J-Box Mount is compatible with many standard 3-½" and 4" octagonal and round J-Boxes with a 1-½" minimum depth. Fire rated J-Boxes may also be used.



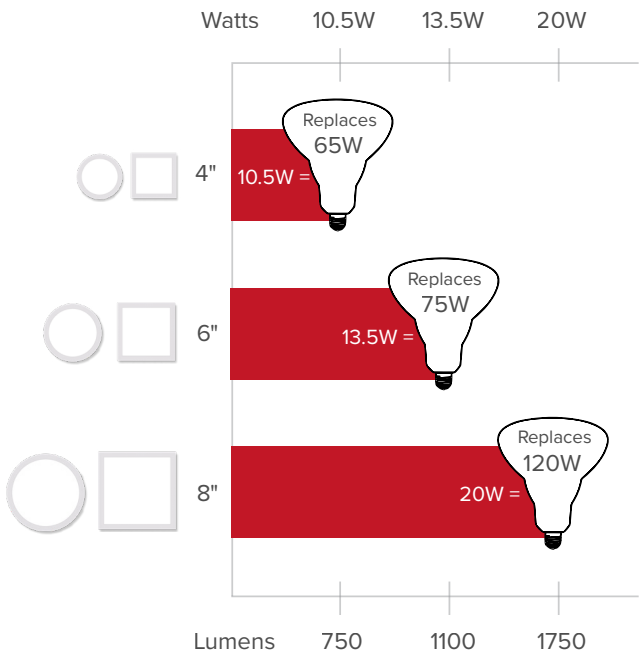





Save Energy, Reduce Costs

Replacing incandescent lamps with long-life Edge-Lit LEDs significantly reduces energy consumption and maintenance costs.



Direct J-Box Mount	LBSES - LiteBox® Edge-Lit							
	Shape	Aperture	Catalog Number	Lumens	Wattage	LPW	CCT	CRI
		4"	LBSES-4RD-CS9-WH	761	9.9	77	Switchable 27/30/35/40K	90
		6"	LBSES-6RD-CS9-WH	1178	13.1	90		
		8"	LBSES-8RD-CS9-WH	1754	19.3	91		
		4"	LBSES-4SQD-CS9-WH	757	10.0	76		
		6"	LBSES-6SQD-CS9-WH	1076	13.0	83		
		8"	LBSES-8SQD-CS9-WH	1770	20.0	89		
	LBSE - LiteBox® Edge-Lit							
		4"	LBSE-4RD-30K8-WH	783	10.4	75	30K	80
LBSE-4RD-35K8-WH			846	10.4	81	35K		
6"		LBSE-6RD-30K8-WH	1144	12.9	89	30K		
		LBSE-6RD-35K8-WH	1237	12.9	96	35K		
8"		LBSE-8RD-30K8-WH	1825	20.0	91	30K		
		LBSE-8RD-35K8-WH	1973	20.0	99	35K		
	4"	LBSE-4SQD-30K8-WH	753	10.1	75	30K		
		LBSE-4SQD-35K8-WH	813	10.1	81	35K		
	6"	LBSE-6SQD-30K8-WH	1048	13.0	81	30K		
		LBSE-6SQD-35K8-WH	1133	13.0	87	35K		
	8"	LBSE-8SQD-30K8-WH	1669	20.0	83	30K		
		LBSE-8SQD-35K8-WH	1804	20.0	90	35K		

Remote J-Box Mount	LBSES - LiteBox® Edge-Lit							
	Shape	Aperture	Catalog Number	Lumens	Wattage	LPW	CCT	CRI
		4"	LBSES-4RD-RM-CS9-WH	761	9.9	77	Switchable 27/30/35/40K	90
		6"	LBSES-6RD-RM-CS9-WH	1178	13.1	90		
		8"	LBSES-8RD-RM-CS9-WH	1754	19.3	91		
		4"	LBSES-4SQD-RM-CS9-WH	757	10.0	76		
		6"	LBSES-6SQD-RM-CS9-WH	1076	13.0	83		
		8"	LBSES-8SQD-RM-CS9-WH	1770	20.0	89		
	LBSE - LiteBox® Edge-Lit							
		4"	LBSE-4RD-RM-30K8-WH	783	10.4	75	30K	80
			LBSE-4RD-RM-35K8-WH	846	10.4	81	35K	
		6"	LBSE-6RD-RM-30K8-WH	1144	12.9	89	30K	
			LBSE-6RD-RM-35K8-WH	1237	12.9	96	35K	
		8"	LBSE-8RD-RM-30K8-WH	1825	20.0	91	30K	
			LBSE-8RD-RM-35K8-WH	1973	20.0	99	35K	
		4"	LBSE-4SQD-RM-30K8-WH	753	10.1	75	30K	
			LBSE-4SQD-RM-35K8-WH	813	10.1	81	35K	
		6"	LBSE-6SQD-RM-30K8-WH	1048	13.0	81	30K	
			LBSE-6SQD-RM-35K8-WH	1133	13.0	87	35K	
		8"	LBSE-8SQD-RM-30K8-WH	1669	20.0	83	30K	
LBSE-8SQD-RM-35K8-WH			1804	20.0	90	35K		
Emergency Accessory Kits								
Shape	Aperture	Catalog Number	For Use With					
	4"	LBSE-4RD-EM (WH OR BL)	LBSE/LBSES-4RD-RM					
	6"	LBSE-6RD-EM (WH OR BL)	LBSE/LBSES-6RD-RM					
	8"	LBSE-8RD-EM (WH OR BL)	LBSE/LBSES-8RD-RM					
	4"	LBSE-4SQD-EM (WH OR BL)	LBSE/LBSES-4SQD-RM					
	6"	LBSE-6SQD-EM (WH OR BL)	LBSE/LBSES-6SQD-RM					
	8"	LBSE-8SQD-EM (WH OR BL)	LBSE/LBSES-8SQD-RM					





ARCHITECTURAL AREA LIGHTING

BEACON PRODUCTS

COLUMBIA LIGHTING

COMPASS

DUAL-LITE

HUBBELL CONTROL SOLUTIONS

HUBBELL OUTDOOR LIGHTING

KIM LIGHTING

KURT VERSEN

LITECONTROL

PRESCOLITE



701 Millennium Blvd. Greenville, SC 29607  
Tel 864.678.1000  
[www.prescolite.com](http://www.prescolite.com)

4/21

Copyright © 2020 Prescolite, a division of Hubbell Lighting, Inc. All rights reserved. Please refer to online specifications for most up-to-date content as specifications are subject to change without notice.