



LFX-LARAMIE SERIES



Shown with Narrow/Medium Distribution Optics – MTO versions



Shown with Wide Distribution Optics



Optional 7 pin NEMA twist lock photocell receptacle

High output, highly efficient LED floodlight with a variety of NEMA distributions for floodlighting applications including: large area, building facades, security and signage.

Features and Benefits:

- Replaces up to 1000w HID systems
- In stock for quick shipment
- Distributions: Wide, Medium, and Narrow; Stock versions Wide only
- Heat and impact resistant tempered glass lens
- Die-cast aluminum housing
- Yoke mount with 3 ft. SO cord
- Knuckle slipfitter mount (made-to-order only)
- 120-277V, 50/60Hz operation
- 347V-480V, 50/60Hz operation (made-to-order only)
- Dark bronze powder paint finish standard (consult factory for additional finishes)

More Info: www.hubbelloutdoor.com/products/floodlighting/



Performance Data - Stock

Series Number	Equivalency	Distribution Type	Lumens Delivered	Max Candle Power	Voltage	System Watts	Lumens Per Watt	CCT/CRI
LFX-345-4K-Y-7PR	1000w	Wide	34,773	15,398	120-277V	341	102	4000K/70
LFX-345-Y-7PR			35,125	15,554			103	5000K/70


MTO ordering information see specification sheet

LFX-LARAMIE EXTRA LARGE FLOODLIGHT







Photometrics - For additional photometric information and IES downloads, visit our web site at www.hubbelloutdoor.com

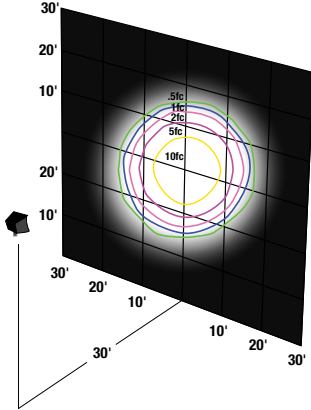

LFX-4L-345-5K7-N-UNV-X (Narrow)

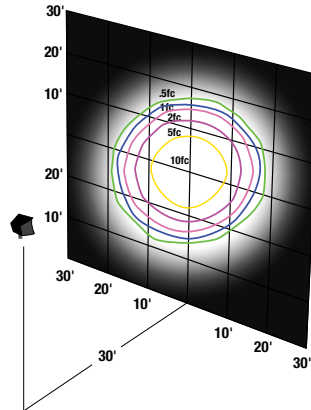


LFX-4L-345-5K7-M-UNV-X (Medium)

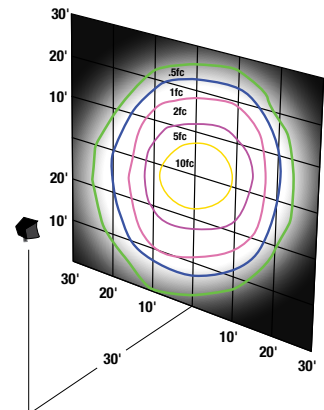

LFX-4L-345-5K7-W-UNV-X (Wide)

Dimensions

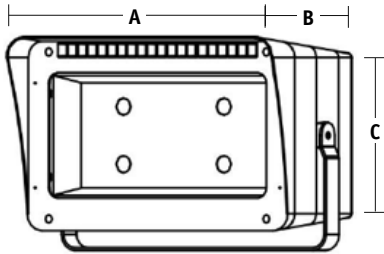

A	B	C
23.1"	14.6"	18.9"
587mm	370mm	480mm

Accessories - Order Separately

CATALOG NUMBER	DESCRIPTION
LFX-SPC	Vandal Shield Polycarbonate
LFX-TV	Top Visor
LFX-WG	Wire Guard