

- Weather-proof protection and cooling for network switches, PoE devices and equipment deployed outside facility
- Top mounted patch panel allows for efficient cable use and convenient patch cord installation
- Utilize shared accessories with RE-BOX®, QUADCAB® and IDF wall mount enclosures

FEATURES

- Active closed-loop cooling system to maintain equipment operating temperature range
- Keyed locking door compresses gasket to ensure lifetime weather rating
- Steel construction with a baked powder coat finish withstands outside environmental conditions

SPECIFICATIONS

- NEMA/IEEEMAC Types 4, 12 and 13
- 14 gauge steel
- ANSI 61 gray polyester powder coat
- 19" rack mount width
- Poured-in polyurethane door gasket

STANDARDS

- EIA/ECA 310-E
- UL and cUL
- NEMA 4/12/13

HUBBELL RE-BOX Industrial Enclosure with Cooling



Hubbell's Industrial RE-BOX® Enclosure with Cooling product offering allows deployment of network equipment outside of the data center while maintaining an appropriate temperature operating range. High quality manufacturing and installer friendly configurations ensure that equipment is safe from environmental factors and meet the many challenges of outside plant installations.

APPLICATIONS

- Parking garages
- Outdoor
- Roof top
- Fiber interconnect
- Security
- Campus



RE-BOX® VERTICAL ENCLOSURES

Requires: 1160 BTU air conditioner (IRAC1)
Includes: enclosure, 5U bracket, 4U patch panel bracket

| Height | Width | Depth | Rack Units | Catalog No. |
|--------|-------|-------|------------|-----------------|
| 24" | 24" | 12" | 9 | IR221APG |
| 36" | 24" | 12" | 9 | IR321APG |
| 48" | 24" | 12" | 9 | IR421APG |

STANDARD ENCLOSURES

Requires: 3000 BTU air conditioner (IRAC3)
Includes: enclosure, rail, 50 pack M6 cage nuts

| Height | Width | Depth | Rack Units | Catalog No. |
|--------|-------|-------|------------|-----------------|
| 24" | 24" | 24" | 12 | IR222APG |
| 36" | 24" | 24" | 19 | IR322APG |

FIBER KIT ENCLOSURE

Requires: 2000 BTU air conditioner (IRAC2)
Contents: enclosure, 2U equipment bracket, fiber patch panel kit, 20A power receptacle kit

| Height | Width | Depth | Rack Units | Catalog No. |
|--------|-------|-------|------------|-----------------|
| 24" | 14" | 16" | 2 | IR211AFK |

AIR CONDITIONERS

Requires: 110V service
Includes: A/C unit, mounting brackets

| BTU | Amp | Catalog No. |
|------|-----|--------------|
| 1160 | 4.3 | IRAC1 |
| 2000 | 4 | IRAC2 |
| 3000 | 6 | IRAC3 |

FLOOR STANDING KIT


Includes: (2) floor standing supports

| Height | Width | Depth | Catalog No. |
|--------|-------|-------|----------------|
| 18" | 24" | 12" | IRF1812 |
| 12" | 24" | 24" | IRF1224 |

ACCESSORIES

| Description | Catalog No. |
|---------------------------------|----------------|
| 4U patch panel mounting bracket | REK19 |
| 5U equipment mounting bracket | REKZ |
| Cement anchors 4pk | HPWRRRA |
| Bonding busbar | REKGB |

DIMENSIONS

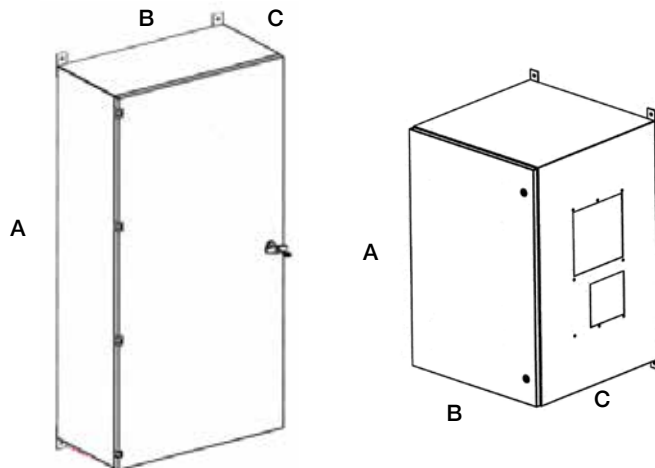

| Enclosure | Catalog No. | A | B | C |
|-----------|-------------|-----|-----|-----|
| Vertical | IR221APG | 24" | 24" | 12" |
| | IR321APG | 36" | 24" | 12" |
| | IR421APG | 48" | 24" | 12" |
| Standard | IR222APG | 24" | 24" | 24" |
| | IR322APG | 36" | 24" | 24" |
| Fiber | IR211AFK | 24" | 14" | 16" |