

CANOPY



- Low profile, rugged die-cast aluminum housing with corrosion resistant powder coat finish
- 3/4" conduit entry on top for pendant mounting
- Capable of mounting on a 3 - 3 1/2" junction box
- UV-stabilized acrylic prismatic refractor with self-retaining screws




STOCK SKUs	Wattage	Voltage	CCT/CRI	Lumens	LPW	Equivalency	Color
• SGC-F-20-4K	22.9W	120-277V	4000K/70	3224	141	100W	Bronze
• SGC-F-40-4K	41W	120-277V	4000K/70	5807	142	150W	Bronze
• SGC-F-40-4K-WH	41W	120-277V	4000K/70	5807	142	150W	White
• SGC-F-60-4K	59.9W	120-277V	4000K/70	8043	134	250W	Bronze


PERFORMANCE

2.0 fc
 1.0 fc
 0.5 fc


SGC-F-20-4K

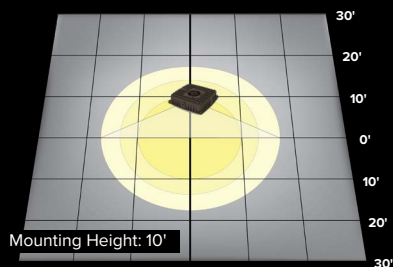



SGC-F-40-4K

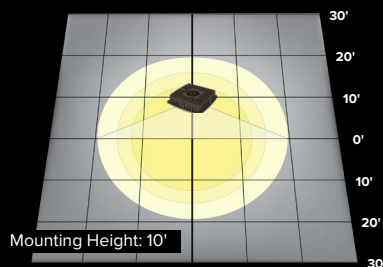

SGC-F-60-4K

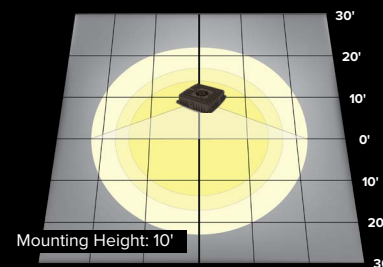

DIMENSIONS

 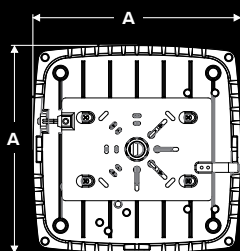

A	B	Weight
10.2"	3.6"	4.9 lbs.
260 mm	91 mm	2.2 kg

ADDITIONAL COLOR OPTIONS



WHITE HOUSING