



WGH LED SERIES

LED BUILDING MOUNT SERIES



WGH-30/40



WGH-110L/133L



WGH-225L

More Info: [Hubbell Outdoor Retractor Wallpacks](#)

WGH series provides multiple sizes/form factors and lumen packages for perimeter lighting for safety and security. Applications include: factories, warehouses, self storage and commercial buildings.

Features and Benefits:

- Replaces up to 400w HID systems
- In stock for quick shipment
- Designed for mounting heights from 10-20ft
- Impact resistant non-yellowing glass refractor
- Three 1/2" threaded conduit hubs for wiring or photocontrol connection (PC not included)
- 120-277V, 50/60Hz operation
- Dark bronze powder paint finish



Performance Data

Series Number	Equivalency	Distribution Type	Lumens Delivered	Voltage	System Watts	Lumens Per Watt	CCT/CRI
WGH-30-4K-U-S	150W	Type IV	3259	120-277V	28	116	4000K/80
WGH-30-5K-U-S			3326			118	5000K/80
WGH-40-4K-U-S	175W		4394		40	109	4000K/80
WGH-40-5K-U-S			4484			112	5000K/80
WGH-110L-4K-U-M	250W		6170		54	113	4000K/80
WGH-110L-5K-U-M			6372			116	5000K/80
WGH-225L-4K-U-L	400W		11838	102	116	4000K/80	
WGH-225L-4K-C-L			12818	347/480V	110	117	4000K/80
WGH-225L-5K-U-L			12134	120-277V	102	119	5000K/80






Performance

WGH-30-4K-U-S

ISOMETRIC FOOTCANDLE

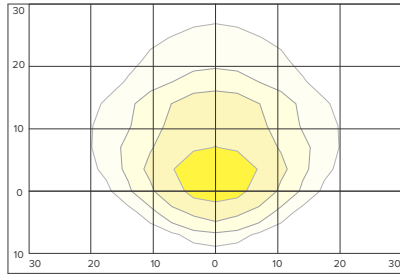


10' Mounting Height

- 5.0 FC
- 2.0 FC
- 1.0 FC
- 0.5 FC

WGH-40-4K-U-S

ISOMETRIC FOOTCANDLE

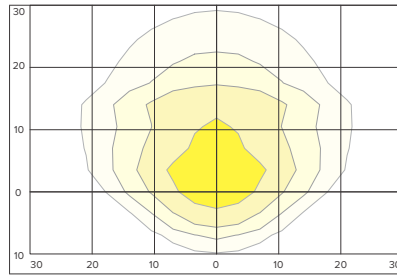


10' Mounting Height

- 5.0 FC
- 2.0 FC
- 1.0 FC
- 0.5 FC

WGH-110-4K-U-M

ISOMETRIC FOOTCANDLE

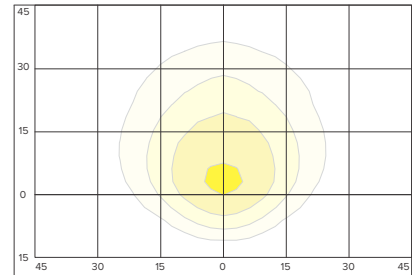


15' Mounting Height

- 5.0 FC
- 2.0 FC
- 1.0 FC
- 0.5 FC

WGH-133-4K-U-M

ISOMETRIC FOOTCANDLE

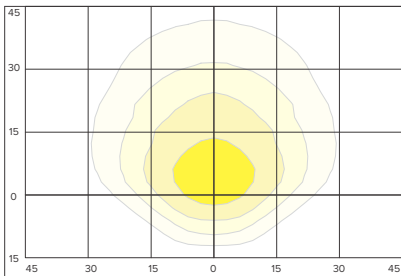


15' Mounting Height

- 5.0 FC
- 2.0 FC
- 1.0 FC
- 0.5 FC

WGH-225L-4K-U-L

ISOMETRIC FOOTCANDLE

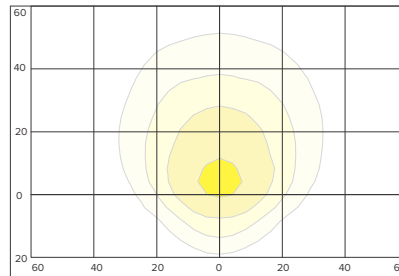


20' Mounting Height


- 5.0 FC
- 2.0 FC
- 1.0 FC
- 0.5 FC

Dimensions


SMALL

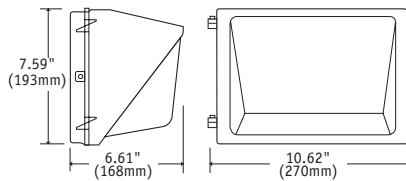

MEDIUM

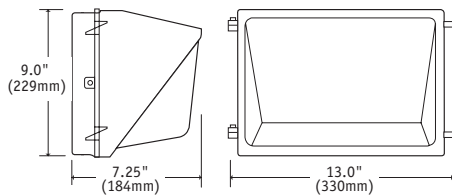

LARGE

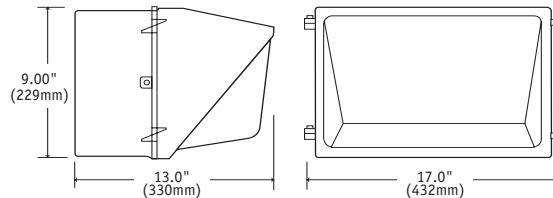

Accessories

CATALOG NUMBER	DESCRIPTION
PBT-1	Photocontrol, 120V
PBT-234	Photocontrol, 208, 240, 277V
SM106-SHIELD	Polycarbonate Shield for 110L size
SM708-GUARD	Wire Guard for 225L size

