

# WALL MOUNT


selection guide

architectural  
arealighting


BEACON  
design · performance · technology

HUBBELL®  
Outdoor Lighting

## ARCHITECTURAL BUILDING MOUNT

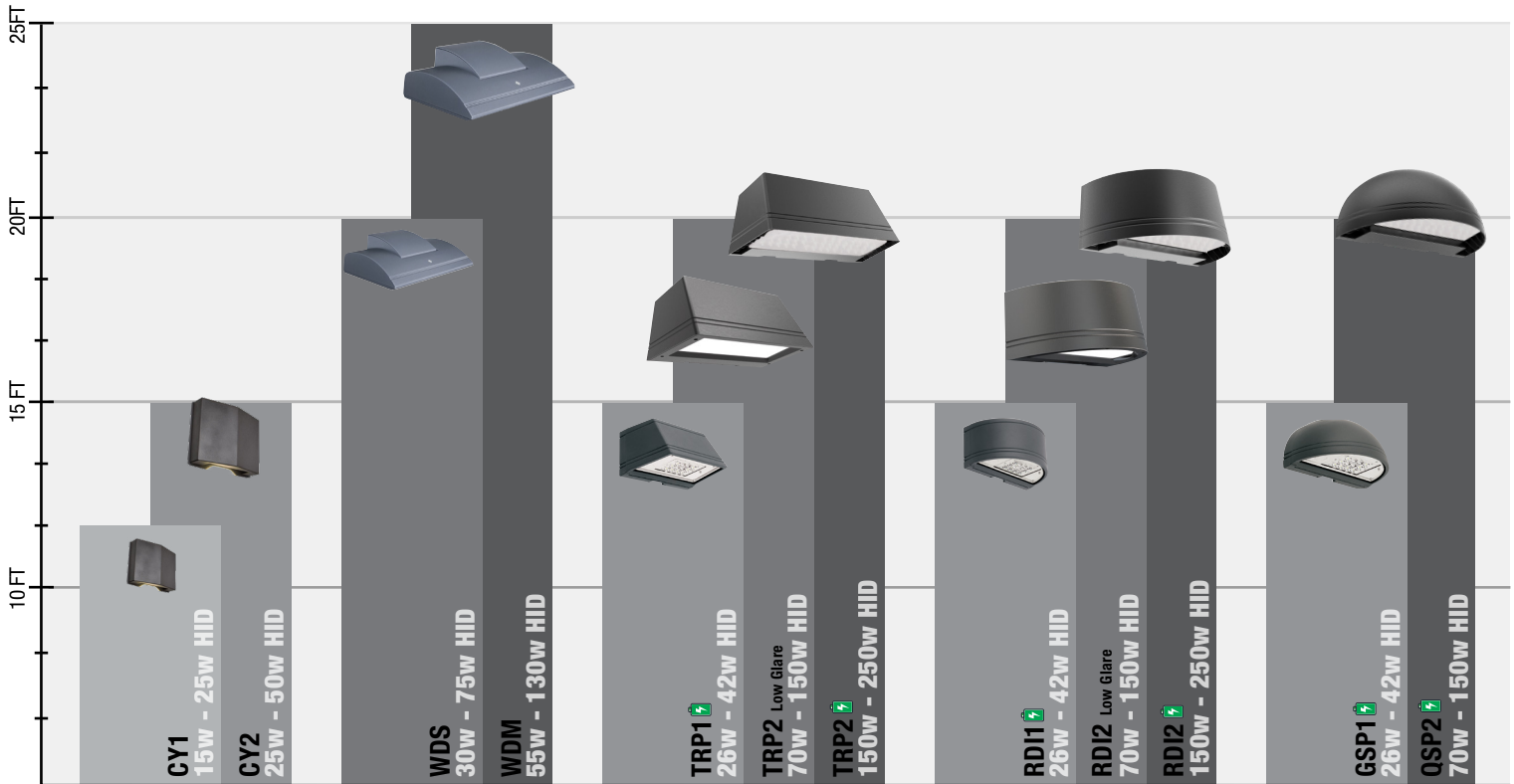

## COMMERCIAL WALL MOUNT

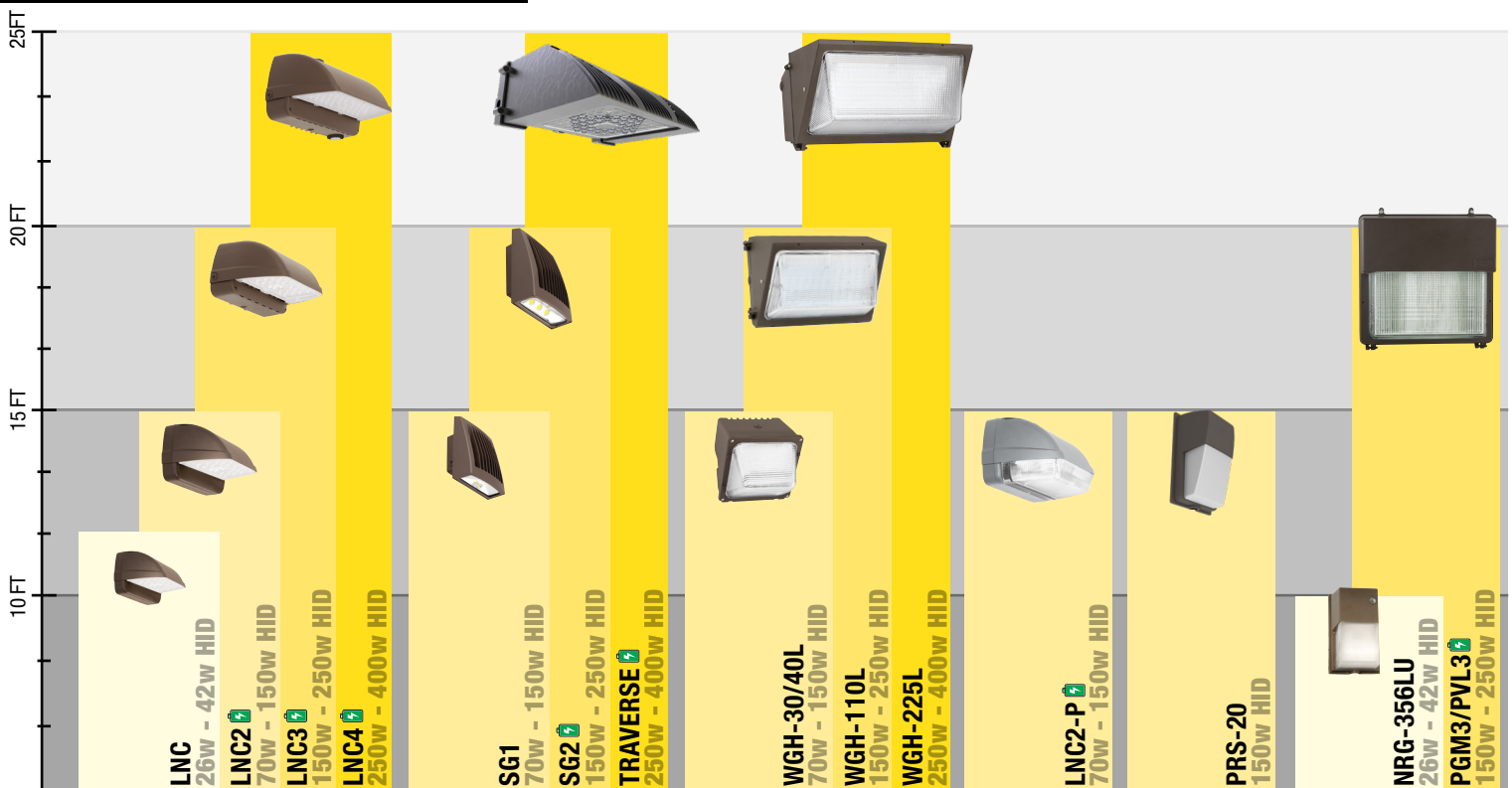

Stock items available. Please check [website](#) for availability.

= Battery Back up available

HUBBELL®  
Lighting

Copyright © 2020 Hubbell Lighting, Inc. All rights reserved. Rev. 06/11/2020  
701 Millennium Blvd. Greenville, SC 29607 | Tel 864.678.1000 | [www.hubbellighting.com](#)  
Please refer to online specifications for most up-to-date content as specifications are subject to change without notice.



# WALL MOUNT

## selection guide



### ARCHITECTURAL BUILDING MOUNT



Wall Mount Series	Mounting Height Range	Mounting Height Spacing	Delivered Lumens	System Watts	LPW	HID Equivalency	Approximate Energy Savings	CCT	Voltage	DLC Listing	Battery Backup	Photocell	Occupancy Sensor	SiteSync
WDM	15' - 25'	4 - 6 X	6,000 - 15,000	55 - 130W	Up to 145	250 - 400W+	75 - 80%	3K/4K/5K	120 - 480V	Standard & Premium	Yes	Button	Yes	Yes
WDS	10' - 20'	4 - 6 X	3,000 - 8,000	30 - 75W	Up to 130	100 - 250W	75 - 80%	3K/4K/5K	120 - 480V	Standard & Premium	Yes	Button	Yes	Yes
CY2	10' - 15'	4 - 6 X	2,500 - 5,000	25 - 50W	Up to 110	100 - 175W	75 - 75%	2.7K/3K/4K/5K	120 - 480V	Standard	Yes	Button	Yes	Yes
CY1	8' - 12'	4 - 6 X	1,500 - 2,500	15 - 25W	Up to 115	50 - 100W	75 - 75%	2.7K/3K/4K/5K	120 - 480V	Standard	No	Button	No	No
TRP2/RD12/QSP2	12 - 20'	4 - 6 X	3,700 - 10,800	28 - 87W	Up to 145	150 - 400W	75 - 80%	3K/4K/5K	120 - 480V	Standard & Premium	Yes	Button	Yes	Yes
TRP2/RD12 Low Glare	10 - 20'	3 - 4 X	3,000 - 9,000	21 - 62W	Up to 155	150 - 250W	75 - 80%	3K/4K/5K	120 - 480V	Standard & Premium	No	Button	Yes	Yes
TRP1/RD11/QSP1	8 - 15'	4 - 6 X	1,500 - 3,000	14 - 28W	Up to 120	70 - 150W	75 - 80%	3K/4K/5K	120 - 277V	Standard & Premium	Yes	Button	Yes	No

### COMMERCIAL WALL MOUNT



Wall Mount Series	Mounting Height Range	Mounting Height Spacing	Delivered Lumens	System Watts	LPW	HID Equivalency	Approximate Energy Savings	CCT	Voltage	DLC Listing	Battery Backup	Photocell	Occupancy Sensor	SiteSync
Traverse	15' - 25'	4 - 6 X	3,300 - 15,000	27 - 136W	Up to 125	150 - 400W+	75 - 80%	3K/4K/5K	120 - 480V	Standard & Premium	36L Only	Button	Yes	Yes
LitePak LNC4	15' - 25'	4 - 6 X	4,500 - 14,800	40 - 170W	Up to 115	175 - 400W+	65 - 75%	3K/4K/5K	120 - 480V	Standard & Premium	36L Only	Button and 7-Pin Receptacle	Yes	Yes
WGH-225L	15' - 25'	3 - 4 X	11,800 - 12,800	102 - 110W	Up to 120	400W	75 - 80%	4K/5K	120 - 480V	Standard	No	Button	No	No
Sling SG2	12 - 20'	3 - 4 X	5,500 - 8,100	50 - 80W	Up to 110	175 - 250W	70%	3K/4K/5K	120 - 480V	Standard & Premium	Yes	Button	Yes	Yes
LitePak LNC3	10 - 20'	4 - 6 X	3,000 - 7,600	28 - 83W	Up to 115	150 - 250W	70 - 80%	3K/4K/5K	120 - 480V	Standard & Premium	Yes	Button and 7-Pin Receptacle	Yes	Yes
LitePack LNC2	8 - 15'	4 - 6 X	1,600 - 4,300	14 - 42W	Up to 120	70 - 175W	75 - 80%	3K/4K/5K	120 - 480V	Standard & Premium	Yes	Button	Yes	Yes
LitePak LNC	8 - 12'	3 - 5 X	1,000 - 2,000	13 - 22W	Up to 95	50 - 100W	75 - 80%	3K/4K/5K	120 - 277V	Standard	No	Button	No	No
Sling SG1	8 - 15'	3 - 4 X	2,200 - 3,300	21 - 29W	Up to 115	100 - 150W	80%	3K/4K/5K	120 - 277V	Standard & Premium	No	Button	No	No
LMC	10 - 20'	4 - 6 X	3,800 - 7,300	35 - 70W	Up to 115	150 - 250W	70 - 80%	3K/4K/5K	120 - 480V	Standard	Yes	Button	Yes	No
PVL3	10 - 20'	3 - 4 X	3,500 - 6,800	32 - 72W	Up to 110	150 - 250W	75 - 80%	3K/4K/5K	120 - 480V	No	350mA Only	Button	Yes	No
WGH-110L	10 - 20'	3 - 4 X	6,200 - 6,400	54W	Up to 120	250W	75 - 80%	4K/5K	120 - 277V	Standard	No	Button	No	No
LNC2 Prismatic	8 - 15'	4 - 5 X	1,600 - 4,000	13 - 37W	Up to 130	70 - 175W	75 - 80%	3K/4K/5K	120 - 480V	Standard & Premium	Yes	Button	Yes	Yes
WGH-30/40L	8 - 15'	3 - 4 X	2,900 - 3,300	32W	Up to 105	150W	80%	4K/5K	120 - 277V	Standard	No	Button	No	No
PRS-20	8 - 15'	2 - 3 X	2,104 - 2,130	22W	Up to 96	150W	75%	4K/5K	120 - 277V	Standard	No	Button	No	No
NRG356	8 - 10'	2 - 3 X	1,800	17W	Up to 110	70W	75%	4K/5K	120 - 277V	Standard	No	Button	No	No