

MINI POWER CENTRES

HUBBELL

Wiring Products



When you have a power centre requirement, Hubbell has your solution. A complete line of industrial, commercial and hospital grade power centres. Design what you need to suit your specific application requirements.

Hubbell's extruded aluminum design provides rugged service while maintaining an attractive appearance. Fully CSA and/or UL listed.

Hubbell custom power centre options could include surge protection, additional external grounds, breakers, pilot lights or lit rocker switches.



Power centres can be customized to include Hubbell's wide offering of receptacles including twist lock, surge suppression, styleline receptacles, standard duplex receptacles or modules such as RJ45 jacks, to name a few.

If it can be CSA or UL Certified, Hubbell can design and manufacture to suit your requirements.

Make an informed choice. Choose Hubbell power centres for your power requirements.

FEATURES

- Made in Canada
- Complete customized
- Build your own
- Surge protection
- Hospital, medical, commercial & industrial grades available

BENEFITS

- Short lead time on product
- Built to suit each application
- Pay for only what you need
- Protect your investment
- Select the proper protection



SAMPLE POWER CENTRE OPTIONS

CIRCUIT BREAKER

Circuit Breakers can be placed on the front face, top or side of the mini power centre.



PILOT LIGHT

Available with a 20A/125V or 15A/125V pilot light.



SWITCH

Available with a 20A /125V or 15A/125V lighted rocker switch.




CORD

Molded cord set is supplied as standard in 6', 10' and 15' lengths. Assembled cord set is also available for 6' to 30' lengths. Proper plug is supplied to match power rating.

The commonly used devices are shown below. Consult factory for applications involving other devices.



Duplex Standard Specification Grade

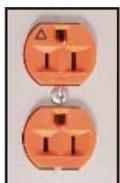

Duplex Isolated Ground Grade



Duplex Hospital Grade



 
Single Receptacle



Twist-Lock® 20A



Straightblade StyleLine®



Single Receptacle Round



Surge Suppression Receptacle



Face Mtg.



Top Mtg.



Side Mtg.



MOLDED FLEXIBLE CORD

Moulded cord & plug 125V 14/3 SJ 6' to 15'



ASSEMBLED FLEXIBLE CORD

Cord & plug 6' to 30ft 14/3SJ or 12/3SJ & plug to suit power rating.



JUNCTION BOX

Junction Box can be used for 1 to 4 circuits

MINI POWER CENTRE

Specifications

Power Centre	Extruded aluminum with painted or anodized finish 1.27mm thickness
Mounting Tabs	Steel
Rocker Switch	Non-metallic housing
Assy Screws	Steel
Breaker Switch	Non-metallic housing
Breaker	Push to reset, quick connect
Grommet	Non-metallic
Input Voltage	125VAC
Circuit Wire	#12 (20A) or #14 (15A) TEW solid copper conductor
Cord	14/3 SJTW stranded conductor 300V with 15A 125V or 12/3 SJTW stranded conductor 20A 250V complete with U-ground moulded plug with 2,3 or 5 meter cord Available in black or white (hospital grade)
Rocker Switch	16A 125V
Approvals	CSA certified or UL listed

Power Centre Length

Mini Power Centres are available from 9" to 10' long as standard. These units can be modified to accommodate custom fits or special mounting applications. Consult factory for more information.

Device Options

Available with a minimum of 3 outlets to a maximum of 12 outlets.

Standard colours are as follows:



Grey



White



Black



Ivory



Clear Anodized

Consult Factory for custom coloured paint and anodizing options.

STANDARD POWER CENTRE

Standard power centre is a commercial or industrial grade power centre that can use a variety of devices with many flexible mounting and customizable options.

- Allows Isolated Ground receptacles in a power centre with or without a cord
- Allows the use of a junction box
- Rated for 15A 125V, 15A 250V, 20A 125V or 20A 250V
- Allows multiple circuits
- Allows isolated ground with the use of a BX cable
- 1 – 32 outlets available
- 4 circuits available
- Maximum of 4 receptacles per circuit

Description	2 meter cord	3 meter cord	5 meter cord
2 Specification grade duplex receptacles	MCP46B	MCP410B	MCP415B
3 Specification grade duplex receptacles	MCP66B	MCP610B	MCP615B
4 Specification grade duplex receptacles	MCP86B	MCP810B	MCP815B

HOSPITAL GRADE

Hospital grade is a power centre that meets hospital grade requirements like external grounding and houses hospital grade devices.

- All devices are hospital grade (green dot)
- White extrusion and cord
- Supplied with external ground stud for direct grounding
- Meets Electrical Safety and Essential Electrical Systems in Health Care Facilities (Can/CSA – Z32-99)

Description	2 meter cord	3 meter cord	5 meter cord
2 Specification grade duplex receptacles	MCP46BHG	MCP410BHG	MCP415BHG
3 Specification grade duplex receptacles	MCP66BHG	MCP610BHG	MCP615BHG
4 Specification grade duplex receptacles	MCP86BHG	MCP810BHG	MCP815BHG

MEDICAL GRADE

Medical grade is a standard power centre that houses hospital grade devices.


- White extrusion and cord
- See Standard Power Centre for more details

Description	2 meter cord	3 meter cord	5 meter cord
2 Specification grade duplex receptacles	MCP46BS	MCP410BS	MCP415BS
3 Specification grade duplex receptacles	MCP66BS	MCP610BS	MCP615BS
4 Specification grade duplex receptacles	MCP86BS	MCP810BS	MCP815BS

**Does not meet Electrical Safety and Essential Electrical Systems in Health Care Facilities (Can/CSA-Z32-99)*

**No switch can be added*

EXTRUSION STYLE

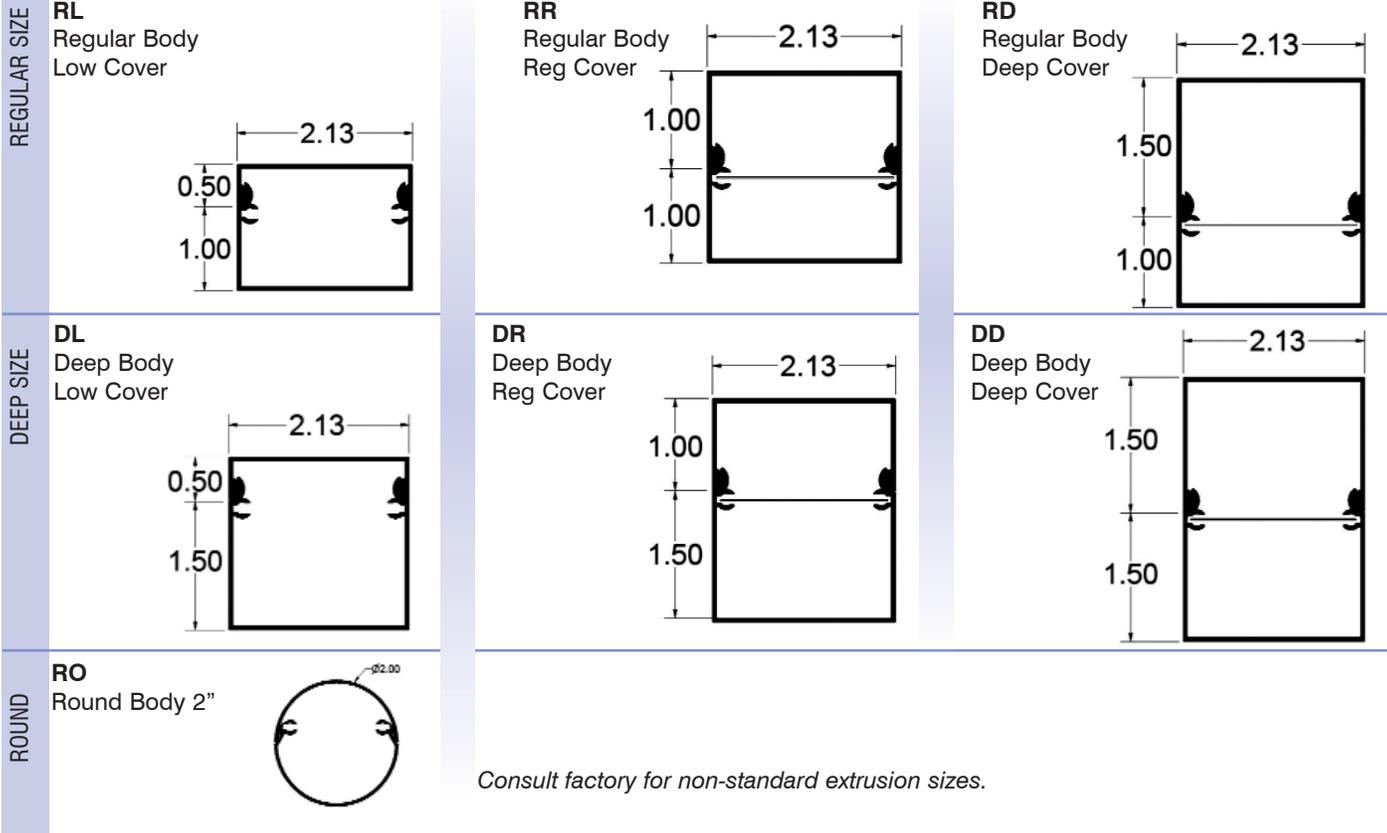

ORDERING INFORMATION - CUSTOM POWER CENTRE

		PC	RL	09	06	GY	Drawing # from factory
Item Type	Code	←	←	←	←	←	
Standard Power Centre	PC						
Extrusion Style	Code	←	←	←	←	←	
Regular Body, low cover	RL						
Regular Body, regular cover	RR						
Regular Body, deep cover	RD						
Deep Body, low cover	DL						
Deep Body, regular cover	DR						
Deep Body, deep cover	DD						
Round Extrusion 2" diameter	RO						
Product Size	Code	←	←	←	←	←	
Indicate length in feet	XX						
Indicate length in Inches	XX						
Colour	Code	←	←	←	←	←	
Grey	GY						
White	WH						
Black	BK						
Ivory	IV						
Clear Anodized	CA						
Custom Colour	OT						

Drawing # is supplied by the factory based on the above information.



© Hubbell Wiring Products
 Hubbell Canada Inc.

870 Brock Road South, Pickering, ON L1W 1Z8 • (905) 839-1138 • Fax: (905) 839-9108
 www.HubbellOnline.com

TECHNICAL SERVICES: 1-877-233-8324



h1956