


GROUNDING PRODUCTS

UL LISTED CHEMICAL GROUND ROD KITS

VERTICAL

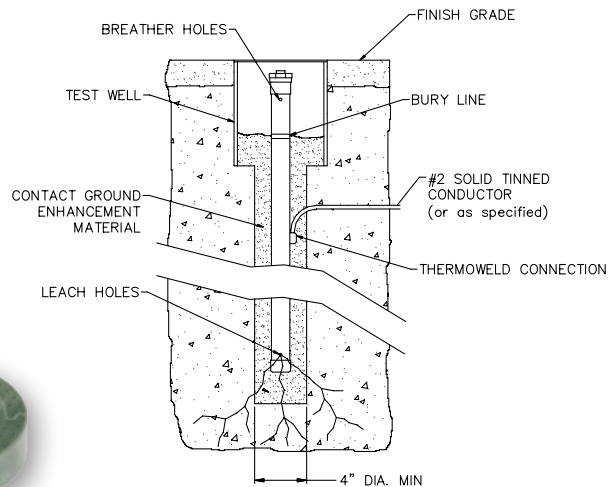

Section 8
Grounding Products

Catalog Number	Length	Inspection Well	Contact GF 25# Bag	Pigtail
38-6050-01	5'	No	~	5' - 4/0 STR
38-6050-31	5'	Yes	2	5' - 4/0 STR
38-6050-02	10'	No	~	5' - #2 SOL (Tinned)
38-6050-32	10'	Yes	4	5' - #2 SOL (Tinned)
38-6050-03	10'	No	~	5' - 2/0 STR
38-6050-33	10'	Yes	4	5' - 2/0 STR
38-6050-04	10'	No	~	5' - 4/0 STR
38-6050-34	10'	Yes	4	5' - 4/0 STR
38-6050-05	20'	No	~	5' - #2 SOL (Tinned)
38-6050-35	20'	Yes	8	5' - #2 SOL (Tinned)
38-6050-06	20'	No	~	5' - 2/0 STR
38-6050-36	20'	Yes	8	5' - 2/0 STR
38-6050-07	20'	No	~	5' - 4/0 STR
38-6050-37	20'	Yes	8	5' - 4/0 STR

• Other sizes and conductor types available. Contact the factory for details.

APPLICATION NOTES:

- Supplied Pre-Filled.
- Chemical Ground Rods are used in high resistivity soil conditions and when low resistance ground electrode systems are critical.
- Conductor is welded 18" down from the top.
- Outside diameter of copper tube is 2-1/8".