


BONDING/PIPE CLAMPS

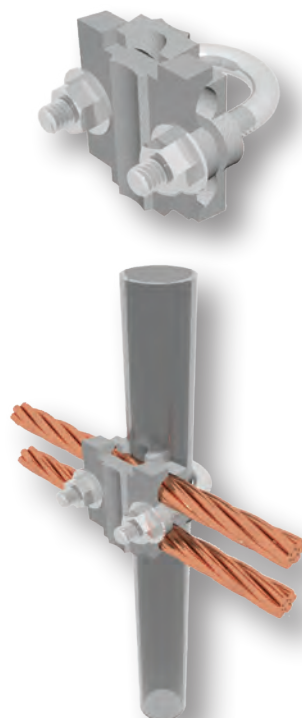

Pipe Range 0.375" - 1"

Cast U-Bolt Pipe Clamps for use with pipe or round bar.

- Manufactured from electroplated tinned bronze or aluminum.
- Wider conductor range; #6 through 250 MCM.
- Features "quick connect", bidirectional design.
- PEM® stud ensures a flush mounting surface.
- Suitable for Direct Burial.

Catalog Number	Material	Description
38-7420-00	Aluminum	1" U-Bolt Bonding Clamp - Fits .400" to 1.375" O.D. Pipe
38-7420-10	Bronze	1" U-Bolt Bonding Clamp - Fits .400" to 1.375" O.D. Pipe
38-7420-11	Tinned	1" U-Bolt Bonding Clamp - Fits .400" to 1.375" O.D. Pipe



Pipe Range 2" - 8"

Catalog Number	Material	Description
38-7421-00	Aluminum	2" U-Bolt Bonding Clamp - Fits 1.315" to 2.000" O.D. Pipe
38-7421-10	Bronze	2" U-Bolt Bonding Clamp - Fits 1.315" to 2.000" O.D. Pipe
38-7421-11	Tinned	2" U-Bolt Bonding Clamp - Fits 1.315" to 2.000" O.D. Pipe
38-7422-00	Aluminum	3" U-Bolt Bonding Clamp - Fits 1.900" to 3.000" O.D. Pipe
38-7422-10	Bronze	3" U-Bolt Bonding Clamp - Fits 1.900" to 3.000" O.D. Pipe
38-7422-11	Tinned	3" U-Bolt Bonding Clamp - Fits 1.900" to 3.000" O.D. Pipe
38-7423-00	Aluminum	4" U-Bolt Bonding Clamp - Fits 2.750" to 4.500" O.D. Pipe
38-7423-10	Bronze	4" U-Bolt Bonding Clamp - Fits 2.750" to 4.500" O.D. Pipe
38-7423-11	Tinned	4" U-Bolt Bonding Clamp - Fits 2.750" to 4.500" O.D. Pipe
38-7424-00	Aluminum	6" U-Bolt Bonding Clamp - Fits 4.500" to 6.750" O.D. Pipe
38-7424-10	Bronze	6" U-Bolt Bonding Clamp - Fits 4.500" to 6.750" O.D. Pipe
38-7424-11	Tinned	6" U-Bolt Bonding Clamp - Fits 4.500" to 6.750" O.D. Pipe
38-7711-00	Aluminum	8" U-Bolt Bonding Clamp - Fits 6.000" to 8.625" O.D. Pipe
38-7711-10	Bronze	8" U-Bolt Bonding Clamp - Fits 6.000" to 8.625" O.D. Pipe
38-7711-11	Tinned	8" U-Bolt Bonding Clamp - Fits 6.000" to 8.625" O.D. Pipe