

Straight Blade Devices



Heavy Duty, Specification Grade Receptacles

15A and 20A 125V and 250V Receptacles and Equipment Base Devices


TECH-SPEC®




Style		Receptacles						Equipment Base Devices - Clamp-Type, Back Wiring			
		Duplex			Decoratator	Single		Male		Female	
Rating	Color	Weather Resistant	Back and Side Wired	Back and Side Wired	Side Wired	Back and Side Wired	Side Wired	Color	Nylon Cup	Self-Grounding Strap	Nylon Cup
NEMA 5-15, 15A 125V 	Black	5262BBLKWR	5262BBLK	—	5242BLK	9252BLK	—	Black	—	5278G	—
	Brown	5262BNWR	5262BN	—	5242	9252	5251	White	5278	—	5279
	Gray	5262BGRYWR	5262BGRY	—	5242GRY	9252GRY	—				
	Ivory	5262BIWR	5262BI	5251I	5242I	9252I	5251I				
	Red	5262BREDWR	5262BRED	—	5242RED	—	—				
	White	5262BWWR	5262BW	5252W	5242W	9252W	—				
NEMA 5-20, 20A 125V 	Black	5362BBLKWR	5362BBLK	—	5342BLK	9352BLK	5351BLK	Black	—	5378G	—
	Brown	5362BNWR	5362BN	—	5342	9352BRN	5351	White	5378	—	5379
	Gray	5362BGRYWR	5362BGRY	—	5342GRY	9352GRY	—				
	Ivory	5362BIWR	5362BI	5351I	5342I	9352I	5351I				
	Red	5362BREDWR	5362BRED	—	5342RED	—	—				
	White	5362BWWR	5362BW	5352W	5342W	9352W	—				
NEMA 6-15, 15A 250V 								White	5678	5678G	5679
NEMA 6-20, 20A 250V 								White	5478	—	5479

Product Dimensions Inches (mm)


	Receptacle			Equipment Devices	
	Duplex	Decoratator	Single	Male	Female
A	4.06" (103.1)	4.06" (103.1)	4.06" (103.1)	1.84" (46.7)	1.84" (46.7)
B	3.28" (83.3)	3.28" (83.3)	3.28" (83.3)	2.00" (50.8)	2.00" (50.8)
C	1.38" (35.1)	1.36" (34.5)	1.38" (35.1)	2.50" (63.5)	2.50" (63.5)
D	0.92" (23.4)	1.03" (26.2)	0.92" (23.4)	1.61" (40.9)	1.47" (37.3)
E	2.68" (68.1)	2.75" (69.9)	1.78" (45.2)	1.55" (39.4)	1.31" (33.3)

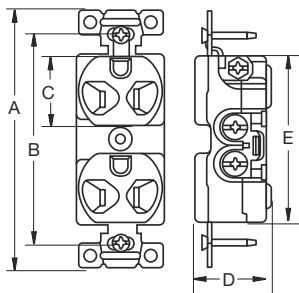


Duplex Receptacle

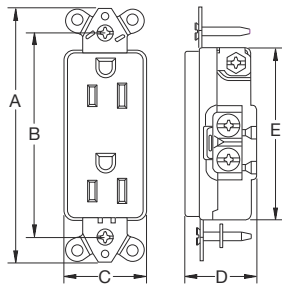


Duplex Receptacle

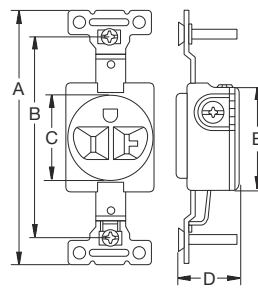

Single Receptacle

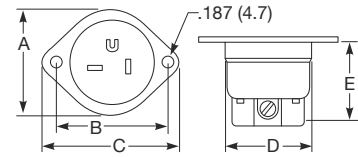

Male Equipment Device

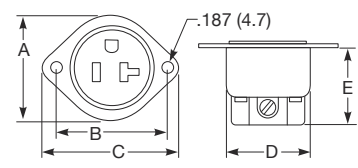

Female Equipment Device