

Straight Blade Devices

QUADPLEX® Receptacles and Cord Sets




- Accepts up to four straight or angle plugs
- Heavy duty, triple-wipe, high performance brass line contacts for excellent retention and conductivity
- Break-off tab for two-circuit wiring (except surge)
- Saves wiring and installation time
- "A" and "B" circuits molded into face for easy identification
- Easily removable knockouts for mounting to octagon concrete ring or box

QUADPLEX®

Mounts directly to 4" square or octagon boxes. No cover plate required. Can be retrofitted to 1 and 2-gang device boxes, mud rings on 4" boxes or 4 1/16" boxes using adapter plate. Rugged impact resistant construction. Break-off tabs for split circuit wiring (except surge units).

15A and 20A 125V Receptacles and Cord Sets

QUADPLEX®

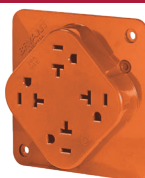

| Rating | Color | Standard | Color | Isolated Ground | Color | Surge Suppression Isolated Ground | 6 Foot Cord Sets, 12/3 SJO | | |
|-------------------------|---------------|-----------------|--------|------------------|---------------|-----------------------------------|----------------------------|------------------|-----------------|
| | | | | | | | Surge Suppression | GFCI | |
| NEMA 5-15, 15A 125V | Black | 1254BLK | Orange | 1254IGO | Blue Ivory | 1254SA 1254SIA | Ivory | T1254SI6A | — |
| | Brown | 1254B | | | | | Yellow | — | T1254GF6 |
| | Gray | 1254GY | | | | | | | |
| | Ivory | 1254I | | | | | | | |
| | Red | 1254R | | | | | | | |
| NEMA 5-20, 20A 125V | Black | 21254BLK | Orange | 21254HIGO | Blue Ivory | 21254SA 21254SIA | | | |
| | Brown | 21254B | | | | | | | |
| | Gray | 21254GY | | | | | | | |
| | Ivory | 21254I | | | | | | | |
| | Red | 21254R | | | | | | | |
| White | 21254W | | | | | | | | |

Note: See Section C for isolated ground and surge protection products.

Adapter Plates and Portable Boxes


| Color | Adapter Plates | | Portable Boxes | |
|--------|--------------------------------|-------------------|-----------------|-------------------------------|
| | For 1- and 2-Gang Device Boxes | For 4 1/16" Boxes | with Cord Grip | Feed-thru with Two Cord Grips |
| Black | ADAPBLK | — | 4SQBXBLK | 4SQBXFBLK |
| Blue | ADAPBLU | — | 4SQXBBLU | — |
| Brown | ADAPB | — | 4SQBXB | — |
| Gray | ADAPGRY | — | 4SQBXGRY | — |
| Ivory | ADAPI | ADAPIS | 4SQBXI | 4SQBXFI |
| Orange | ADAPO | — | 4SQBXO | — |
| Red | ADAPR | — | 4SQBXR | 4SQBXFR |
| White | ADAPW | — | 4SQBXW | — |




Product Dimensions Inches (mm)

| | Receptacle | Adapter Plate | Portable Box |
|---|---------------|---------------|---------------|
| A | 4.30" (109.2) | 4.78" (121.4) | 4.30" (109.2) |
| B | 3.38" (85.9) | 4.25" (108.0) | 4.05" (102.9) |
| C | 3.02" (76.7) | 3.38" (85.9) | 3.28" (83.9) |
| D | 0.92" (23.4) | 2.75" (69.9)* | 0.84" (21.3) |
| E | 0.10" (2.6) | 0.38" (9.5) | 0.75" (19.1) |
| F | — | 2.75" (6.9) | — |


Note: *Mounting dimensions for 4 1/16" adapter plate.

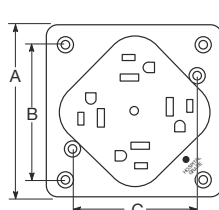

Receptacle

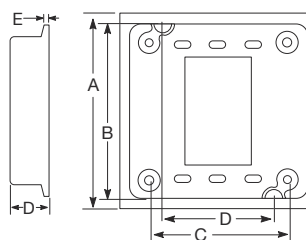

Adapter Plate

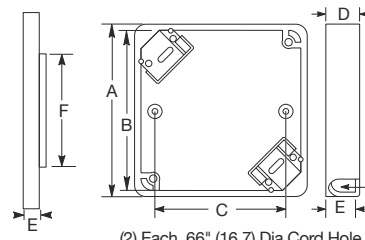

Portable Box