


Straight Blade Devices



Residential Grade Duplex and Decorator Receptacles

Best Solution for Residential 15A & 20A Branch Circuit Wiring

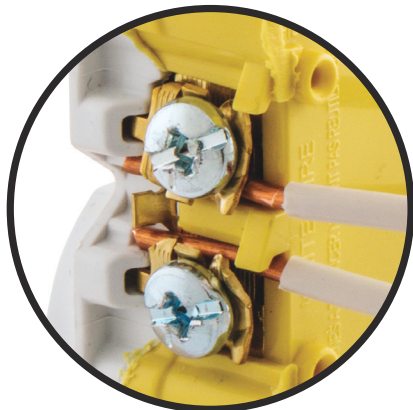

Fast and Secure



- 1** Strip the wire
- 2** Insert the wire
- 3** Clamp the connection

XClamp and Duplex Receptacles

- Eliminates the need to loop the wire
- External back-wire clamp for fast and easy installation of 15A & 20A branch circuits in residential applications
- Compression plates maximize holding power to provide a stronger, more secure connection
- Terminate up to 8 wires
- Accommodates #12 & #14 AWG wire
- Break-off tabs for switched receptacle applications
- Tamper-resistant shutter complies with NEC®

XClamp Duplex Receptacles

Description	Color	Catalog Number
Tamper-Resistant, 15A 125V, 2 Pole, 3 Wire Grounding, 20A Circuit Rated	Ivory	RR15SITRX
	Light Almond	RR15SLATRX
	White	RR15SWTRX




15A 125V Quick Thread TR Receptacles



Wiring		Push and Side Wired	Eight Push Wire Holes Only
Grounding		Self-Grounding	#14 AWG Only
Rating	Color	Catalog Number	Catalog Number
NEMA 5-15, 15A 125V	Black	RR15QBKTR	RR15QBKTR
	Brown	RR15QTR	RR15EQTR
	Gray	—	—
	Ivory	RR15QITR	RR15EQITR
	Light Almond	RR15QLATR	RR15EQLATR
	White	RR15QWTR	RR15EQWTR

15A 125V Duplex and Decorator Receptacles

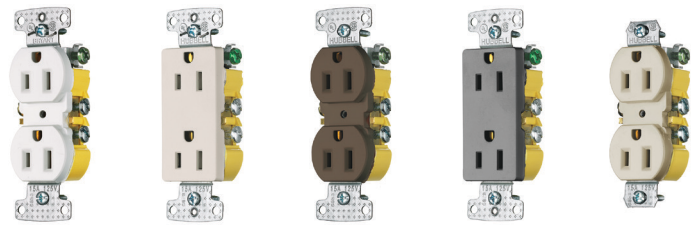

Wiring		Push and Side Wired		
Grounding		Self-Grounding	Grounding	
Rating	Color	Duplex	Decorator	Earless Duplex
NEMA 5-15, 15A 125V	Black	—	RRD15SBK	—
	Brown	RR15S	RRD15S	RR15K
	Gray	—	RRD15SGY	—
	Ivory	RR15SI	RRD15SI	RR15KI
	Light Almond	RR15SLA	RRD15SLA	—
	White	RR15SW	RRD15SW	RR15KW

15A 125V Duplex and Decorator Tamper-Resistant Receptacles



Wiring		Push and Side Wired		Eight Push Wire Holes Only, #14 AWG		Back and Side Wired	
Grounding		Self-Grounding	Grounding	Grounding	Self-Grounding	Self-Grounding	
Rating	Color	Decorator	Earless Duplex	Earless Decorator	Duplex	Decorator	
NEMA 5-15, 15A 125V	Black	RRD15SBKTR	—	RRD15KBKTR	RR15EBKTR	RRD15EBKTR	—
	Brown	RRD15SSTR	RR15KTR	RRD15KTR	—	RRD15ETR	—
	Gray	RRD15SGYTR	—	RRD15KGYTR	RR15EGYTR	RRD15EGYTR	—
	Ivory	RRD15SITR	RR15KITR	RRD15KITR	RR15EITR	RRD15EITR	DR15NLIV
	Light Almond	RRD15SLATR	RR15KLATR	RRD15KLATR	RR15ELATR	RRD15ELATR	DR15NLLA
	White	RRD15SWTR	RR15KWTR	RRD15KWTR	RR15EWTR	RRD15EWTR	DR15NLWH

Note: See page R-6 for tamper-resistant description.