

# Straight Blade Devices



## Triple Gripper® Extra Heavy Duty Industrial Plugs and Connectors



- Hand grip features wide-rib, non-slip design
- Double wall construction provides extra protection for internal components
- Universal cord grip design accepts .300 - .655 in. (7.6 – 16.6mm) cord without inserts or adapters
- Impact/chemical resistant, toughened nylon construction
- Face and body feature alignment keys for easy assembly
- Amperage, voltage and NEMA® configuration imprinted on face for easy identification





### Patented Triple Gripper®

Bryant's Tech-Spec® plugs and connectors represent some of the industry's most recognized products as well as one of the finest series of plugs and connectors on the market. The quality of the non-slip, wide-ribbed handgrip, heavy duty double wall housing and tough, impact/chemical resistant nylon construction are second to none. They are easy to assemble and automatically center and secure the cord as the assembly screws are tightened - no external clamps or additional screws are required. An elastomeric dust seal prevents dust, moisture and contaminants from entering the wiring chamber.

### 15A and 20A 125V and 250V Plugs and Connectors, 2-Pole 3-Wire Inches (mm)


TECH-SPEC®



Device Type			Plug			Connector		
Rating	Cord Diameter	Color	Nylon	Nylon/ Polymer	Corrosion- Resistant Nylon/Polymer	Nylon	Nylon/ Polymer	Corrosion- Resistant Nylon/Polymer
NEMA 5-15, 15A 125V 	.300"-.655" (7.6-16.6)	Black/White	<b>BRY5266NP</b>	—	—	<b>BRY5269NC</b>	—	—
	.245"-.655" (6.2-16.6)	Black Orange Yellow	—	<b>BRY5266NPB</b> <b>BRY5266NPOR</b> <b>BRY5266NPSY</b>	— — <b>BRY5266NPCR</b>	— — —	<b>BRY5269NCB</b> — <b>BRY5269NCSY</b>	— — <b>BRY5269NCCR</b>
	.300"-.655" (7.6-16.6)	Black/White	<b>BRY5366NP</b>	—	—	<b>BRY5369NC</b>	—	—
NEMA 5-20, 20A 125V 	.245"-.655" (6.2-16.6)	Yellow	—	<b>BRY5366NPSY</b>	<b>BRY5366NPCR</b>	—	<b>BRY5369NCSY</b>	<b>BRY5369NCCR</b>
	.300"-.625" (7.6-15.9)	Black/White	<b>BRY5666NP</b>	—	—	<b>BRY5669NC</b>	—	—
NEMA 6-15, 15A 250V 	.245"-.655" (6.2-16.6)	Yellow	—	<b>BRY5666NPSY</b>	—	—	—	—
	.300"-.625" (7.6-15.9)	Black/White	<b>BRY5466NP</b>	—	—	<b>BRY5469NC</b>	—	—
NEMA 6-20, 20A 250V 	.245"-.655" (6.2-16.6)	Yellow	—	<b>BRY5466NPSY</b>	—	—	<b>BRY5469NCSY</b>	—

### Product Dimensions Inches (mm)

	Plug	Connector
A	1.52" (38.6)	1.52" (38.6)
B	2.18" (55.4)	2.95" (74.9)
C	1.38" (35.1)	1.38" (35.1)

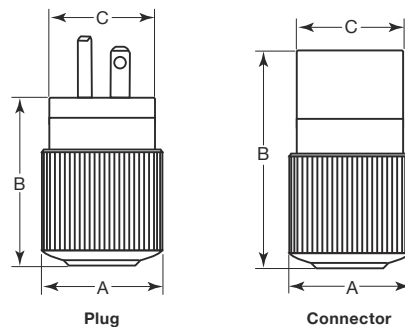

NEMA® is a registered trademark of the National Electrical Manufacturers Association.