


Straight Blade Devices


Residential Grade Plugs, Connectors, Taps and Adapters

Plugs and Connectors

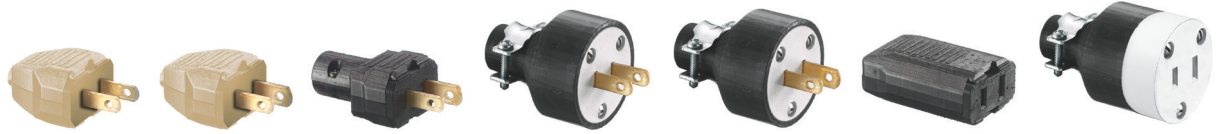

Device Type		Straight Plug				Straight Connector		
Rating	Color	Non-Polarized, Two Blade, Spt 1 and 2 Cord 18/2 and 16/2 AWG	Polarized, Two Blade, Spt 1 and 2 Cord 18/2 and 16/2 AWG	Polarized, Two Blade, Light Duty, Wire Range: #16-18 AWG, Up to .25 In. Diameter Cord	Non-Polarized, Two Blade, Heavy Duty, Wire Range: #14-18 AWG, Up to .33 In. Diameter Cord	Polarized, Two Blade, Heavy Duty, Wire Range: #14-18 AWG, Up to .33 In. Diameter Cord	Polarized, Two Blade, Light Duty, Wire Range: #16-18 AWG, Up to .25 In. Diameter Cord	Polarized, Two Blade, Heavy Duty, Wire Range: #14-18 AWG, Up to .33 In. Diameter Cord
NEMA 1-15, 15A 125V	Black Ivory White	— RP123I RP123W	— RP123PI RP123PW	RP101BK — RP101W	RP646 — —	RP648 — —	RP102BK — RP102W	RP649 — —

Plugs, Taps and Adapters

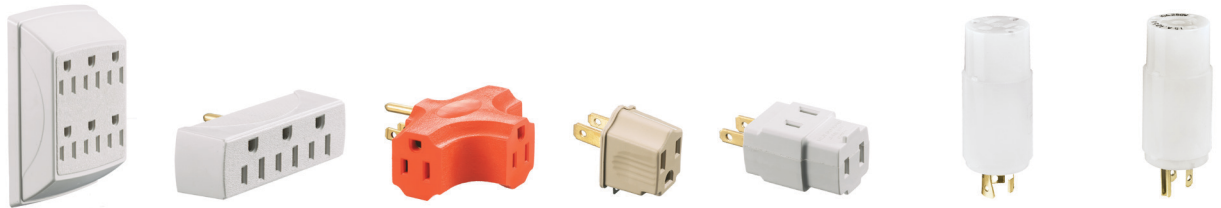

Description	Duplex Receptacle, Six Outlets	Single Receptacle, Three Outlets	Single Receptacle, Three Outlets	Two Wire to U-Ground	Cube Tap, without Ground	Male end: 10A 250V, 15A 125V, Locking Female end: 15A 125V, Straight Blade	Male end: 15A 125V, Straight Blade Female end: 10A 250V, 15A 125V, Locking
Rating	NEMA 5-15, 15A 125V						
Ivory	RT600I	RT300I	—	RT200	—	—	—
White	RT600W	RT300W	—	—	RT100W	9053AB*	9054AB*†
Orange	—	—	RT303	—	—	—	—

Note: Adapters are not intended to be used as a replacement for permanent devices. They are intended for temporary use only.

*Not UL Listed.

†Must always be used with grounded receptacle.

Product Dimensions Inches (mm)

	RP123	RP101	RP102	RP646/RP648	RP649
A	1.41" (35.8)	1.73" (43.9)	2.19" (55.6)	2.00" (50.8)	2.67" (67.8)
B	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.50" (38.1)	1.49" (37.8)
C	0.89" (22.6)	0.89" (22.6)	0.83" (21.2)	1.60" (40.6)	1.60" (40.6)
D	—	—	—	0.71" (17.9)	0.73" (18.5)

