


Straight Blade Devices



Hospital Grade • USB Charger Receptacles

 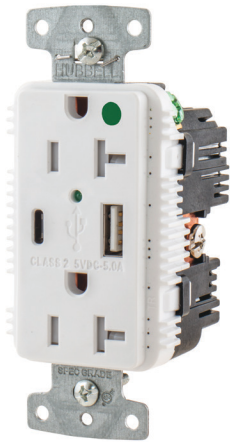




- Green LED indicator to show USB power available
- USB stainless steel ports rated for minimum 10,000 insertions and removals
- Tamper-Resistant (TR) decorator duplex
- Back and side wire for solid or stranded wire
- Complies with battery charging specification BC1.2
- Designed for commercial, industrial and home use
- Compatible with USB 1.1/2.0/3.0 devices, including Apple® products

USB Charger Receptacles

More Ways to Charge Faster with Bryant's line of USB Chargers, available in Type-C, Combination Type A&C or the legacy Type A, all with a USB high power output of 5 Amp 5 Volt DC. Bryant's USB Charger Duplex Receptacle provides both USB and electrical power in a standard single gang opening. Designed to provide maximum charging for portable electronics, the USB ports are capable of charging two tablets simultaneously.

15A and 20A 125V USB Charger Receptacles



Wiring		Back and Side Wired		
Face		Decorator		
Rating	Color	(2) Type-C Ports	(1) Type A and (1) Type-C Port	(2) Type A Ports
NEMA 5-15, 15A 125V 	Black	USBB8200C5BK	USBB8200AC5BK	USBB8200A5BK
	Brown	USBB8200C5	USBB8200AC5	USBB8200A5
	Gray	USBB8200C5GY	USBB8200AC5GY	USBB8200A5GY
	Ivory	USBB8200C5I	USBB8200AC5I	USBB8200A5I
	Light Almond	USBB8200C5LA	USBB8200AC5LA	USBB8200A5LA
	Red	USBB8200C5R	USBB8200AC5R	USBB8200A5R
	White	USBB8200C5W	USBB8200AC5W	USBB8200A5W
NEMA 5-20, 20A 125V 	Black	USBB8300C5BK	USBB8300AC5BK	USBB8300A5BK
	Brown	USBB8300C5	USBB8300AC5	USBB8300A5
	Gray	USBB8300C5GY	USBB8300AC5GY	USBB8300A5GY
	Ivory	USBB8300C5I	USBB8300AC5I	USBB8300A5I
	Light Almond	USBB8300C5LA	USBB8300AC5LA	USBB8300A5LA
	Red	USBB8300C5R	USBB8300AC5R	USBB8300A5R
	White	USBB8300C5W	USBB8300AC5W	USBB8300A5W

Note: See page R-6 for tamper-resistant description.
See page A-29 for technical specifications.

Product Dimensions Inches (mm)

A	3.28" (83.3)
B	1.75" (44.5)
C	2.62" (66.5)
D	1.73" (43.9)
E	0.27" (6.8)

