

# Straight Blade Devices

## Industrial Grade Extra Heavy Duty, Specification Grade Single Receptacles

### 15A and 20A 125V and 250V Receptacles, Back and Side Wired



Rating	Color	Single		Color	Isolated Ground		Color	Corrosion Resistant
		Standard	Weather Resistant		Standard	Weather Resistant		Standard
NEMA 5-15, 15A 125V 	Black	<b>5261BLK</b>	<b>5261BLKW</b>	Gray Ivory Orange White	<b>5261IGGRY</b> <b>5261IGI</b> <b>5261IG</b> <b>5261IGW</b>	<b>5261IGGRYWR</b> <b>5261IGIWR</b> <b>5261IGWR</b> <b>5261IGWWR</b>	Yellow	<b>5261CR</b>
	Brown	<b>5261</b>	<b>5261WR</b>					
	Gray	<b>5261GRY</b>	<b>5261GRYWR</b>					
	Ivory	<b>5261I</b>	<b>5261IWR</b>					
	Red	<b>5261RED</b>	<b>5261REDWR</b>					
White	<b>5261W</b>	<b>5261WWR</b>						
NEMA 5-20, 20A 125V 	Black	<b>5361BLK</b>	<b>5361BLKW</b>	Gray Ivory Orange White	<b>5361IGGRY</b> <b>5361IGI</b> <b>5361IG</b> <b>5361IGW</b>	<b>5361IGGRYWR</b> <b>5361IGIWR</b> <b>5361IGWR</b> <b>5361IGWWR</b>	Yellow	<b>5361CR</b>
	Brown	<b>5361</b>	<b>5361WR</b>					
	Gray	<b>5361GRY</b>	<b>5361GRYWR</b>					
	Ivory	<b>5361I</b>	<b>5361IWR</b>					
	Red	<b>5361RED</b>	<b>5361REDWR</b>					
White	<b>5361W</b>	<b>5361WWR</b>						
NEMA 6-15, 15A 250V 	Black	<b>5661BLK</b>	—				Yellow	—
	Brown	<b>5661</b>	—					
	Gray	<b>5661GRY</b>	—					
	Ivory	<b>5661I</b>	—					
	Red	<b>5661RED</b>	—					
White	<b>5661W</b>	—						
NEMA 6-20, 20A 250V 	Black	<b>5461BLK</b>	—				Yellow	<b>5461CR</b>
	Brown	<b>5461</b>	—					
	Gray	<b>5461GRY</b>	—					
	Ivory	<b>5461I</b>	—					
	Red	<b>5461RED</b>	—					
White	<b>5461W</b>	—						

Notes: See page R-6 for weather resistant description.

See Section C for isolated ground products.  
See page R-6 for weather resistant description.

See Section I for corrosion-resistant products.

### 15A and 20A 125V Short Yoke Receptacles



Wiring		Back and Side Wired		Side Wired
Rating	Color	Standard	Weather Resistant	Urea Face
NEMA 5-15, 15A 125V	Brown	<b>5284</b>	<b>5284WR</b>	<b>5258</b>
NEMA 5-20, 20A 125V	Brown	—	<b>5384WR</b>	—
NEMA 6-15, 15A 250V	Brown	<b>5684</b>	—	—
NEMA 6-20, 20A 250V	Brown	<b>5484</b>	—	—


### 15A and 20A 125V Specialty Receptacles




Rating	Description	Color	Catalog Number
NEMA 5-15, 15A 125V	5261 on 4.0" (101.6) round metal box cover	Brown	<b>5281</b>

### Product Dimensions Inches (mm)


	Single	Short Yoke	Short Yoke Urea Face
A	4.06" (103.1)	2.25" (57.2)	2.25" (57.2)
B	3.28" (83.3)	1.94" (49.3)	1.75" (44.5)
C	1.38" (35.1)	1.38" (35.1)	1.38" (35.1)
D	0.91" (23.1)	0.81" (20.6)	0.85" (21.6)
E	1.78" (45.2)	1.78" (45.3)	1.49" (37.8)

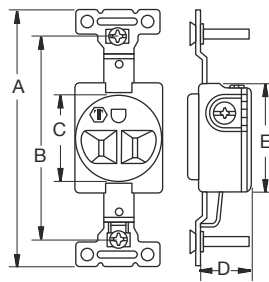

Standard

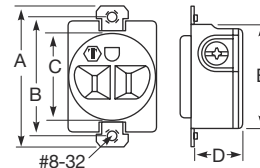

Short Yoke

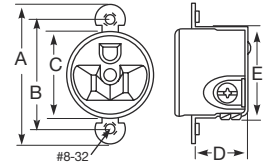

Short Yoke Urea Face