

Hospital Grade Devices

Heavy Duty Receptacles



- Hospital Grade and Specification Grade
- Tamper-Resistant... NOT Plug Resistant™
- Power indicating LED feature optional
- Circuit ID marking area on Hospital Grade
- Steel mounting strap, self-grounding

FASHION SERIES 9000

- High-impact thermoplastic face and base
- Back and side wired
- Break-off tab for two-circuit wiring
- Heavy duty, wrap-around steel yoke


Heavy Duty Receptacles

The Hubbell Tamper-Resistant Mechanism eliminates the frustration and difficulty experienced using TR receptacles with plugs that have sharp, or bent blades. Hubbell TR receptacles work so well there is virtually no perceptible difference in the feel between the TR receptacles and our conventional non-TR receptacles. Trust Hubbell to deliver Tamper-Resistant protection that feels like it's not even there.

Fashion Series® 9000

The built-in features of the 9200 self-grounding receptacle reflect the super-safe design, solid construction, and attention to details – the Face of Quality of Bryant's full line of Fashion Series 9000 designer receptacles. This line assures you of the exact device you need for hospital, industrial or commercial applications.

15A and 20A 125V Duplex Receptacles

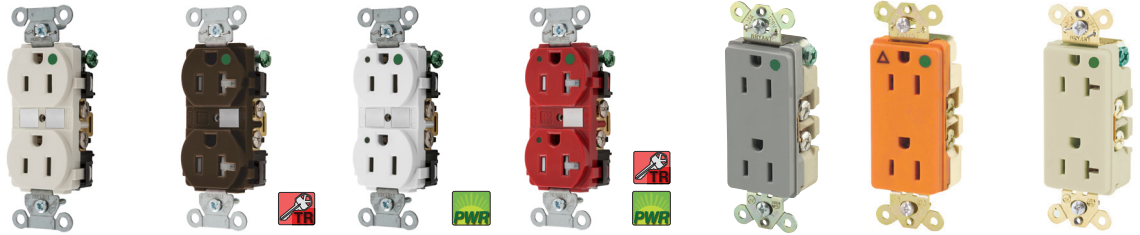

Wiring		Back and Side Wired						
Face		Duplex				Decorator		
Rating	Color	Standard	Tamper-Resistant	Power Ind. LED	TR & LED	Duplex	Isolated Ground	Lighted Face
NEMA 5-15, 15A 125V 	Brown	8200HB	8200HBTR	8200HBL	8200HBLTR	9200	—	—
	Gray	8200HBGRY	8200HBGRYTR	8200HBGRYL	8200HBGRYLTR	9200GRY	9200IGGRY	9200GRYL
	Ivory	8200HBI	8200HBITR	8200HBIL	8200HBILTR	9200I	9200IGI	9200IIL
	Red	8200HBRED	8200HBREDTR	8200HBREDL	8200HBREDLTR	9200RED	9200IGRED	9200REDL
	White	8200HBW	8200HBWTR	8200HBWL	8200HBWLTR	9200W	9200IGW	9200WL
	Orange	—	—	—	—	—	9200IG	—
NEMA 5-20, 20A 125V 	Brown	8300HB	8300HBTR	8300HBL	8300HBLTR	9300	—	—
	Gray	8300HBGRY	8300HBGRYTR	8300HBGRYL	8300HBGRYLTR	9300GRY	9300IGGRY	—
	Ivory	8300HBI	8300HBITR	8300HBIL	8300HBILTR	9300I	9300IGI	9300IIL
	Red	8300HBRED	8300HBREDTR	8300HBREDL	8300HBREDLTR	9300RED	9300IGRED	9300REDL
	White	8300HBW	8300HBWTR	8300HBWL	8300HBWLTR	9300W	9300IGW	9300WL
	Orange	—	—	—	—	—	9300IG	—

Note: *Orange is Isolated Ground. See Section C for isolated ground products.
See page A-28 for technical specifications.

Product Dimensions Inches (mm)

Receptacle	Dimension
A	3.28" (83.3)
B	1.36" (34.5)
C	1.03" (26.2)
D	2.75" (69.9)