

Surge and Isolated Ground Devices





Surge Suppression Receptacles



- Damage-alert alarm sounds when surge protection is no longer functioning, muting screw allows damage-alert alarm to be silenced until device is replaced
- Power-on indicator light verifies that suppression circuit is fully functional, light off means power has been interrupted, flashing light indicates surge protection circuitry has been damaged
- Automatic grounding clip
- High-impact nylon face resists breakage
- Distinctive surge symbol provides quick visual identification of surge suppression receptacle

Hospital Grade ● and Specification Grade, Standard and Isolated Ground Surge Suppression Receptacles




Face		Surge Suppression Receptacles with Light and Alarm, 240 Joules/15,000 Amps per Mode			
		Hospital Grade		Nylon Face	
Rating	Color	Standard	with Isolated Ground	Standard	with Isolated Ground
NEMA 5-15, 15A 125V 	Blue	SP82A	SP82IGA	SP52A	SP52IGA
	Gray	SP82GYA	SP82IGGYA	SP52GYA	SP52IGGYA
	Ivory	SP82IA	SP82IGIA	SP52IA	SP52IGIA
	Orange	—	SP82IGOA	—	SP52IGOA
	Red	—	SP82IGRA	—	—
White	SP82WA	SP82IGWA	SP52WA	SP52IGWA	
NEMA 5-20, 20A 125V 	Blue	SP83A	SP83IGA	SP53A	SP53IGA
	Gray	SP83GYA	SP83IGGYA	SP53GYA	SP53IGGYA
	Ivory	SP83IA	SP83IGIA	SP53IA	SP53IGIA
	Orange	—	SP83IGOA	—	SP53IGOA
	Red	—	SP83IGRA	—	—
White	SP83WA	SP83IGWA	SP53WA	SP53IGWA	

Product Dimensions Inches (mm)

	Receptacle
A	4.04" (102.6)
B	2.80" (71.1)
C	1.72" (43.7)
D	1.60" (40.6)
E	1.24" (31.5)

Note: See page A-5 for dimensions on adapter plates and portable boxes.

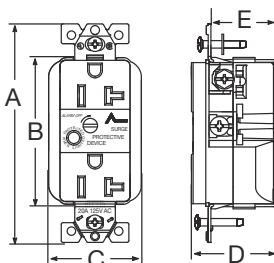

Lexan® is a registered trademark of Sabic Innovative Plastics.