

Switches



Extra Heavy Duty Industrial Specification Grade Toggle Switches



- High-impact and chemical resistant nylon toggle
- Corrosion-resistant brass and nickel-plated yoke
- Dual-grounding options, grounding terminal or stainless steel self-grounding clip
- Back wiring, each clamp-type terminal accepts two wires, avoiding the need to pigtail

Extra Heavy Duty Industrial Specification Grade Toggle Switches, Back and Side Wired




Amp	Color	Single Pole	Double Pole	3-Way	4-Way
15A 120-277V AC	Black	4801BLK	4802BLK	4803BLK	4804BLK
	Brown	4801	4802	4803	4804
	Gray	4801GRY	4802GRY	4803GRY	4804GRY
	Ivory	4801I	4802I	4803I	4804I
	Red	4801RED	4802RED	4803RED	4804RED
	White	4801W	4802W	4803W	4804W
20A 120-277V AC	Black	4901BLK	4902BLK	4903BLK	4904BLK
	Brown	4901	4902	4903	4904
	Gray	4901GRY	4902GRY	4903GRY	4904GRY
	Ivory	4901I	4902I	4903I	4904I
	Red	4901RED	4902RED	4903RED	4904RED
	White	4901W	4902W	4903W	4904W
30A 120-277V AC	Black	—	—	—	—
	Brown	3001	3002BRN	3003BRN	—
	Gray	—	3002GRY	3003GRY	—
	Ivory	3001I	3002I	3003I	—
	Red	—	—	—	—
	White	—	—	—	—


Product Dimensions

Inches (mm)

A	4.06" (103.1)
B	3.28" (83.3)
C	1.30" (33.0)
D	1.11" (28.2)
E	2.27" (57.7)

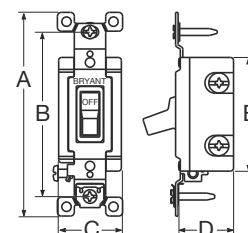

Illuminated and Pilot Toggle Switches, Back and Side Wired

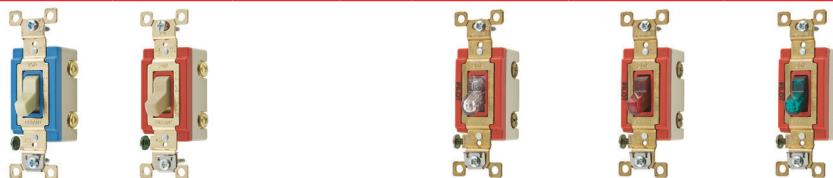

Illuminated Toggle Switch Illuminates when Switch is OFF				Pilot Toggle Switch Illuminates when Switch is ON				
Amp	Color	Single Pole	3-Way	Amp	Color	Single Pole	Double Pole	3-Way
15A 120-277V AC	Ivory	4801GLI	4803GLI	20A	Clear	4901PLC120	—	4903PLC120
				120V AC	Green	4901PLG120	—	—
					Red	4901PLR120	4902PLR120	4903PLR120
20A 120-277V AC	Clear Ivory	4901GLC 4901GLI	4903GLC 4903GLI	20A	Clear	4901PLC277	—	—
				277V AC	Red	4901PLR277	4902PLR277	4903PLR277
				30A	Red	3001PLR120	3002PLR120	—
				120V AC	Red	—	3002PLR277	—
30A	Red	—	—	277V AC	Red	—	3002PLR277	—

Horsepower Ratings

Rating	15A	20A	30A
120V	HP	1 HP	2 HP
240V	2 HP	2 HP	2 HP
277 VAC	2 HP	2 HP	2 HP