


Switches

Extra Heavy Duty Industrial Specification Grade Locking Switches

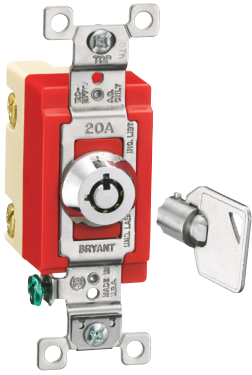

- Tapered head steel lock construction resists impact
- Six point tumbler cylinder provides superior protection
- Barrel locking key for maximum security
- Locks keyed alike for planned security use by authorized personnel


Extra Heavy Duty Industrial Specification Grade Locking Switches, Back and Side Wired



Description	Amp	Single Pole	Double Pole	3-Way	4-Way	Replacement Key	Catalog Number
Locking switch, straight key included	15A 120-277V AC	4801L	4802L	4803L	4804L	Straight-key, one key provided with each straight locking switch	6006
	20A 120-277V AC	4901L	4902L	4903L	4904L		
Barrel locking switch, barrel key included	20A 120-277V AC	4901RKL	4902RKL	4903RKL	4904RKL	Barrel-key, two keys provided with each barrel-key locking switch	6006RKL

Product Dimensions

	Locking	Barrel Lock
A	4.06" (103.1)	4.06" (103.1)
B	3.28" (83.3)	3.28" (83.3)
C	1.31" (33.3)	1.25" (31.8)
D	1.13" (28.6)	1.66" (42.2)
E	2.28" (57.9)	2.28" (57.9)

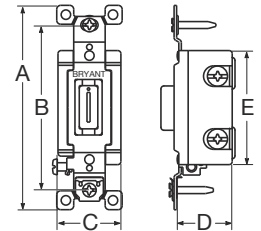

Industrial Grade, Maintained and Momentary Contact Switches

Three-Position Two-Circuit Maintained and Momentary Contact Switches, "Center OFF"



Amp	Color	Maintained Contact				Momentary Contact	
		Single Pole, Double-Throw		Double Pole, Double-Throw		Single Pole, Three-Position	
		Nylon Toggle	Locking	Nylon Toggle	Locking	Nylon Toggle	Locking
15A 120-277V AC	Black	—	4822L	—	—	—	4821L
	Brown	4822	—	4825	—	4821	—
	Gray	—	—	—	—	4821GRY	—
	Ivory	4822I	—	4825I	—	4821I	—
	White	—	—	—	—	—	—
20A 120-277V AC	Black	—	—	—	4925L	—	4921L
	Brown	4922	—	4925	—	4921	—
	Gray	4922GRY	—	—	—	4921GRY	—
	Ivory	4922I	—	4925I	—	4921I	—
	White	4922W	—	4925W	—	—	—
30A 120-277V AC	Brown	—	—	3025BRN	—	<i>Note: See above for replacement key 6006 information.</i>	
	Ivory	—	—	3025I	—		

Product Dimensions

	Inches (mm)
A	4.06" (103.1)
B	3.28" (83.3)
C	1.30" (33.0)
D	1.11" (28.2)
E	2.27" (57.7)

