


Toggle AC Manual Motor Controllers/Disconnects

TECH·SPEC®



- Ideal motor controller suitable as a disconnect
- High temperature thermoset body
- Provides high resistance to electrical arc tracking
- Strong ON/OFF action with quick-make, slow break operation provides long-life and reliability
- Superior dielectric strength
- Optional side guard, for close wall applications and finger safe environments
- Can be built into equipment and enclosures with either box or panel-mount installation

Toggle AC Manual Motor Controllers/Disconnects

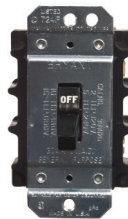

Poles	HP Rating				30A		40A	50A	60A		85A
	120V AC	240V AC	480V AC	600V AC	Back and Side Wired		Side Wired	Side Wired	Front Wired	Back Wired	Standard
					Standard Toggle	Short Toggle	Standard Toggle	Standard Toggle	Standard Toggle	Standard Toggle	Standard Toggle
2	2	5	10	15	30002D	30002DS	40002D	50002D	—	—	—
2	2	5	10	15	—	—	4002*	—	—	—	—
3	3	7.5	15	20	30003D	30003DS	40003D	50003D	—	—	—
2	—	10	15	20	—	—	—	—	60002FWD	60002D	85002D
3	—	10	25	30	—	—	—	—	60003FWD	60003D	—
3	—	10	25	40	—	—	—	—	—	—	85003D

Note: *Motor controller only.


Accessories

Description	Catalog Number
Finger guards, red, for use with 30, 40 and 50 amp switches (set of 2)	30003FG




Product Dimensions Inches (mm)


	30002D, 30003D, 40002D, 40003D, 50002D, 50003D	60002D, 60003D, 85002D, 85003D	4002
A	3.78" (96.0)	3.78" (96.0)	4.06" (103.1)
B	3.28" (83.3)	3.28" (83.3)	2.38" (60.5)
C	2.38" (60.4)	2.38" (60.4)	2.26" (57.4)
D	2.25" (57.2)	3.56" (90.4)	1.25" (31.8)
E	1.53" (38.9)	1.92" (48.8)	1.11" (28.2)
F	2.43" (62.0)	2.83" (71.9)	(2) #6-32 TAP

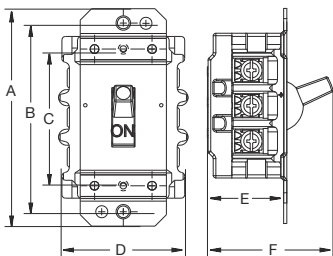

30002D, 30003D, 40002D, 40003D, 50002D, 50003D

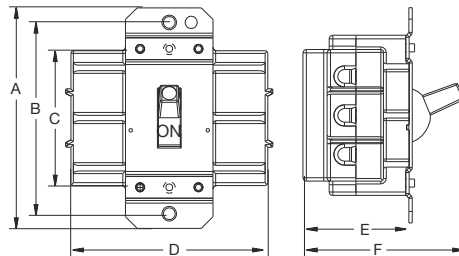

60002D, 60003D, 85002D, 85003D

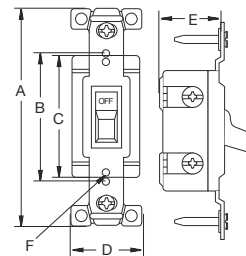

4002