

15A Locking Plugs, Connectors and Receptacles Inches (mm)

UL Type 4, 4X, 6P

IP65, 66, 67, 69k*

SUITABILITY





Rating Plug	Connector	Poles/ Wires	Cord Diameter	Color	Thermoplastic Elastomer			
					Plug	Connector	Receptacle	Duplex Receptacle
NEMA L5-15, 15A 125V 		2-Pole 3-Wire	.300"-.625" (7.6-15.9)	Yellow Black Clear	BRY24W47 BRY24W47BK BRY24W47WC	BRY25W47 BRY25W47BK BRY25W47WC	BRY65W47 — —	BRY65W47D — —
NEMA L6-15, 15A 250V 		2-Pole 3-Wire	.300"-.625" (7.6-15.9)	Yellow	BRY24W49	BRY25W49	BRY65W49	BRY65W49D
NEMA L7-15, 15A 277V AC 		2-Pole 3-Wire	.300"-.625" (7.6-15.9)	Yellow Black	BRY24W34 BRY24W34BK	BRY25W34 BRY25W34BK	BRY65W34 —	BRY65W34D —

Note: *Single and duplex receptacles while in use, not with cover closed.
Black devices are available, consult factory.

Product Dimensions Inches (mm)

	15A Locking	20A Locking	30A Locking	15A and 20A Straight Blade Receptacles	15A, 20A and 30A Locking Receptacles
A				4.56" (115.9)	4.56" (115.9)
B				3.10" (78.7)	3.10" (78.7)
C				1.20" (30.6)	1.20" (30.6)
D				3.25" (82.6)	3.25" (82.6)
				1.88" (47.6)	1.88" (47.6)
				1.26" (32.0)	1.26" (32.0)
				1.63" (41.4)	1.63" (41.4)

Note: For BRY26W09 and BRY27W09 use 20 amp locking dimensions.

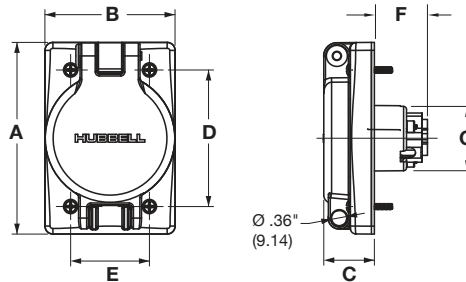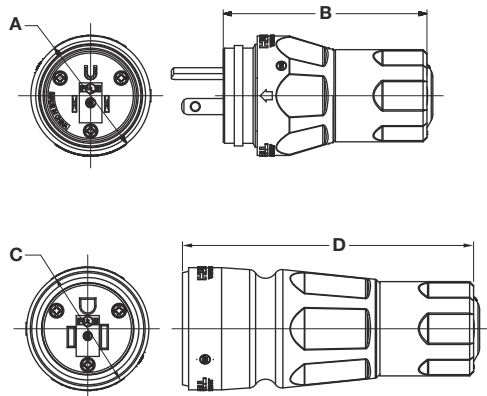

	15A Locking	20A and 30A Locking	20A Locking Non-NEMA	30A Locking Non-NEMA
F	1.46" (37.1)			
G	1.63" (41.4)			
		20A and 30A Locking		
F		1.72" (43.7)		
G		2.25" (57.2)		
		20A Locking Non-NEMA		
F		2.26" (57.4)		
G		2.25" (57.2)		
		30A Locking Non-NEMA		
F		1.97" (50.0)		
G		2.25" (57.2)		