

# Corrosion-Resistant Devices

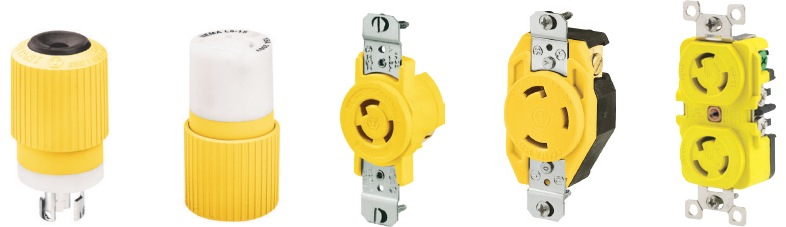





## 15, 20 and 30 Amp Locking Devices



### 15A, 20A and 30A Locking Plugs, Connectors, Receptacles and Cord Set Inches (mm)

**TECH·SPEC®**



Rating Plug Connector	Cord Diameter	Poles/Wires	Color	Clamp-Type Terminals, Back Wired		Nylon Receptacle	
				Nylon Plug	Nylon Connector	Single, Back and Side Wired	Duplex, Back Wired, Clamp-Type Terminals
NEMA L5-15 15A 125V 	.300"-.625" (7.6-15.9)	2-Pole 3-Wire	Yellow	4721NPCR*	4732NCCR*	4710CR*	4700DRCR
NEMA L5-20 20A 125V 	.300"-.950" (7.6-24.1)	2-Pole 3-Wire	Yellow	70520NPCR*	70520NCCR	70520FRCR	—
NEMA L5-30 30A 125V 	.300"-.950" (7.6-24.1)	2-Pole 3-Wire	Yellow	70530NPCR	70530NCCR	70530FRCR	—

Note: \*Not Fed. Spec.  
See page A-47 for information on weather protective boots.  
See page Q-8 for horsepower ratings.

### Product Dimensions Inches (mm)

	Single Receptacle		Duplex Receptacle
	15A	20A/30A	15A
A	3.28" (83.3)	3.28" (83.3)	3.28" (83.3)
B	2.38" (60.5)	2.38" (60.5)	2.74" (69.5)
C	1.38" (35.1)	1.56" (39.6)	1.70" (43.2)
D	1.41" (35.8)	1.70" (43.2)	1.17" (29.67)
E	1.37" (34.8)	2.67" (67.8)	.93" (23.72)
F	1.01" (25.7)	1.24" (31.5)	—

Connector	
15A	20A/30A
A	2.95" (75.0)
B	1.38" (35.1)
C	1.53" (39.1)
A	3.90" (99.0)
B	1.83" (46.5)
C	2.13" (54.0)