

# Electric Cord and Cable Reels

## Weatherproof Cable Reels



- UL Type 4X enclosure rating protects spring motor, junction box, slip ring assembly and cable entrance from hose/down or corrosion
- Multi-position nylon roller guide can be mounted in four different positions
- Ratchet lock can be disengaged in field for constant tension applications
- Powder coated, solid steel construction protects reel from abrasion or corrosion
- Optional pivot base allows 340° rotation of reel and increases range of cable to nearly any direction

### Weatherproof Cable Reels, 50 Feet (15.2m)

Description	Cable Type	Amps	Volts AC	Weight Lbs. (kg)	Catalog Number
14" weatherproof reel	14/3 SOW-A	15	600	55 (24.9)	<b>BRY501431W*</b>
16" weatherproof reel	12/3 SOW-A	20	600	80 (36.3)	<b>BRY501232W*</b>
16" weatherproof reel	12/4 SOW-A	16	600	86 (39.0)	<b>BRY501242W*</b>
16" weatherproof reel	10/3 SOW-A	25	600	86 (39.0)	<b>BRY501032W*</b>
16" weatherproof reel	10/4 SOW-A	20	600	92 (41.7)	<b>BRY501042W*</b>

Note: \*All weatherproof cable reels are supplied with wire leads and 3/4" NPT hub feed. Power supply cable not supplied.



**BRY501242W**

### Accessories





**BRY14PB**

Description	Weight Lbs. (kg)	Description
14" pivot base	5 (2.3)	<b>BRY14PB</b>
16" pivot base	13 (5.9)	<b>BRY16PB</b>
Replacement stop	0.2 (.09)	<b>BRYWPBS</b>

### Product Dimensions Inches (mm)

	Reel		Base	
	14"	16"	14"	16"
A	6.50" (165)	6.50" (165)	3.00" (76)	6.00" (152)
B	8.12" (206)	9.12" (232)	3.00" (76)	6.00" (152)
C	16.25" (413)	18.25" (464)	3.00" (76)	4.94" (125)
D	13.75" (349)	15.75" (400)	6.50" (165)	6.50" (165)
E	3.00" (76)	3.00" (76)	—	—
F	12.19" (310)	14.19" (360)	—	—

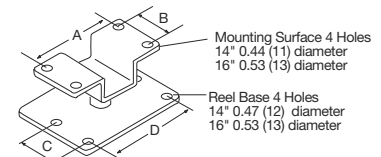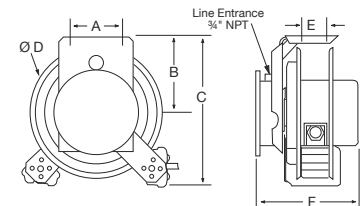

## Static Discharge Reels



- Compact design minimizes required installation space
- Steel construction
- Available with steel or nylon coated steel cable
- Large grounding jaw clamp provides low resistant ground termination

### Static Discharge Reels, 50 Feet (15.2m)

Cable Type	Weight Lbs. (kg)	Catalog Number
Single 3/32" steel	12 (5.4)	<b>BRY50SD</b>



**BRY50SD**

### Product Dimensions Inches (mm)

	Reel
A	8.81" (224)
B	8.62" (219)
C	7.88" (200)
D	1.50" (38)
E	3.35" (85)

