

# Wire Management Products

## Special Purpose Splicing Grips



FTD10024

### Application:


Temporary splice for cable and wire rope, can be used as cable reinforcement and to protect cables and hoses from abrasion, used to replace old wire rope with new wire rope

### Ideal For Use In:

- Cranes
- Oil derricks
- Drag lines
- Hoists
- Factory control cables

### Flexible Tube Inches (cm)

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs. (N)	Mesh Length Inches (cm)	Catalog Number
.37"- .49" (.94-1.24)	3,200 (14,234)	18" (45.72)	<b>FTD03718</b>
.50"- .61" (1.27-1.55)	3,200 (14,234)	18" (45.72)	<b>FTD05018</b>
.50"- .61" (1.27-1.55)	3,200 (14,234)	24" (60.96)	<b>FTD05024</b>
.62"- .74" (1.57-1.88)	4,000 (17,792)	18" (45.72)	<b>FTD06218</b>
.62"- .74" (1.57-1.88)	4,000 (17,792)	24" (60.96)	<b>FTD06224</b>
.62"- .74" (1.57-1.88)	4,000 (17,792)	36" (91.44)	<b>FTD06236</b>
.75"- .99" (1.90-2.51)	6,800 (30,246)	24" (60.96)	<b>FTD07524</b>
.75"- .99" (1.90-2.51)	6,800 (30,246)	36" (91.44)	<b>FTD07536</b>
.75"- .99" (1.90-2.51)	6,800 (30,246)	48" (121.92)	<b>FTD07548</b>
.75"- .99" (1.90-2.51)	6,800 (30,246)	72" (182.88)	<b>FTD07572</b>
1.00"-1.49" (2.54-3.78)	9,000 (40,032)	24" (60.96)	<b>FTD10024</b>
1.00"-1.49" (2.54-3.78)	9,100 (40,477)	36" (91.44)	<b>FTD10036</b>
1.00"-1.49" (2.54-3.78)	9,100 (40,477)	48" (121.92)	<b>FTD10048</b>
1.00"-1.49" (2.54-3.78)	9,100 (40,477)	72" (182.88)	<b>FTD10072</b>

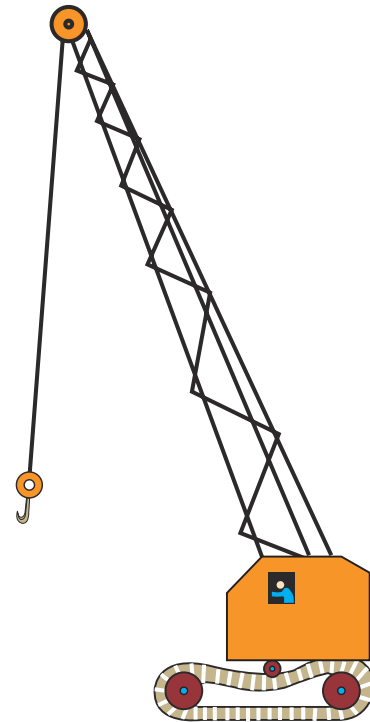

### CAUTION

Never use grip to approximate breaking strength. Refer to page N-26 for safety and working load factors. Banding is necessary to guard against accidental release of grip and provide maximum reliability.