


Delivery Systems

FloorTrak® Floor Cable Covers

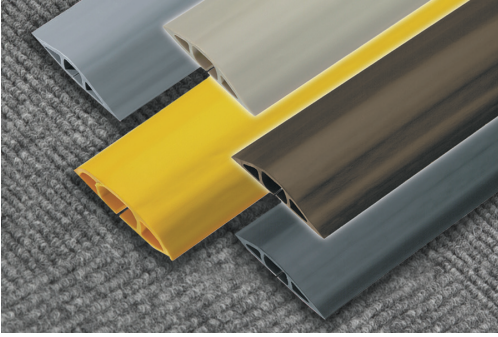

FloorTrak® is a flexible, non-metallic cover for cables that run over the floor when portable cords and cables cannot be concealed or routed away from traffic patterns. FloorTrak protects, organizes and reduces trip hazards.

- Four different sizes mean it will handle cables of up to 1.25 inches (31.8mm) in diameter
- FT2, FT3 and FT4 are available in five PVC colors to blend with various decors
- FT10 is available in black and yellow colors only
- The F10 Heavy Duty FloorTrak is ideal for applications such as industrial work areas, food processing plants and abusive areas where cable management is necessary



FloorTrak® 2 Feet (m)

Color	Length	Catalog Number
Black	10.0' (3.05)	BRYFT2BK10
Brown	10.0' (3.05)	BRYFT2BR10
Beige	10.0' (3.05)	BRYFT2BG10
Gray	10.0' (3.05)	BRYFT2GY10
Yellow	10.0' (3.05)	BRYFT2Y10



FloorTrak® 3 Feet (m)

Color	Length	Catalog Number
Black	5.0' (1.52)	BRYFT3BK5
Black	25.0' (7.62)	BRYFT3BK25
Brown	5.0' (1.52)	BRYFT3BR5
Brown	25.0' (7.62)	BRYFT3BR25
Beige	5.0' (1.52)	BRYFT3BG5
Beige	25.0' (7.62)	BRYFT3BG25
Gray	5.0' (1.52)	BRYFT3GY5
Gray	25.0' (7.62)	BRYFT3GY25
Yellow	5.0' (1.52)	BRYFT3Y5
Yellow	25.0' (7.62)	BRYFT3Y25



FloorTrak® 4 Feet (m)

Color	Length	Catalog Number
Black	5.0' (1.52)	BRYFT4BK5
Black	25.0' (7.62)	BRYFT4BK25
Gray	25.0' (7.62)	BRYFT4GY25
Yellow	5.0' (1.52)	BRYFT4Y5
Yellow	25.0' (7.62)	BRYFT4Y25



FloorTrak® 10 (Heavy Duty) Feet (m)

Color	Length	Catalog Number
Black	3.0' (.914)	BRYFT10BK3
Black	5.0' (1.52)	BRYFT10BK5
Yellow	3.0' (.914)	BRYFT10Y3
Yellow	5.0' (1.52)	BRYFT10Y5




Accessories

Description	Catalog Number
1.0" wide, 75 ft. roll double-sided adhesive tape	BRYFTT1
2.0" wide, 75 ft. roll double-sided adhesive tape	BRYFTT2

Product Dimensions Inches (mm)

FloorTrak®	FT2	FT3	FT4	FT10 (Heavy Duty)
Width (A)	2.75" (69.9)	3.00" (76.2)	3.25" (82.6)	5.60" (142.2)
Height (B)	0.53" (13.5)	0.75" (19.1)	1.10" (27.9)	1.70" (43.2)
Center Hole (Cx D)	0.60" x 0.31" (15.2 x 7.9)	0.75" x 0.50" (19.1 x 12.7)	1.21" x 0.75" (30.7 x 19.1)	1.81" x 1.25" (45.98 x 31.75)

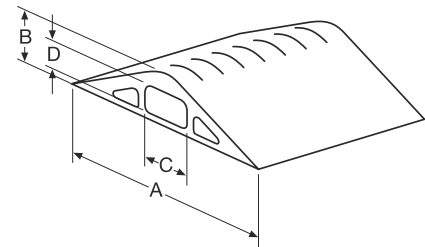

Specifications

Material	Flexible/Rigid PVC
Operating temperature	0°F to +120°F (-18°C to +49°C)