


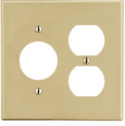






Wallplates and Covers



Combination Wallplates

Combination Wallplates, 2-Gang

Description	Color	Thermoplastic		Material	Metal Catalog Number
		Standard	Mid-Size		
2-Gang, 1-Toggle, 1-Duplex 	Brown Gray Ivory Light Almond Red White	P18 P18GY P18I P18LA P18R P18W	– PJ18GY PJ18I PJ18LA – PJ18W	Aluminum Brass Brass Plated Chrome S/S 302/304	① SB18 – SCH18 SS18
2-Gang, 1-Duplex, 1-Decorator 	Black Brown Gray Ivory Light Almond Red White	P826BK P826 P826GY P826I P826LA P826R P826W	PJ826BK PJ826 PJ826GY PJ826I PJ826LA – PJ826W	Aluminum Brass Brass Plated Chrome S/S 302/304	① SB826 ① ① SS826
2-Gang, 1-Toggle, 1-Decorator 	Black Brown Gray Ivory Light Almond Red White	P126BK P126 P126GY P126I P126LA P126R P126W	– PJ126 PJ126GY PJ126I PJ126LA – PJ126W	Aluminum Brass Brass Plated Chrome S/S 302/304	① SB126 – ① SS126
2-Gang, 1-Single Receptacle 1.40 in. (35.6) Hole, 1-Duplex 	Ivory White	P78I P78W	– –	Aluminum Brass Brass Plated Chrome S/S 302/304	① ① ① ① SS78
2-Gang, 1-Single Receptacle 1.60 in. (40.6) Hole, 1-Duplex 				Aluminum Brass Brass Plated Chrome S/S 302/304	① ① ① ① SS8720
2-Gang, 1-Toggle, 1-Blank Box Mount 	Brown Gray Ivory Light Almond White	– P113GY P113I P113LA P113W	PJ113 – PJ113I – PJ113W	Aluminum Brass Brass Plated Chrome S/S 302/304	① ① ① ① SS113
2-Gang, 1-Toggle, 1-Blank Strap Mount 				Aluminum Brass Brass Plated Chrome S/S 302/304	① ① ① ① SS114
2-Gang, 1-Blank, 1-Decorator Box Mount 	Black Gray Ivory Light Almond White	P1326BK P1326GY P1326I P1326LA P1326W	– – PJ1326I PJ1326LA PJ1326W	Aluminum Brass Brass Plated Chrome S/S 302/304	① ① ① ① SS1426*

Note: Thermoplastic wallplates feature pre-inserted captive screws for faster assembly in single gang configurations.

① Available as a custom wallplate, see pages Q-29 & Q-30. Consult custom wallplates section for additional openings and combinations.

*Strap Mount.