

 

 
 
 
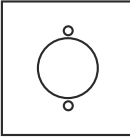
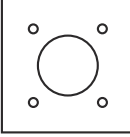
 
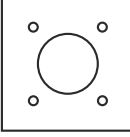


Wallplates and Covers

Selection Chart

Wallplate Selection Chart for Single Receptacles Inches (mm)

Typical Receptacle	Matching Wallplate	Stainless Steel 302/304	Stainless Steel 430	Solid Brass	Hi-Impact Nylon			
					Ivory	Brown		
 15 or 20 amp straight blade devices	 15 amp locking devices		1-Gang, single receptacle 1.40 in. (35.6) I.D. opening	SS7	SS7L	SB7	P7I	P7*
 20 or 30 amp locking devices 3-wire, 4-wire or 5-wire		1-Gang, single receptacle 1.60 in. (40.6) I.D. opening	SS720	—	SB720	P720I	P720*	
 30 or 50 amp 3-wire power outlets		1-Gang, power outlet 2.15 in. (54.6) I.D. opening	SS723	SS723L	—	P724I	P724*	
		2-Gang, power outlet 2.15 in. (54.6) I.D. opening	SS702	—	—	—	—	
		2-Gang, 2.15 in. (54.6) I.D. opening 1.81 in. W (46.0) x 2.38 in. H (60.3) mounting	SS703	SS703L	—	P703I	P703*	
 30, 50 or 60 amp 3-wire power outlets		2-Gang, 2.48 in. (63.0) I.D. opening 1.81 in. W (46.0) x 2.38 in. H (60.3) mounting	SS701	—	—	—	—	

Note: *Catalog number indicated is Brown, for full offering of color options and materials see pages Q-7 and Q-8.