

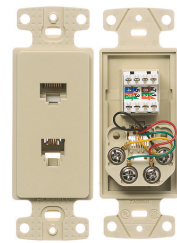
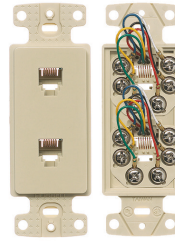


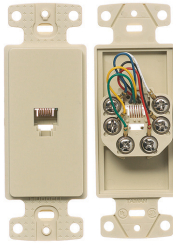

- Frames offer voice, Category 5e and Coaxial video in different configurations
- High impact-resistant thermoplastic frame
- Convenient screw down terminals
- Meets FCC part 68
- UL Listed 1863 – Communication Circuit Accessory and CSA Certified




Molded-In Voice Data Decorator Frames

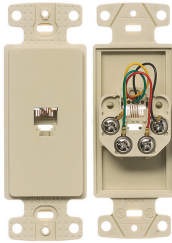

Two Jack Voice Data Frame

Description	One RJ11 Jack, 6-Position, 4-Conductor	One RJ11 Jack, 6-Position, 6-Conductor	Duplex RJ11 Jacks, 6-Position, 6-Conductor	RJ11 Jack, 6-Position, 4-Conductor	Category 5e, 8-Position, 8-Conductor
Color	Screw Terminations	Screw Terminations	Screw Terminations	Screw Terminations	110 IDC
Black	NS770BK	—	—	NS784BK	NS784BK
Brown	NS770	NS771	—	NS784	NS784
Gray	NS770GY	—	—	NS784GY	NS784GY
Ivory	NS770I	NS771I	NS772I	NS784I	NS784I
Light Almond	NS770LA	NS771LA	NS772LA	NS784LA	NS784LA
White	NS770W	NS771W	NS772W	NS784W	NS784W

Molded-In Video and Voice Decorator Frames

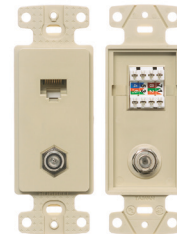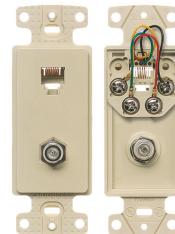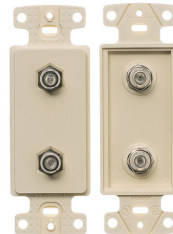

Description	One F-Type Coupler Bulkhead, Female to Female	Duplex F-Type Coupler Bulkhead, Female to Female	One RJ11 Jack, 6-Position, 4-Conductor, One F-Type Coupler Bulkhead, Female to Female	One Cat. 5e 110 Punch-Down, One F-Type Coupler Bulkhead, Female to Female
Color	Screw Terminations	Screw Terminations	Screw Terminations	Screw Terminations
Black	—	—	—	NS785BK
Brown	—	—	—	NS785
Gray	—	—	—	NS785GY
Ivory	NS780I	NS782I	NS783I	NS785I
Light Almond	NS780LA	NS782LA	NS783LA	NS785LA
White	NS780W	NS782W	NS783W	NS785W