





- Provide economical alternative to wall phone outlet placement
- High impact-resistant thermoplastic plate
- Convenient screw down terminals
- Meets FCC part 68
- UL Listed 1863 – Communication Circuit Accessory and CSA Certified


Molded-In Plates for Voice, 1-Gang

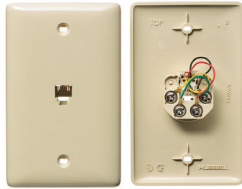

One RJ11 Jack,
6-Position, 4-Conductor,
Screw Terminations

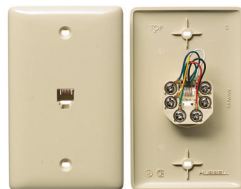

One RJ11 Jack,
6-Position, 6-Conductor,
Screw Terminations

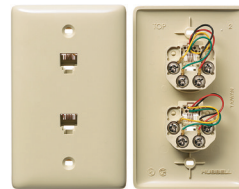

Duplex RJ11 Jacks,
6-Position, 4-Conductor,
Screw Terminations




Duplex RJ11 Jacks,
6-Position, 6-Conductor,
Screw Terminations


Description

Color	Standard	Mid-Size	Standard	Standard	Mid-Size	Standard
Brown	NS730	NS735	NS732	—	—	—
Ivory	NS730I	NS735I	NS732I	NS742I	NS745I	NS744I
Light Almond	NS730LA	NS735LA	NS732LA	NS742LA	—	—
White	NS730W	NS735W	NS732W	NS742W	NS745W	NS744W

Molded-In Plates for Voice and CATV/Satellite, 1-Gang

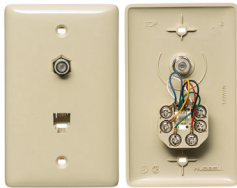

One RJ11 Jack,
6-Position, 6-Conductor,
One F-Type Coupler Bulkhead,
Female to Female

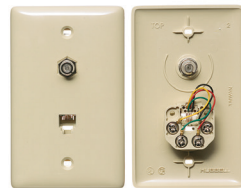

One RJ11 Jack,
6-Position, 4-Conductor,
One F-Type Coupler Bulkhead,
Female to Female



One F-Type
Coupler Bulkhead,
Female to Female



Duplex F-Type
Coupler Bulkhead,
Female to Female

Description

Color	Standard	Mid-Size	Standard	Standard	Mid-Size	Standard
Ivory	NS748I	NS755I	NS747I	NS750I	NS751I	NS752I
Light Almond	NS748LA	NS755LA	NS747LA	NS750LA	NS751LA	NS752LA
White	NS748W	NS755W	NS747W	NS750W	NS751W	NS752W



One Category 5e 110 Punch-Down,
One RJ11 Jack, 6-Position, 4-Conductor,
One F-Type Coupler Bulkhead,
Female to Female

Description

Color	Standard
Black	NS790BK
Brown	NS790
Gray	NS790GY
Ivory	NS790I
Light Almond	NS790LA
White	NS790W