

# Straight Blade Devices

## QUADPLEX® Receptacles and Cord Sets



- Accepts up to four straight or angle plugs
- Heavy duty, triple-wipe, high performance brass line contacts for excellent retention and conductivity
- Break-off tab for two-circuit wiring (except surge)
- Saves wiring and installation time
- "A" and "B" circuits molded into face for easy identification
- Easily removable knockouts for mounting to octagon concrete ring or box

### QUADPLEX®

Mounts directly to 4" square or octagon boxes. No cover plate required. Can be retrofitted to 1 and 2-gang device boxes, mud rings on 4" boxes or 4 1/16" boxes using adapter plate. Rugged impact resistant construction. Break-off tabs for split circuit wiring (except surge units).

## 15A and 20A 125V Receptacles and Cord Sets

QUADPLEX®



Rating	Color	Standard
NEMA 5-15, 15A 125V	Black	<b>1254BLK</b>
	Brown	<b>1254B</b>
	Gray	<b>1254GY</b>
	Ivory	<b>1254I</b>
	Red	<b>1254R</b>
	White	<b>1254W</b>
NEMA 5-20, 20A 125V	Black	<b>21254BLK</b>
	Brown	<b>21254B</b>
	Gray	<b>21254GY</b>
	Ivory	<b>21254I</b>
	Red	<b>21254R</b>
	White	<b>21254W</b>

Color	Isolated Ground
Orange	<b>1254IGO</b>
	Bulk Package
Orange	<b>1254IGOB</b>
Orange	<b>21254HIGO</b>
	With Wire Leads
Orange	<b>21254IGOL</b>

Color	Surge Suppression Isolated Ground
Blue Ivory	<b>1254SA</b> <b>1254SIA</b>
Blue Ivory	<b>21254SA</b> <b>21254SIA</b>
	With Wire Leads
Blue Ivory	<b>21254SLA</b> <b>21254SILA</b>

Color	6 Foot Cord Sets, 12/3 SJO	
	Surge Suppression	GFCI
Ivory Yellow	<b>T1254SI6A</b> —	— <b>T1254GF6</b>

Note: See Section C for isolated ground and surge protection products.

## Adapter Plates and Portable Boxes


Color	Adapter Plates		Portable Boxes	
	For 1- and 2-Gang Device Boxes	For 4 1/16" Boxes	with Cord Grip	Feed-thru with Two Cord Grips
Black	<b>ADAPBLK</b>	—	<b>4SQBXBLK</b>	<b>4SQBXFBLK</b>
Blue	<b>ADAPBLU</b>	—	<b>4SQXBBLU</b>	—
Brown	<b>ADAPB</b>	—	<b>4SQBXB</b>	—
Gray	<b>ADAPGRY</b>	—	<b>4SQBXGRY</b>	—
Ivory	<b>ADAPI</b>	<b>ADAPIS</b>	<b>4SQBXI</b>	<b>4SQBXFI</b>
Orange	<b>ADAPO</b>	—	<b>4SQBXO</b>	—
Red	<b>ADAPR</b>	—	<b>4SQBXR</b>	<b>4SQBXFR</b>
White	<b>ADAPW</b>	—	<b>4SQBXW</b>	—




## Product Dimensions Inches (mm)

	Receptacle	Adapter Plate	Portable Box
A	4.30" (109.2)	4.78" (121.4)	4.30" (109.2)
B	3.38" (85.9)	4.25" (108.0)	4.05" (102.9)
C	3.02" (76.7)	3.38" (85.9)	3.28" (85.9)
D	0.92" (23.4)	2.75" (69.9)*	0.84" (21.3)
E	0.10" (2.6)	0.38" (9.5)	0.75" (19.1)
F	—	2.75" (6.9)	—


Note: \*Mounting dimensions for 4 1/16" adapter plate.

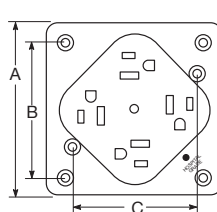

Receptacle

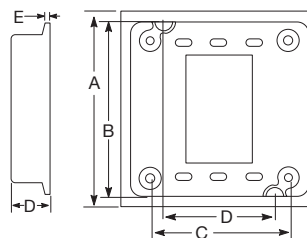

Adapter Plate

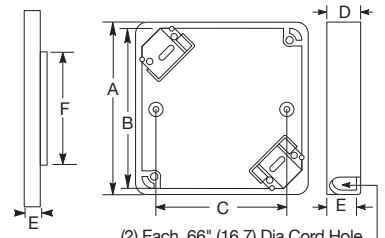

Portable Box