

Surge and Isolated Ground Devices



Surge Suppression Receptacles



- Damage-alert alarm sounds when surge protection is no longer functioning, muting screw allows damage-alert alarm to be silenced until device is replaced
- Power-on indicator light verifies that suppression circuit is fully functional, light off means power has been interrupted, flashing light indicates surge protection circuitry has been damaged
- Automatic grounding clip
- High-impact nylon face resists breakage
- Distinctive surge symbol provides quick visual identification of surge suppression receptacle

Hospital Grade and Specification Grade, Standard and Isolated Ground Surge Suppression Receptacles




Face		Surge Suppression Receptacles with Light and Alarm, 240 Joules/15,000 Amps per Mode			
		Hospital Grade		Nylon Face	
Rating	Color	Standard	with Isolated Ground	Standard	with Isolated Ground
NEMA 5-15, 15A 125V 	Blue	SP82A	SP821GA	SP52A	SP521GA
	Gray	SP82GYA	SP821GGYA	SP52GYA	SP521GGYA
	Ivory	SP82IA	SP821GIA	SP52IA	SP521GIA
	Orange	—	SP821GOA	—	SP521GOA
	Red	—	SP821GRA	—	—
	White	SP82WA	SP821GWA	SP52WA	SP521GWA
NEMA 5-20, 20A 125V 	Blue	SP83A	SP831GA	SP53A	SP531GA
	Gray	SP83GYA	SP831GGYA	SP53GYA	SP531GGYA
	Ivory	SP83IA	SP831GIA	SP53IA	SP531GIA
	Orange	—	SP831GOA	—	SP531GOA
	Red	—	SP831GRA	—	—
	White	SP83WA	SP831GWA	SP53WA	SP531GWA

Product Dimensions Inches (mm)

Receptacle	
A	4.04" (102.6)
B	2.80" (71.1)
C	1.72" (43.7)
D	1.60" (40.6)
E	1.24" (31.5)

Note: See page A-5 for dimensions on adapter plates and portable boxes.

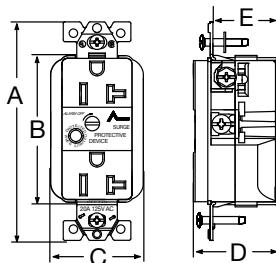

Lexan® is a registered trademark of Sabic Innovative Plastics.