

Switches



Push Button Switches

Push Button Switches



Description	Color	Push Button Switch			
		Single Pole	Double Pole	3-Way	4-Way
Standard, 20A 120-277V AC	Brown	4981	4982	4983*	4984*
Pilot light, pilot illuminates when switch is ON, 20A 120V AC	Red	4997PLR	—	4998PLR*	—

Note: *Pilot Light is not UL Listed or CSA Certified.

Weatherproof Cover




Description	Catalog Number
1-Gang, clear silicone rubber cover, fits both FS/FD and standard boxes	1795WP

Note: Weatherproof cover is not CSA Certified.


Product Dimensions Inches (mm)

	Push Button Switch	Weatherproof Cover
A	3.28" (83.3)	4.63" (117.6)
B	2.38" (60.5)	3.25" (82.6)
C	1.50" (38.1)	2.38" (60.5)
D	0.97" (24.6)	2.94" (74.7)
E	2.44" (62.0)	1.88" (47.8)

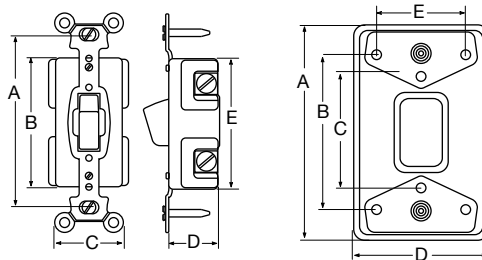

Heavy Duty Specification Grade Toggle Switches

Heavy Duty Specification Grade Self-Grounding Toggle Switches, Back and Side Wired

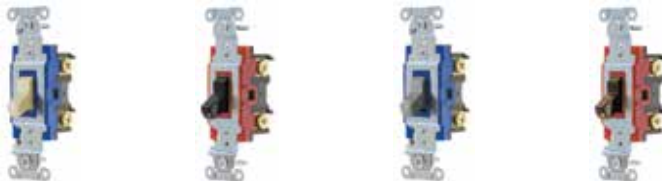

Amp	Color	Single Pole	Double Pole	3-Way	4-Way
15A 120-277V AC	Black	4801BBLK	—	4803BBLK	—
	Brown	4801B	—	4803B	—
	Gray	4801BGRY	—	4803BGRY	—
	Ivory	4801BI	—	4803BI	—
	Light Almond	4801BLA	—	4803BLA	—
	Red	4801BRED	—	4803BRED	—
	White	4801BW	—	—	4803BW
20A 120-277V AC	Black	4901BBLK	4902BBLK	4903BBLK	4904BBLK
	Brown	4901B	4902B	4903B	4904B
	Gray	4901BGRY	4902BGRY	4903BGRY	4904BGRY
	Ivory	4901BI	4902BI	4903BI	4904BI
	Light Almond	4901BLA	4902BLA	4903BLA	4904BLA
	Red	4901BRED	4902BRED	4903BRED	4904BRED
	White	4901BW	4902BW	4903BW	4904BW

Product Dimensions Inches (mm)

A	3.28" (83.3)
B	2.33" (59.1)
C	1.25" (31.8)
D	1.13" (28.7)
E	2.28" (57.9)

