

Occupancy Sensors and Lighting Controls



Architectural Grade Preset Slide Dimmers



- Full-range dimming preset slider
- Advanced RFI protection circuitry
- Complete solid-state electronics
- Rating stamped on yoke for permanent identification
- Advanced circuitry reduces motor hum and radio interference
- Reduces energy costs


Architectural Preset Slide Dimmers, Single Pole/3-Way



Product Dimensions Inches (mm)

	BAS203/BAS153	BAS103/BAS63
A	4.50" (114.3)	4.50" (114.3)
B	4.50" (114.3)	2.75" (69.9)
C	1.31" (33.3)*	1.31" (33.3)*
D	2.75" (69.9)	2.75" (69.9)
E	0.62" (15.7)	0.62" (15.7)

Note: *High watt models up to 1.71 in. (43.4).

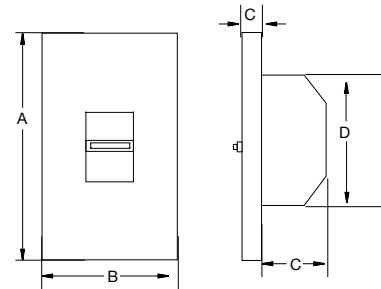

Color	Single Pole/3-Way, 120V AC, 60 Hz			
	2000W	1500W	1000W	600W
Ivory	BAS203I	BAS153I	BAS103I	BAS63I
White	BAS203W	BAS153W	BAS103W	BAS63W

Slide and Rotary Dimmers



Standard toggle switches provide the basic ON/OFF control for home lighting and appliances.

- Optimum CFL and LED control
- Low end adjustment for fine tuning
- Decorator and traditional toggle styling available
- No neutral required



Adjustment dial to set the low-light level



CFL/LED Dimmers

Description	Toggle Dimmer	Decorator Dimmer
Rating	CFL/LED 150W Incandescent/Halogen 600W 120V AC, 60Hz	
Termination	Single Pole/Three Way	Single Pole/Three Way
Ivory	RAYCL153PI	RDVCL153PI
Light Almond	RAYCL153PLA	RDVCL153PLA
White	RAYCL153PW	RDVCL153PW