


16,000 lb. Series Guy Strains - Eye / Eye

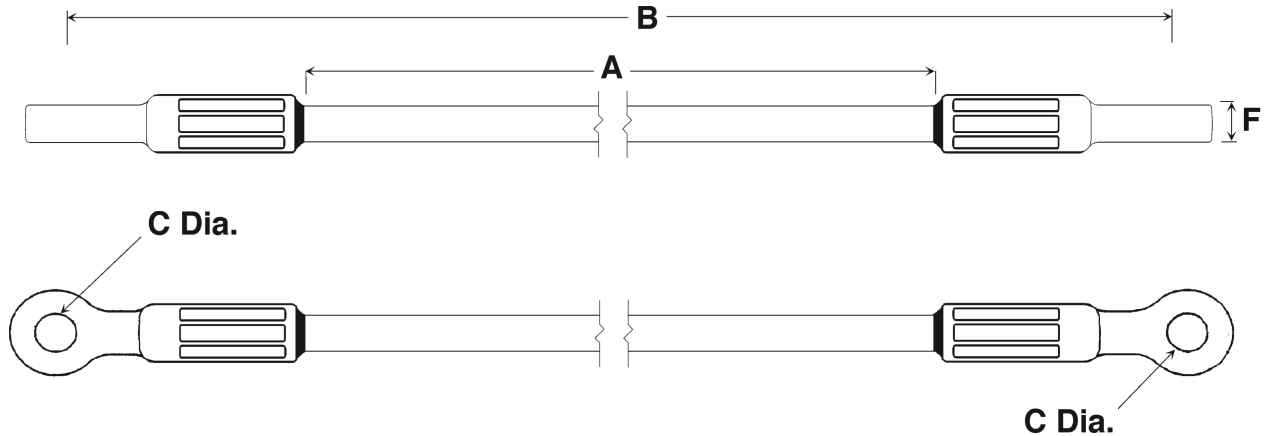

C Dimension is 5/8" (16 mm) for 16,000 lbs. series

5/8" dia. Fiberglass rod.

RUS Accepted.

Castings are hot-dip galvanized ductile iron.

Catalog Number	Length A	Length B	Width F	Weight (Each)
16,000 lbs. (7258 kg) Minimum Ultimate Strength*				
GS16012EE	12" (30.5 cm)	19.6" (49.8 cm)	0.625" (16 mm)	2.8 lbs. (1.3 kg)
GS16018EE	18" (45.7 cm)	25.6" (65.0 cm)	0.625" (16 mm)	2.9 lbs. (1.3 kg)
GS16024EE	24" (61.0 cm)	31.6" (80.3 cm)	0.625" (16 mm)	3.1 lbs. (1.4 kg)
GS16036EE	36" (91.4 cm)	43.6" (110.7 cm)	0.625" (16 mm)	3.3 lbs. (1.5 kg)
GS16042EE	42" (106.7 cm)	49.6" (126.0 cm)	0.625" (16 mm)	3.5 lbs. (1.6 kg)
GS16054EE	54" (137.2 cm)	61.6" (156.5 cm)	0.625" (16 mm)	3.7 lbs. (1.7 kg)
GS16078EE	78" (198.1 cm)	85.6" (217.4 cm)	0.625" (16 mm)	4.2 lbs. (1.9 kg)
GS16096EE	96" (243.8 cm)	103.6" (263.1 cm)	0.625" (16 mm)	4.6 lbs. (2.1 kg)
GS16120EE	120" (304.8 cm)	127.6" (324.1 cm)	0.625" (16 mm)	5.1 lbs. (2.3 kg)
GS16144EE	144" (365.8 cm)	151.6" (385.1 cm)	0.625" (16 mm)	5.7 lbs. (2.6 kg)

Add "SC" suffix to the end of the catalog number to denote Silicone Coated rod

*Recommended maximum working load is 50% of minimum ultimate ratings listed.

