


## 30,000 lb. SERIES Guy Strains - Clevis / Clevis

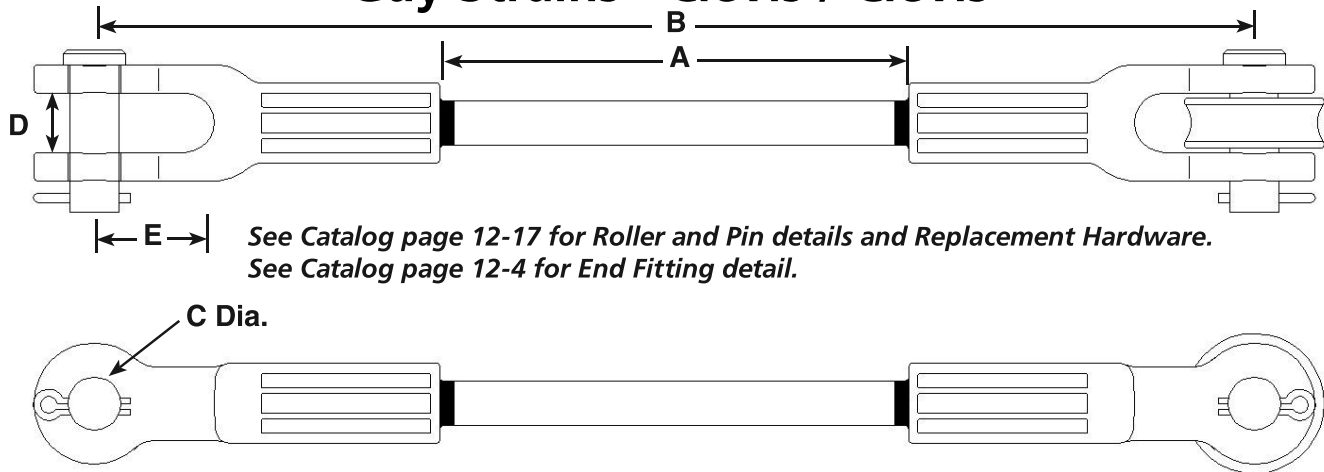

See Note For Roller Configurations

C Dimension is 3/4" for 30,000 lbs. series

D Dimension is 1" for 30,000 lbs. series

E Dimension is 2.04" for 30,000 lbs. series

3/4" dia. Fiberglass rod.

Castings are hot-dip galvanized ductile iron.

Catalog Number	Length A	Length B	Weight (Each)
<b>30,000 lbs. (13,608 kg) Minimum Ultimate Strength*</b>			
GS30012CC1	12" (30.5 cm)	24" (61.0 cm)	6.1 lbs. (2.8 kg)
GS30018CC1	18" (45.8 cm)	30" (76.2 cm)	6.3 lbs. (2.9 kg)
GS30024CC1	24" (61.0 cm)	36" (91.4 cm)	6.5 lbs. (2.9 kg)
GS30030CC1	30" (76.2 cm)	42" (106.7 cm)	6.7 lbs. (3.0 kg)
GS30036CC1	36" (91.4 cm)	48" (122.0 cm)	6.9 lbs. (3.1 kg)
GS30042CC1	42" (106.7 cm)	54" (137.2 cm)	7.1 lbs. (3.2 kg)
GS30048CC1	48" (121.9 cm)	60" (152.4 cm)	7.3 lbs. (3.3 kg)
GS30054CC1	54" (137.2 cm)	66" (167.6 cm)	7.5 lbs. (3.4 kg)
GS30060CC1	60" (152.4 cm)	72" (182.9 cm)	7.7 lbs. (3.5 kg)
GS30072CC1	72" (182.9 cm)	84" (213.4 cm)	8.0 lbs. (3.6 kg)
GS30078CC1	78" (198.1 cm)	90" (228.6 cm)	8.2 lbs. (3.7 kg)
GS30084CC1	84" (213.4 cm)	96" (243.8 cm)	8.4 lbs. (3.8 kg)
GS30090CC1	90" (228.6 cm)	102" (259.1 cm)	8.6 lbs. (3.9 kg)
GS30096CC1	96" (243.8 cm)	108" (274.3 cm)	8.8 lbs. (4.0 kg)
GS30108CC1	108" (274.3 cm)	120" (304.8 cm)	9.2 lbs. (4.2 kg)
GS30120CC1	120" (304.8 cm)	132" (335.3 cm)	9.6 lbs. (4.4 kg)
GS30144CC1	144" (365.8 cm)	156" (396.2 cm)	10.3 lbs. (4.7 kg)

GS—CC1 series has 1 Roller as detailed in drawing

For 2 Rollers, replace "CC1" in number with "CC2"

For no Rollers, replace "CC1" in number with "CC"

Add "SC" suffix to the end of the catalog number to denote Silicone Coated Rod

\*Recommended maximum working load is 50% of minimum ultimate ratings listed.

