


Three-Phase Vertical Pin Standoff Bracket (15°)

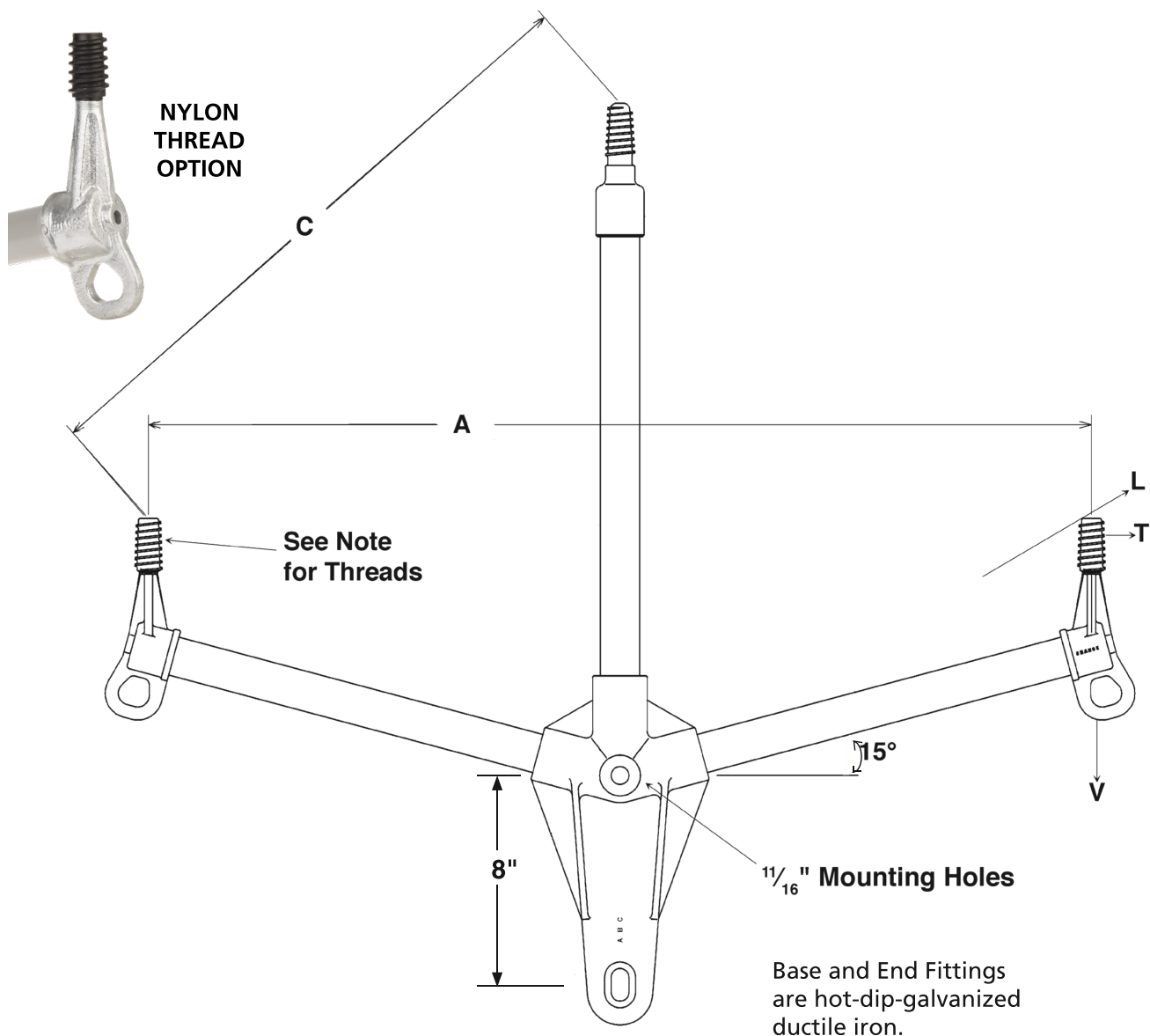

Catalog Number	Length A	Length C	Minimum Ultimate*			Weight (Each)
			Vertical V	Longitudinal L	Transverse T	
Medium Duty 1½" (38 mm) Dia. Fiberglass Rod						
3SBM3024VV1	30" (76.2 cm)	24" (61.0 cm)	1500 lbs. (680 kg)	900 lbs. (408 kg)	1500 lbs. (680 kg)	18.7 lbs. (8.4 kg)
3SBM4828VV1	48" (121.9 cm)	28" (71.1 cm)	1350 lbs. (612 kg)	800 lbs. (363 kg)	1500 lbs. (680 kg)	19.8 lbs. (8.9 kg)

*Recommended maximum working load is 50% of minimum ultimate ratings listed.

3SBM—VV1 series has 1" plastisol coated threads.

For 1" Nylon threads, replace "VV1" in number with "VV2"

For 1" Lead threads, replace "VV1" in number with "VV3"

For 1.375" Lead threads, replace "VV1" in number with "VV4"

Consult factory for additional lengths.

Add "SC" suffix to the end of the catalog number to denote Silicone Coated rod