


### 3 Position (Cloverleaf) Two-Phase Cutout / Arrester Bracket (15°)

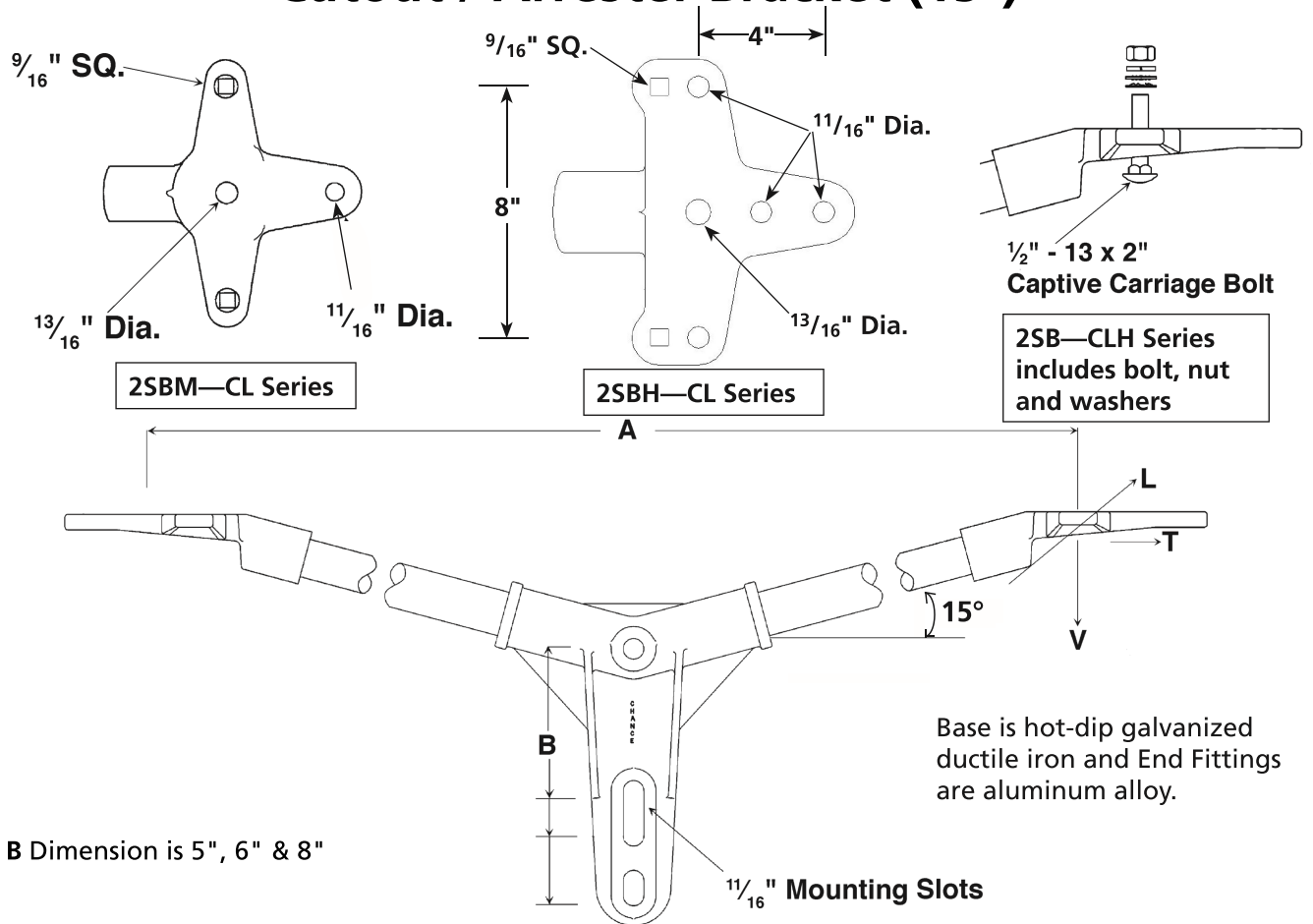

B Dimension is 5", 6" & 8"

Catalog Number	Length A	Minimum Ultimate*			Weight (Each)
		Vertical V	Longitudinal L	Transverse T	
<b>Medium Duty 1½" (38 mm) Dia. Fiberglass Rod</b>					
2SBM36CLCL	36" (91.4 cm)	1200 lbs. (544 kg)	900 lbs. (408 kg)	10,000 lbs. (4536 kg)	12.6 lbs. (5.7 kg)
2SBM42CLCL	42" (106.7 cm)	950 lbs. (431 kg)	700 lbs. (318 kg)	10,000 lbs. (4536 kg)	13.3 lbs. (6.0 kg)
2SBM48CLCL	48" (121.9 cm)	900 lbs. (408 kg)	500 lbs. (227 kg)	10,000 lbs. (4536 kg)	14.1 lbs. (6.4 kg)
2SBM36CLHCLH	36" (91.4 cm)	1200 lbs. (544 kg)	900 lbs. (408 kg)	10,000 lbs. (4536 kg)	12.6 lbs. (5.7 kg)
2SBM42CLHCLH	42" (106.7 cm)	950 lbs. (431 kg)	700 lbs. (318 kg)	10,000 lbs. (4536 kg)	13.3 lbs. (6.0 kg)
2SBM48CLHCLH	48" (121.9 cm)	900 lbs. (408 kg)	500 lbs. (227 kg)	10,000 lbs. (4536 kg)	14.1 lbs. (6.4 kg)
<b>Heavy Duty 2" (51 mm) Dia. Fiberglass Rod</b>					
2SBH36CLCL	36" (91.4 cm)	2600 lbs. (1179 kg)	1900 lbs. (862 kg)	10,000 lbs. (4536 kg)	20.2 lbs. (9.2 kg)
2SBH42CLCL	42" (106.7 cm)	2400 lbs. (1089 kg)	1900 lbs. (862 kg)	10,000 lbs. (4536 kg)	21.3 lbs. (9.7 kg)
2SBH48CLCL	48" (121.9 cm)	2200 lbs. (998 kg)	1850 lbs. (839 kg)	10,000 lbs. (4536 kg)	23.7 lbs. (10.8 kg)
2SBH36CLHCLH	36" (91.4 cm)	2600 lbs. (1179 kg)	1900 lbs. (862 kg)	10,000 lbs. (4536 kg)	20.2 lbs. (9.2 kg)
2SBH42CLHCLH	42" (106.7 cm)	2400 lbs. (1089 kg)	1900 lbs. (862 kg)	10,000 lbs. (4536 kg)	21.3 lbs. (9.7 kg)
2SBH48CLHCLH	48" (121.9 cm)	2200 lbs. (998 kg)	1850 lbs. (839 kg)	10,000 lbs. (4536 kg)	23.7 lbs. (10.8 kg)

\*Recommended maximum working load is 50% of minimum ultimate ratings listed.

Consult factory for additional lengths.

Add "SC" suffix to the end of the catalog number to denote Silicone Coated rod

