

Specifications

- Outer jacket nominal O.D.: 0.27" (Plenum), 0.28" (Riser)
- Conductor: 23 AWG solid bare copper
- Polyester backed aluminum foil shield
- Application: third party qualified for 10 Gigabit Ethernet transmission IEEE 802.3an
- Qualified for PoE IEEE 802.3bt


Standards

- UL Verified TIA 568.2-D Category 6A cable
- ISO 11801 Class EA Category 6A cable
- UL Listed CMP-LP: 0.6A; CMR-LP: 0.5A

NEXTSPEED® Ascent Category 6A F/UTP Cable

NVP: Plenum 69%, Riser 66%

Color	Plenum Reel in Box	Riser Reel in Box
Black	HC6AFTPSPBK	HC6AFTP SRBK
Blue	HC6AFTPSPB	HC6AFTP SRB
Green	HC6AFTPSPGN	HC6AFTP SRGN
Gray	HC6AFTPSPGY	HC6AFTP SRGY
Orange	HC6AFTPSPOR	HC6AFTP SROR
Pink	HC6AFTPSPPK	HC6AFTP SRPK
Purple	HC6AFTPSP	HC6AFTP SRP
Red	HC6AFTPSPR	HC6AFTP SRR
White	HC6AFTPSPW	HC6AFTP SRW
Yellow	HC6AFTPSPY	HC6AFTP SRY

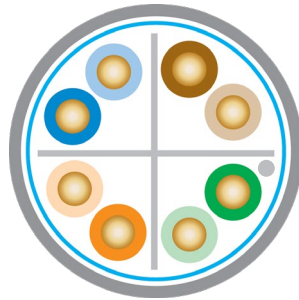

Specifications

- Outer jacket nominal O.D.: 0.28 (Plenum); 0.29 (Riser)
- Conductor: 23 AWG solid bare copper
- Polyester backed aluminum foil shield

Standards

- TIA 568.2-D Category 6 cable
- ISO 11801 Class E Category 6 cable
- UL Listed



NEXTSPEED® Ascent Category 6 F/UTP Cable

NVP: Plenum 71%, Riser 66%

Color	Plenum Reel in Box	Riser Reel in Box
Black	HC6FTPSPBK	HC6FTP SRBK
Blue	HC6FTPSPB	HC6FTP SRB
Green	HC6FTPSPGN	HC6FTP SRGN
Gray	HC6FTPSPGY	HC6FTP SRGY
Orange	HC6FTPSPOR	HC6FTP SROR
Pink	HC6FTPSPPK	HC6FTP SRPK
Purple	HC6FTPSP	HC6FTP SRP
Red	HC6FTPSPR	HC6FTP SRR
White	HC6FTPSPW	HC6FTP SRW
Yellow	HC6FTPSPY	HC6FTP SRY

