




 
FIBERHUBB™ | MPO Cassettes and Panels, H4 Series, 4-Across

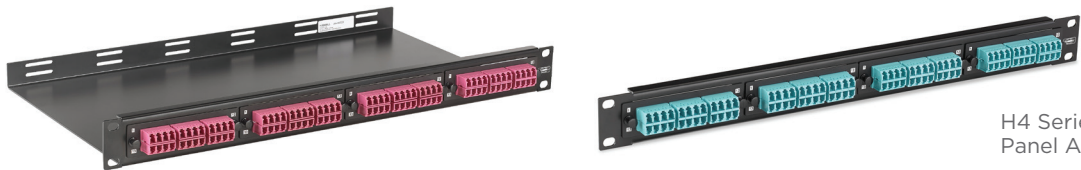

H4 Series 4-Across Panel Applications*

H4 Series MPO 24-Port LC Quad Cassettes

Type A polarity (straight through, pin 1 to pin 1)
MPO input: (2) MPO male pinned receptacles

				
Fiber Type	OM4	OM4	OM3	OS2
Adapter Color	Aqua	Violet	Aqua	Blue
Catalog No.	OCLCQG4H4	OCLCQG4H4VI	OCLCQG3H4	OCLCQSMH4






H4 Series MPO 40G to 10G Break-Out Cassettes

Input: MPO 8-fiber 40G pinned male receptacle; Output: 4 x 10G LC duplex

	
OM4	OM4
Aqua	Violet
OCLCD40G8H4	OCLCD40G8H4VI



H4 Series 24-Port LC Quad Panels

Zirconia ceramic

					
Application	OM3 and OM4	OM4	OS2	OS2	Blank Panel
Adapter Color	Aqua	Violet	Blue	Yellow	-
Catalog No.	FSPLCQS6H4AQ	FSPLCQS6H4VI	FSPLCQS6H4B	FSPLCQS6H4Y	FSPBH4

H4 Series MPO 6-Port Adapter Panels, Standard and Reversed Polarity

Supports 40G/100G MPO channel migration

				
Adapter Color	Aqua	Violet	Green	Gray (Reversed Polarity)
Catalog No.	FSPMTPH4AQ6	FSPMTPH4VI6	FSPMTPH4GN6	FSPMTPH4RPGY6

Note: Standard polarity is key-up to key-down. Reversed polarity is key-up to key-up. See chart on page G07 and specification sheet for 40G/100G gender and polarity guidelines.

Note: *H4 Series cassettes and panels are compatible only with H4 Series rack mount panels and enclosures. See page J05 for product compatibility.