

LGX Max™ Series CS Cassettes

FIBERHUBB LGX Max Series Cassettes utilize the latest in ultra compact duplex connector technology to make ultra high density easily accessible. CS Connector technology allows 36 fiber ports in a single LGX cassette.

Compatibility

- FCR Rackmount Series
- FTR 3 Across Series
- OFPNL Series




FIBERHUBB LGX Max Series Cassettes with CS Connector technology allows 36 fiber ports in a single LGX cassette.

LGX Max Series Cassettes

Fiber Type	CS Ports (front)	Fibers (front)	MPO Ports (rear)	Catalog No.
OS2	18	36	3	OCCSSM
OM3/OM4	18	36	3	OCCSM34

Note: Type A Polarity (straight through, pin 1 to pin 1).

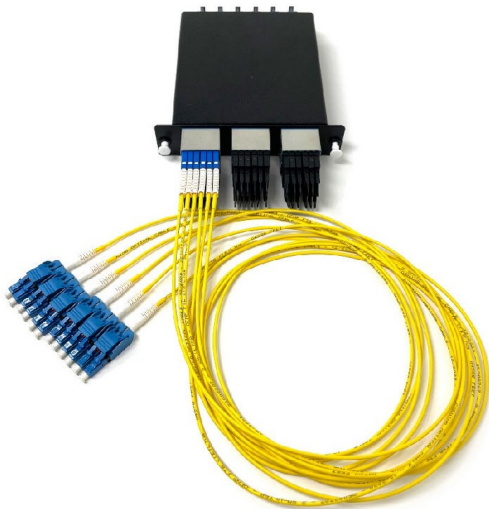


LGX Max™ Series SN Cassettes

FIBERHUBB LGX Max Series Cassettes utilize the latest in ultra compact duplex connector technology to make ultra high density easily accessible.

SN Connector technology allows 72 fiber ports in a single LGX cassette.

Compatibility

- FCR Rackmount Series
- FTR 3 Across Series
- FPR3SP Series
- OFPNL Series

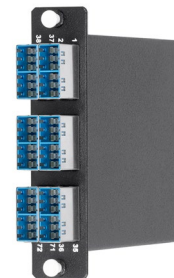

LGX Max Series Cassettes

Fiber Type	SN Ports (front)	Fibers (front)	MPO Ports (rear)	Catalog No.
OS2	36	72	6	OCSNSM
OM3/OM4	36	72	6	OCSNM34

Note: Type A Polarity (straight through, pin 1 to pin 1).