

NEXTFRAME | Wire Basket Tray, Round Cross-Wire



Features

- T-weld construction prevents snags
- 5mm round wire minimum
- High load rating
- Easy to cut and fabricate fittings in the field
- 100% recycled steel
- 2" x 4" mesh opening
- Use factory support hardware or fabricate supports at the job site
- Painted tray includes factory installed masking to ensure proper grounding at splices; no need to remove paint during installation

Round Cross-Wire

10 Feet per Length

118.3" (3m)

10 Piece Min. Order Qty.

2" Deep Tray




Tray Width in (mm)	Load (lb/ft)	Tray Weight per Length (lb)	Splice Quantity		Finish	
			90° Sweep Elbow	Straight Splice	Pre-Galvanized	Black Powder Coat
4" (102)	45	7	2	2	HBT0204	HBT0204BK
6" (152) •	50	9	3	4	HBT0206	HBT0206BK
8" (203) •	52	10.5	4	4	HBT0208	HBT0208BK
12" (305) •	58	12	6	4	HBT0212	HBT0212BK
16" (406) •	70	15	7	4	HBT0216	HBT0216BK
18" (457) •	70	23	9	4	HBT0218	HBT0218BK
20" (508) •	73	25	9	5	HBT0220	HBT0220BK
22" (559)	73	27	12	5	HBT0222	HBT0222BK
24" (610) •	75	31	12	5	HBT0224	HBT0224BK
26" (660)	73	33	13	6	HBT0226	HBT0226BK
28" (711)	73	35	14	6	HBT0228	HBT0228BK
30" (762)	70	38	15	6	HBT0230	HBT0230BK
32" (813)	70	39	16	6	HBT0232	HBT0232BK
4" (102)	49	12	2	4	HBT0404	HBT0404BK
6" (152) •	49	13	3	5	HBT0406	HBT0406BK
8" (203) •	78	15	4	6	HBT0408	HBT0408BK
12" (305) •	78	23	6	6	HBT0412	HBT0412BK
16" (406) •	108	27	7	7	HBT0416	HBT0416BK
18" (457) •	116	29	9	7	HBT0418	HBT0418BK
20" (508) •	116	31	9	7	HBT0420	HBT0420BK
22" (559)	116	33	12	8	HBT0422	HBT0422BK
24" (610) •	116	35	12	8	HBT0424	HBT0424BK
28" (711)	108	39	14	9	HBT0428	HBT0428BK
8" (203) •	116	23	4	6	HBT0608	HBT0608BK
12" (305) •	123	27	6	6	HBT0612	HBT0612BK
16" (406) •	123	31	7	7	HBT0616	HBT0616BK
18" (457) •	127	33	9	7	HBT0618	HBT0618BK
20" (508) •	127	35	9	7	HBT0620	HBT0620BK
22" (559) •	127	37	12	8	HBT0622	HBT0622BK
24" (610) •	150	39	12	8	HBT0624	HBT0624BK
8" (203) •	116	27	4	8	HBT0808	HBT0808BK
12" (305) •	116	31	6	8	HBT0812	HBT0812BK
16" (406) •	116	35	7	9	HBT0816	HBT0816BK
18" (457) •	116	37	9	9	HBT0818	HBT0818BK
20" (508) •	116	39	9	9	HBT0820	HBT0820BK


4" Deep Tray



6" Deep Tray

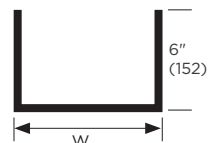

8" Deep Tray

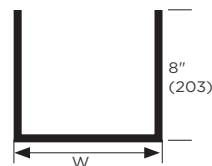

Note: •UL Classified as equipment ground conductor (painted tray cUL Classified only).

All dimensions are +/- 0.25". Custom paint colors available in addition to Black Powder Coat (Contact Hubbell).

HBT0202 (2x2 tray) available as special order. MOQ 40 pieces. Top wire utilizes side weld.