

Performance
All connectors are ETL verified to Category 6 performance.



Durability
Rugged construction for the most punishing environments.



Interface
User-friendly quick connect positive indication when fully engaged.


Specifications

- Vibration: frequency range: 10-500Hz
- Acceleration: 5g (operational)
- Mating cycles: 750 minimum
- HI-Impact housing: Thermoplastic, UL 94V-0



Standards

- TIA-568.2-D Category 6 Component
- IEEE 802.3bt 4PPoE
- Ingress protection: IP67 (dust/water)

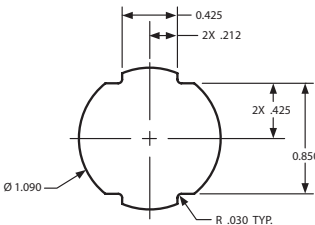

Installation
Standard 3/4" conduit knockout simplifies installation



①



②

HI-Impact Copper Panel Mount Connectors

Includes (1) housing, (1) jack, (1) flat bulkhead gasket, and (1) retaining nut

Description	Catalog No.
HI-Impact Category 6A Unshielded Jack	HI6A
HI-Impact Category Shielded 6A Jack	HIS6A
HI-Impact Category 6A Shielded Coupler	HIS6AC
HI-Impact Category Unshielded 6 Jack	① HI6
HI-Impact Category Unshielded 6 Coupler	HI6C
HI-Impact Protective Cap	② HIC