






Specifications



- High-impact polycarbonate construction provides maximum durability
- Patented keyhole mounting system allows installation in under a minute
- Includes attached gasket and mounting hardware
- Pre-configured for GFCI with patented knockout technology for alternate devices
- Lockable tab for OSHA compliance
- Sealed-in-place gasket
- Each box contains three or six adapters to make a variety of configurations (16 or 55)

Standards

- UL Listed
- NEMA Type 3R Rated
- 2017 NEC® Compliant (Article 406.9)

EXTRA DUTY® Non-Metallic While-In-Use Covers

Description	Product Variations	Dimensions Inches (mm)	Catalog No.	
Standard 1-gang box with clear tinted cover, for horizontal or vertical mounting; 16-in-1 configurations	1.16	5.90" x 4.18" x 2.75" (149.8 x 106.1 x 69.9)	RW58300	
Extra deep 1-gang box with clear tinted cover, for horizontal or vertical mounting; 16-in-1 configurations	1.16	5.92" x 4.20" x 4.75" (150.4 x 106.7 x 120.7)	RW58350	
Standard 2-gang box, clear tinted cover, for horizontal or vertical mounting; 55-in-1 configurations	1.55	5.54" x 5.43" x 2.75" (140.7 x 138.0 x 69.9)	RW58750	

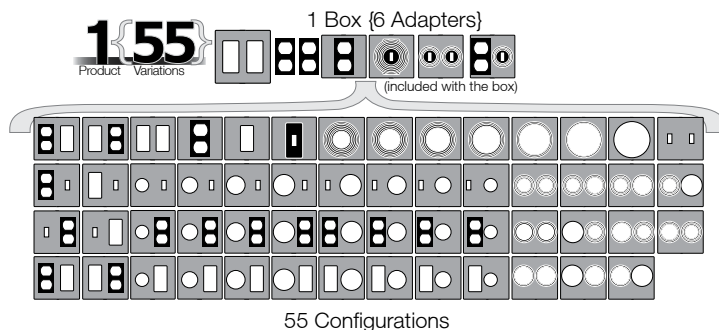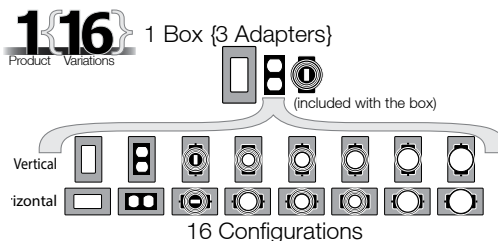

Note: NEC® is a registered trademark of the National Electrical Code. NEMA® is a registered trademark of the National Electrical Manufacturers Association.